


# FEED THROUGH TERMINAL BLOCKS

## AVK Series




- Screw Connection
- Vibration Resistant, Maintenance Free Connection
- Self-Locking Zinc Plated Wire Clamps
- 600V Rated, UL 94 V2 Polyamide 6.6 Housing
- Full Line of Accessories—End Plates, Cross Connectors and Marking Tags
- Stock Colors in Grey, Blue and Red
- Also Available in Yellow, Beige and Green

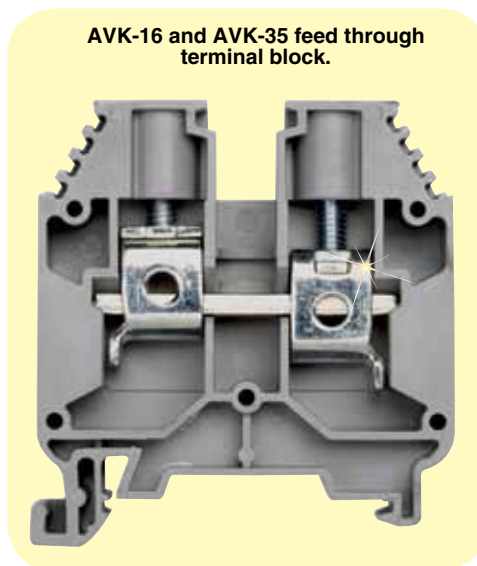

AVK-16 and AVK-35 feed through terminal block.

All models shown smaller than actual size.

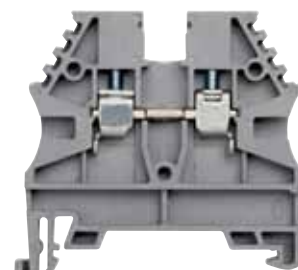

AVK-2.5 to AVK-10 feed through terminal block.



AVK-70 feed through terminal block.



AVK-2.5 ground terminal block.

AVK Series feed through terminal blocks are screw connection style with vibration resistant wire clamps and are DIN rail mounted. The AVK terminal blocks come in all wire ranges and no pre-treatment of the wire is necessary, even for stranded wire. A full line of accessories are available including end plates, end brackets, cross connectors and marking tags. The AVK series also includes 3 size grounding terminal blocks.

## SPECIFICATIONS

ELECTRICAL RATINGS	AVK-2.5	AVK-4	AVK-6	AVK-10	AVK-16	AVK-35	AVK-70
Voltage/Current	750V/26 A	750V/34 A	750V/44 A	750V/61 A	750V/82 A	750V/135 A	750V/192 A
VDE (IEC 60947-7-1)	750V/24 A	750V/32 A	630V/41 A	630V/57 A	750V/76 A	750V/125 A	
UL/CSA	600V/20 A	600V/30 A	600V/50 A	600V/65 A	600V/85 A	600V/115 A	600V/175 A
ATEX	630V/21 A	400V/28 A	630V/36 A	500V/50 A	630V/66 A	630V/109 A	1000V/167 A
Insulation Strip Length	10 mm	10 mm	12 mm	12 mm	16 mm	18 mm	20 mm
AWG	26-12	26-10	26-8	16-6	14-4	8-1	6-2/0
Width	5 mm	6 mm	8 mm	10 mm	12 mm	16 mm	22 mm
End Plate-Partition	AVK-EP-210	AVK-EP-210	AVK-EP-210	AVK-EP-210	AVK-EP-16	Included	Included
Cross-Connectors/2	OM-474122	OM-474132	OM-474142	OM-474152	OM-474162	OM-474172	—
Cross-Connectors/3	OM-474123	OM-474133	OM-474143	OM-474153	OM-474163	OM-474173	—
Cross-Connectors/4	OM-474124	OM-474134	OM-474144	OM-474154	OM-474164	OM-474174	—
Cross-Connectors/10	OM-474129	OM-474139	OM-474149	OM-474159	OM-474169	OM-474179	—

GROUNDING TERMINAL BLOCKS	AVK-2.5/4T	AVK-6/10T	AVK-16/35T
Insulation Strip Length	10 mm	12 mm	18 mm
AWG	26-10	16-8	10-2
Width	6 mm	10 mm	16 mm
End Plate-Partition	Included	Included	Included

OM-474123, 3 piece cross connector.



Shown larger than actual size.

## To Order

MODEL NO.	AMPS	AWG	MODEL NO.	AMPS	AWG
AVK-2.5	20	26-12	AVK-16	85	12-4
AVK-4	30	26-10	AVK-35	115	10-2
AVK-6	50	26-8	AVK-70	175	6-2/0
AVK-10	65	16-6			

**Note:** Standard color is grey, for other colored terminal blocks add suffix “-R” for red, “-B” for blue, “-Y” for yellow, “-G” for green and “-BE” for beige, no additional cost.

## GROUNDING TERMINAL BLOCKS

MODEL NO.	AWG
AVK-2.5/4T	26-10
AVK-16	10-2
AVK-6/10T	16-8
AVK-16/35T	10-2

## ACCESSORIES

MODEL NO.	DESCRIPTION
AVK-EP-210	End plate-partition for AVK-2.5 thru AVK-10
AVK-EP-16	End plate-partition for AVK-16
T-BLK-EB	DIN rail end bracket

## CROSS-CONNECTORS

MODEL NO.	POSITIONS	MODEL NO.	POSITIONS
OM-474122	2	OM-474152	2
OM-474123	3	OM-474153	3
OM-474124	4	OM-474154	4
OM-474129	10	OM-474159	10
OM-474132	2	OM-474162	2
OM-474133	3	OM-474163	3
OM-474134	4	OM-474164	4
OM-474139	10	OM-474169	10
OM-474142	2	OM-474172	2
OM-474143	3	OM-474173	3
OM-474144	4	OM-474174	4
OM-474149	10	OM-474179	10

## MARKING TAGS - 50 PER CARD

## DESCRIPTION

MKR-NO-PRINT	Marking tag without print
MKR-1-10	Marking tag 1 to 10
MKR-11-20	Marking tag 11 to 20
MKR-1-50	Marking tag 1 to 50
MKR-51-100	Marking tag 51 to 100
MKR-101-150	Marking tag 101 to 150
MKR-151-200	Marking tag 151 to 200
MKR-201-250	Marking tag 201 to 250

**Ordering Examples:** AVK-2.5, feed through terminal block for 26-12 AWG rated at 20 A, AVK-EP-210, end plate for AVK-2.5 through AVK-10, and OM-474123, three-position cross connectors.

AVK-35, feed through terminal block for 10-2 AWG rated at 115 A, MKR-1-10, 1 card of 50 marker tags printed with numbers 1 to 10.