

# NEMA 4X 304 STAINLESS STEEL SLOPE TOP ENCLOSURES

## 2 DOOR FREE STANDING ENCLOSURES FOR WASHDOWN AND CORROSIVE APPLICATIONS

For Use  
in Food and  
Beverage  
Industries

### SCE-2DST Series



- 0.104" Thick 304 Stainless Steel
- Seams Continuously Welded and Ground Smooth
- Flange Trough Collar Around All Sides of Door Opening
- 15° Sloping Top
- Removable Center Post
- Heavy-Duty Lifting Eyes Anchor into Reinforced Top
- Body Stiffeners
- Stainless Steel Concealed Hinges and Padlocking Handles
- 3-Point Latching Mechanism
- Removable Print Pocket on Main Door of Disconnect Enclosures
- Provisions for 305 mm (12") Removable Floor Stands
- Panel Supports
- Oil and Water Resistant Gasket
- Ground Stud on Door and Body

The SCE-2DST Series 304 SS electrical enclosure and control panel is designed to house electrical and electronic controls, instruments and equipment in areas which may be regularly hosed down or are in very wet conditions. The 15° slope top on these enclosures and control panels provide protection from dust, dirt, oil and strong jets of water. This indoor/outdoor electrical control panel is the solution for weatherproof applications and use in corrosive environments.



SCE-60EL4812SSST, 304 SS slope top 2 door electrical enclosure shown much smaller than actual size.


### SPECIFICATIONS

#### Finish:

#4 brushed finish on all exterior surfaces. Optional panels are powder coated white.

#### Industry Standard IS5:

NEMA Type 4, 4X, 12, and Type 13  
UL Listed Type 4, 4X, 12  
CSA Type 4, 4X, 12  
IEC 60529 IP 66

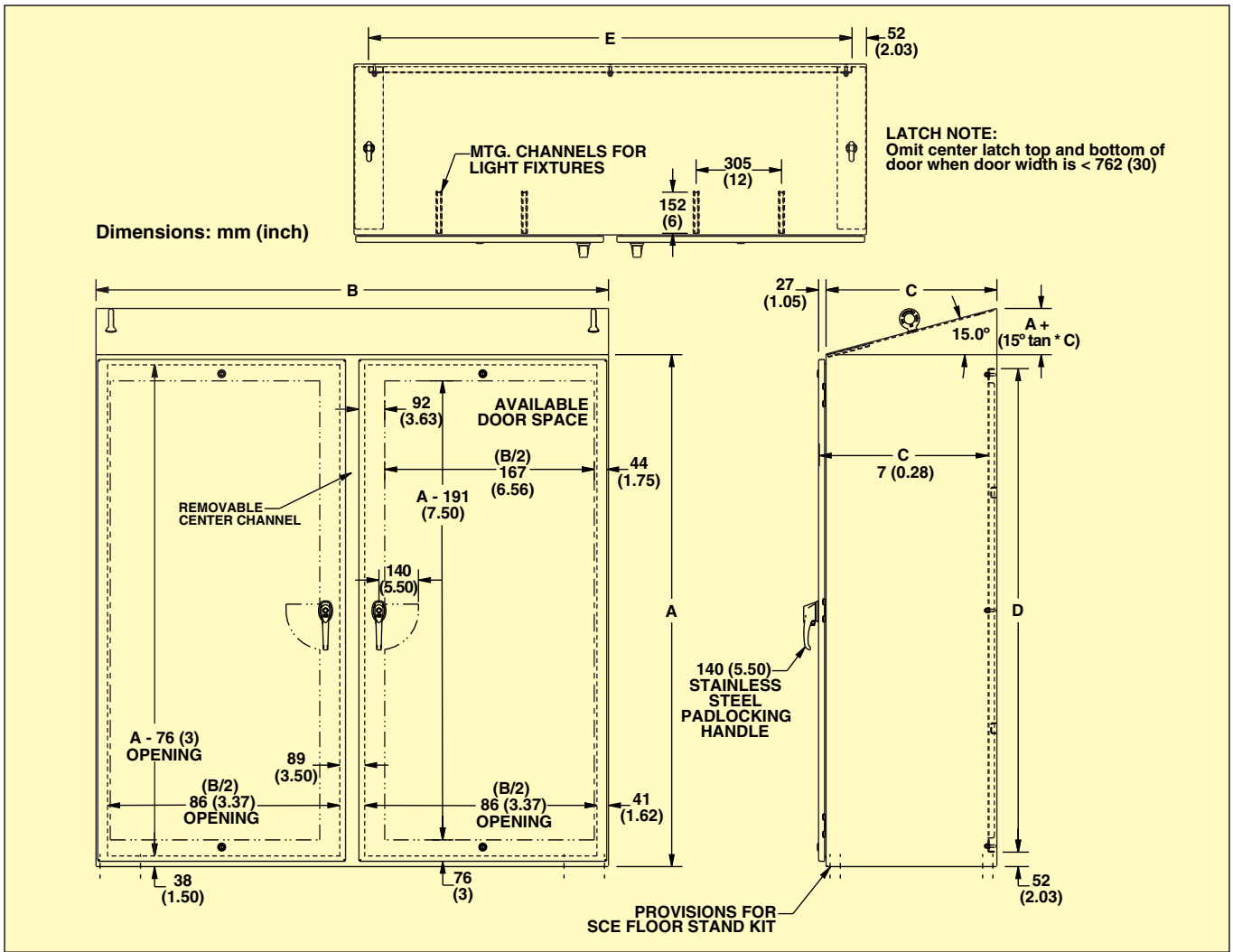

To Order							
MODEL NO.	HEIGHT A (inch)	WIDTH B (inch)	DEPTH C (inch)	Wt. kg (lb)	MODEL NO.	HEIGHT D (inch)	WIDTH E (inch)
SCE-60EL4812SSST	60	48	12	235 (519)	SCE-60P48	56	44
SCE-60EL4818SSST	60	48	18	238 (525)	SCE-60P48	56	44
SCE-60EL6012SSST	60	60	12	259 (571)	SCE-60P60	56	56
SCE-60EL6018SSST	60	60	18	273 (602)	SCE-60P60	56	56
SCE-72EL6012SSST	72	60	12	294 (649)	SCE-72P60	68	56
SCE-72EL6018SSST	72	60	18	309 (682)	SCE-72P60	68	56
SCE-72EL7212SSST	72	72	12	336 (740)	SCE-72P72	68	68
SCE-72EL7218SSST	72	72	18	355 (783)	SCE-72P72	68	68
SCE-72EL7224SSST	72	72	24	408 (904)	SCE-72P72	68	68

## ACCESSORIES

MODEL NO.	DESCRIPTION
SCE-60P48GALV	Galvanized sub-panel for 60 x 48" enclosure
SCE-60P60GALV	Galvanized sub-panel for 60 x 60" enclosure
SCE-72P60GALV	Galvanized sub-panel for 72 x 60" enclosure
SCE-72P72GALV	Galvanized sub-panel for 72 x 72" enclosure

Ordering Example: SCE-60EL4812SSST, 304 stainless steel slope top free standing enclosure 60 x 48 x 12", and SCE-60P48, sub-panel. SCE-72EL7224SSST, 304 stainless steel slope top wall mount enclosure 72 x 72 x 24", SCE-72P72GALV, galvanized sub-panel.