

NEMA 4X 304 STAINLESS STEEL SLOPE TOP ENCLOSURES

WALL MOUNT ENCLOSURES FOR WASHDOWN AND CORROSIVE APPLICATIONS

For Use
in Food and
Beverage
Industries

SCE-ELST Series



- 0.075" Thick 304 Stainless Steel
- Seams Continuously Welded and Ground Smooth
- Flange Trough Collar Around All Sides of Door Opening
- 15° Sloping Top
- Collar Studs Provided for Mounting Optional Sub-Panels
- Mounting Holes in Back of the Enclosure for Wall Mounting
- Mounting Hardware, Sealing Washers and Hole Plugs Included
- Stainless Steel Concealed Hinges
- Removable and Interchangeable Doors
- Black Quarter Turn Latches
- Latches are Opened or Closed with a Screwdriver
- Removable Print Pocket
- Oil and Water Resistant Gasket
- Ground Stud on Door and Body



SCE-16EL1208SSST,
304 SS slope top wall mount
electrical enclosure shown
smaller than actual size.


The SCE-ELST Series 304 SS electrical enclosures are designed to house electrical and electronic controls, instruments and equipment in areas which may be regularly hosed down or are in very wet conditions. The 15° slope top on these enclosures and control panels provide protection from dust, dirt, oil and strong jets of water. This indoor/outdoor electrical control panel is the solution for weatherproof applications or for use in corrosive environments.

SPECIFICATIONS

Finish:
#4 brushed finish on all exterior surfaces. Optional panels are powder coated white.

Industry Standard IS5

NEMA Type 4, 4X, 12 & Type 13
UL Listed Type 4, 4X, 12
CSA Type 4, 4X, 12
IEC 60529 IP 66

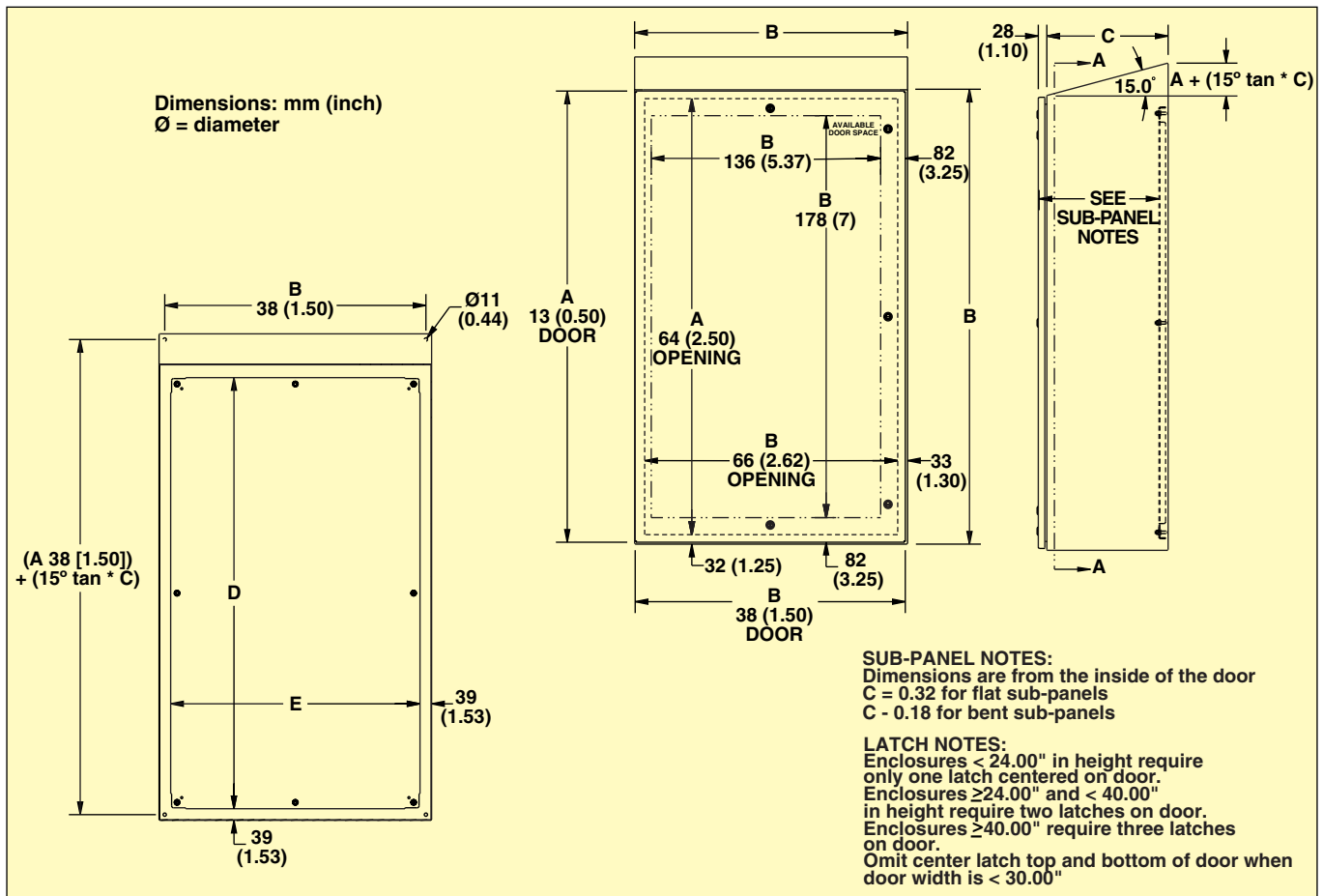

To Order

MODEL NO.	HEIGHT A (inch)	WIDTH B (inch)	DEPTH C (inch)	Wt. kg (lb)	SUB-PANEL MODEL NO.	HEIGHT D (inch)	WIDTH E (inch)
SCE-16EL1208SSST	16	12	8	8 (18)	SCE-16P12	13	9
SCE-16EL1608SSST	16	16	8	10 (22)	SCE-16P16	13	13
SCE-20EL1608SSST	20	16	8	14 (30)	SCE-20P16	17	13
SCE-20EL1612SSST	20	16	12	18 (39)	SCE-20P16	17	13
SCE-20EL2008SSST	20	20	8	17 (38)	SCE-20P20	17	17
SCE-20EL2012SSST	20	20	12	21 (47)	SCE-20P20	17	17
SCE-24EL2008SSST	24	20	8	18 (40)	SCE-24P20	21	17
SCE-24EL2012SSST	24	20	12	25 (56)	SCE-24P20	21	17
SCE-24EL2408SSST	24	24	8	23 (50)	SCE-24P24	21	21
SCE-24EL2412SSST	24	24	12	30 (66)	SCE-24P24	21	21
SCE-30EL2408SSST	30	24	8	25 (56)	SCE-30P24	27	21
SCE-30EL2412SSST	30	24	12	32 (71)	SCE-30P24	27	21
SCE-30EL3008SSST	30	30	8	33 (73)	SCE-30P30	27	27
SCE-36EL2408SSST	36	24	8	32 (71)	SCE-36P24	33	21
SCE-36EL2412SSST	36	24	12	35 (78)	SCE-36P24	33	21
SCE-36EL3008SSST	36	30	8	35 (77)	SCE-36P30	33	27
SCE-36EL3012SSST	36	30	12	45 (99)	SCE-36P30	33	27
SCE-36EL3016SSST	36	30	16	50 (110)	SCE-36P30	33	27
SCE-48EL3616SSST	48	36	16	78 (173)	SCE-48P36	45	33
SCE-60EL3616SSST	60	36	16	82 (180)	SCE-60P36	57	33

Comes complete with mounting hardware, sealing washers, and hole plugs.

Ordering Examples: SCE-16EL1208SSST, 304 stainless steel slope top wall mount enclosure 16 x 12 x 8", and SCE-16P12, sub-panel.
 SCE-24EL2008SSST, 304 stainless steel slope top wall mount enclosure 24 x 20 x 8", and SCE-24P20GALV, galvanized sub-panel.