


# NEMA TYPE 12 SERIES 14 TWO-DOOR CONSOLES

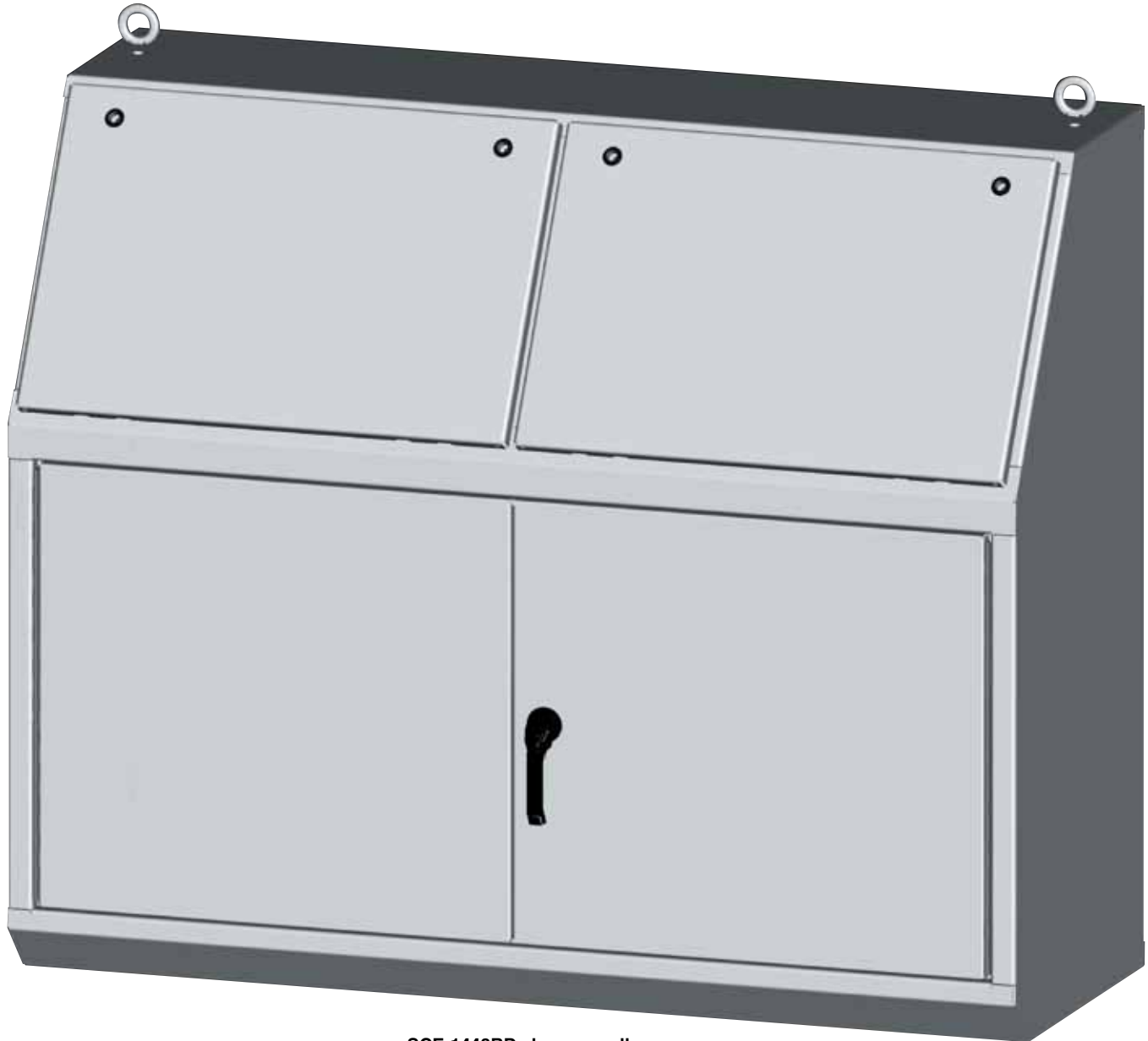


SCE-1448BD shown smaller  
than actual size.

## *SCE-14 2-Door Consoles Series*



- 0.104" Carbon Steel
- Sloping Control Panel Attached with Concealed Hinge on Bottom Edge
- Door opens to 90°
- Black Zinc Die Cast Keylocking/ Padlocking Handles on Front and Rear Doors
- 3-Point Latching Mechanism
- Seams Continuously Welded and Ground Smooth
- Oil-Resistant Gasket on Door
- Optional Equipment Mount to Horizontal Channels Welded to Sides
- Flush Mounted Doors
- Optional Writing Desk and Top Section Available
- Interior Print Pocket
- Removable Eyebolts in Console Body
- Ground Stud on Door

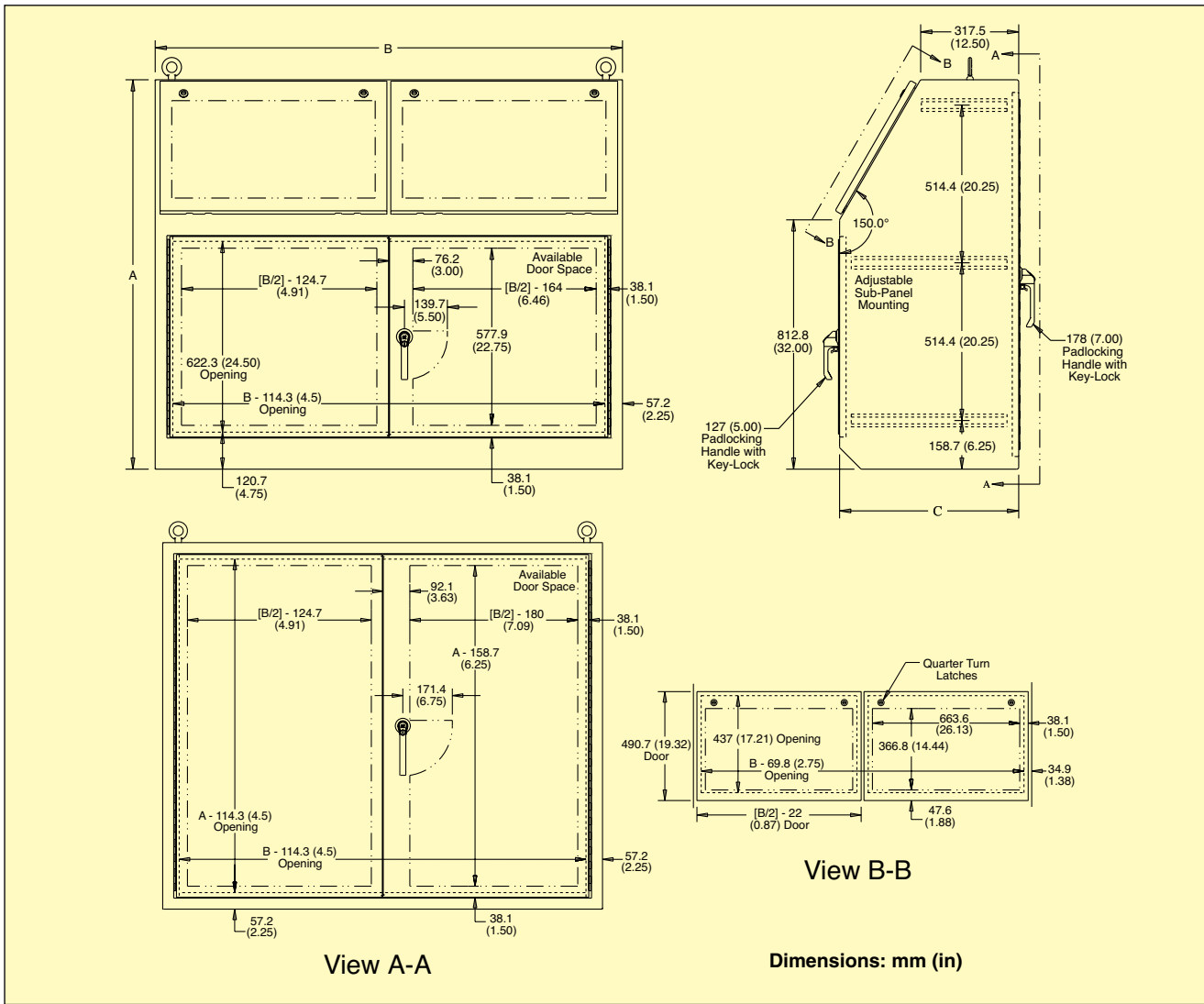

### Application

Designed for electronic controls and instruments. Equipment can be mounted on the sloping control panel door. Interior components mount to stationary panels. Heavy duty construction provides protection from dirt, oil, dust, and water.

### Finish

White powder coated inside and ANSI-61 recoatable gray finish outside over phosphatized surfaces. Optional top sections are ANSI-61 recoatable gray finish inside and outside. Optional panels are powder coated white.

### Industry Standards

NEMA Type 12 & Type 13  
 UL Listed Type 12  
 CSA Type 12  
 IEC 60529 IP 55

<b>To Order</b>				
MODEL NO.	DESCRIPTION	HEIGHT (A) (in)	WIDTH (B) (in)	DEPTH (C) (in)
<b>SERIES 14 TWO DOOR CONSOLES—48" WIDE</b>				
SCE-1448BD	Console body	50.00	48.00	23.00
SCE-1448T	Console top	16.00	48.00	12.50
SCE-1448P2	Half sub-panel	22.00	41.00	
SCE-1448P3	Full sub-panel	42.25	41.00	
SCE-1448W	Writing desk	48.00	10.00	
<b>SERIES 14 TWO DOOR CONSOLES—60" WIDE</b>				
SCE-1460BD	Console body	50.00	60.00	23.00
SCE-1460T	Console top	16.00	60.00	12.50
SCE-1460P2	Half sub-panel	22.00	53.00	
SCE-1460P3	Full sub-panel	42.25	53.00	
SCE-1460W	Writing desk	60.00	10.00	
<b>SERIES 14 TWO DOOR CONSOLES—72" WIDE</b>				
SCE-1472BD	Console body	50.00	72.00	23.00
SCE-1472T	Console top	16.00	72.00	12.50
SCE-1472P3	Full sub-panel	42.25	65.00	
SCE-1472W	Writing desk	72.00	10.00	

**Ordering Examples:** SCE-1448BD, Type 12 series 14 two-door console.  
 SCE-1460BD, Type 12, two-door console, 50 H x 60 W x 23" D, and SCE-1460P3, full-size panel.