

NEMA TYPE 3R HINGED COVER ENCLOSURES

*SCE-3R
Hinge Series*




SCE-12R1206LP
shown smaller
than actual size.

- 0.060 and 0.075" Galvannealed Steel
- Concealed Hinges
- Spot Weld Construction
- Rain Cap
- Mounting Hole In Back of Enclosure

- Provisions for Subplate
- Black Quarter Turn Latches
- Doors Open 180°
- Black Quarter Turn Latch with Padlocking Provisions
- Oil Resistant Gasket

- Ground Studs on Door and Body
- 3/8"-16 Grounding Kit
- Subplate Mounting Hardware
- Optional Mounting Straps Available

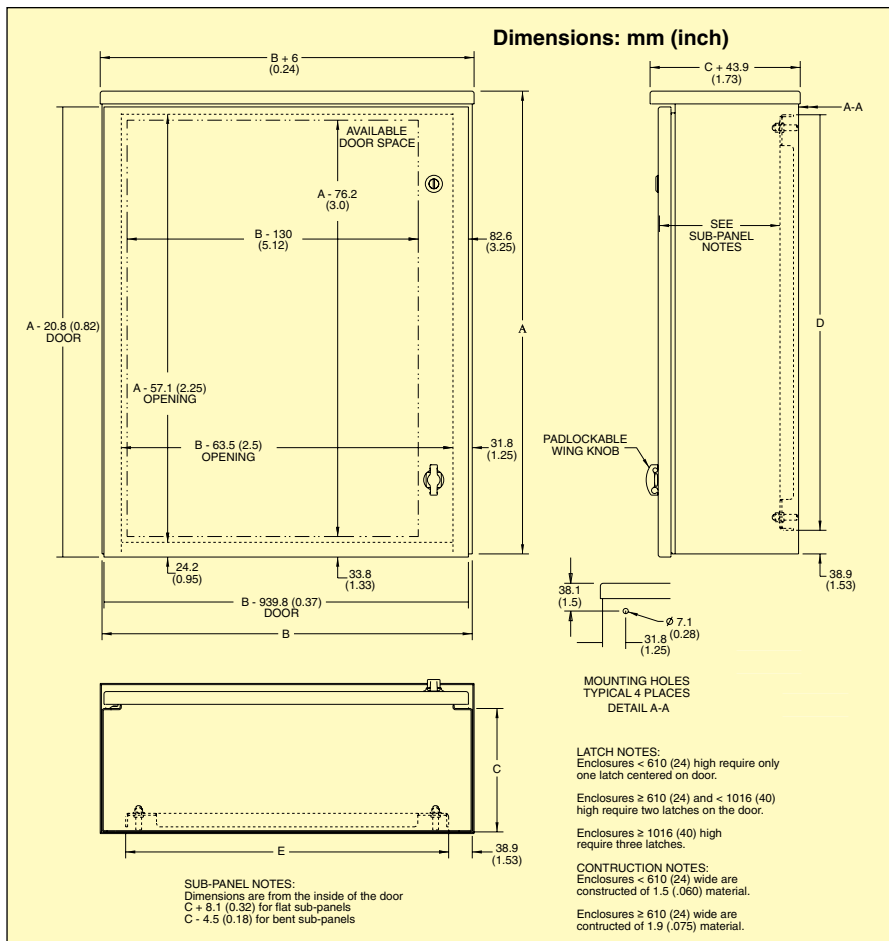

Application

Designed to house electrical controls, instruments and components in an outdoor environment. Protects against rain, sleet and snow.

Finish

ANSI-61 gray powder coat inside and out over phosphatized surface. Optional panels are powder coated white.

Industry Standards

NEMA Type 3R
 UL Listed Type 3R
 CSA Type 3R
 IEC 60529 IP 32

To Order

TYPE 3R HINGED COVER ENCLOSURES

MODEL NO.	ENCLOSURES (inch)			SUB-PANEL (inch)		
	HEIGHT (A)	WIDTH (B)	DEPTH (C)	MODEL NO.	HEIGHT (D)	WIDTH (E)
SCE-12R1206LP	12.00	12.00	6.00	SCE-12DLP12	9.00	9.00
SCE-12R1208LP	12.00	12.00	8.00	SCE-12DLP12	9.00	9.00
SCE-16R1206LP	16.00	12.00	6.00	SCE-16P12	13.00	9.00
SCE-16R1208LP	16.00	12.00	8.00	SCE-16P12	13.00	9.00
SCE-20R1606LP	20.00	16.00	6.00	SCE-20P16	17.00	13.00
SCE-20R1608LP	20.00	16.00	8.00	SCE-20P16	17.00	13.00
SCE-24R2006LP	24.00	20.00	6.00	SCE-24P20	21.00	17.00
SCE-24R2008LP	24.00	20.00	8.00	SCE-24P20	21.00	17.00
SCE-24R2012LP	24.00	20.00	12.00	SCE-24P20	21.00	17.00
SCE-24R2016LP	24.00	20.00	16.00	SCE-24P20	21.00	17.00
SCE-30R2408LP	30.00	24.00	8.00	SCE-30P24	27.00	21.00
SCE-30R2412LP	30.00	24.00	12.00	SCE-30P24	27.00	21.00
SCE-30R2416LP	30.00	24.00	16.00	SCE-30P24	27.00	21.00
SCE-36R2408LP	36.00	24.00	8.00	SCE-36P24	33.00	21.00
SCE-36R2412LP	36.00	24.00	12.00	SCE-36P24	33.00	21.00
SCE-36R2416LP	36.00	24.00	16.00	SCE-36P24	33.00	21.00
SCE-36R3008LP	36.00	30.00	8.00	SCE-36P30	33.00	27.00
SCE-36R3012LP	36.00	30.00	12.00	SCE-36P30	33.00	27.00
SCE-36R3016LP	36.00	30.00	16.00	SCE-36P30	33.00	27.00
SCE-42R3012LP	42.00	30.00	12.00	SCE-42P30	39.00	27.00
SCE-42R3016LP	42.00	30.00	16.00	SCE-42P30	39.00	27.00

Ordering Examples: SCE-12R1206LP, Type 3R hinged cover enclosure.

SCE-24R2012LP, Type 3R hinged cover enclosure, 24 H x 20 W x 12" D, SCE-24P20, sub-panel.