



NEMA TYPE 12 SERIES 9 CONSOLES

SCE Consoles Series

- 0.075" Carbon Steel
- Sloping Control Panel Attached With Concealed Hinge on Bottom Edge
- Door Opens to 90°
- Black Zinc Die Cast Keylocking/ Padlocking Handle
- 3-Point Latching Mechanism
- Seams Continuously Welded and Ground Smooth
- Oil-Resistant Gasket on Door
- Interior Print Pocket
- Optional Back and Side Panels are Mounted on Collar Studs
- Removable Eyebolts
- Ground Stud on Door

Application

Designed for electronic controls and instruments. Equipment can be mounted on the sloping control panel door. Interior components mount to stationary panels. Provides protection from dirt, oil, dust and water.

Finish


White powder coated inside and ANSI-61 recoatable gray finish outside over phosphatized surfaces. Optional panels are powder coated white.

Industry Standards


NEMA Type 12 & Type 13
UL Listed Type 12
CSA Type 12
IEC 60529 IP 55

SCE-924B shown smaller than actual size.




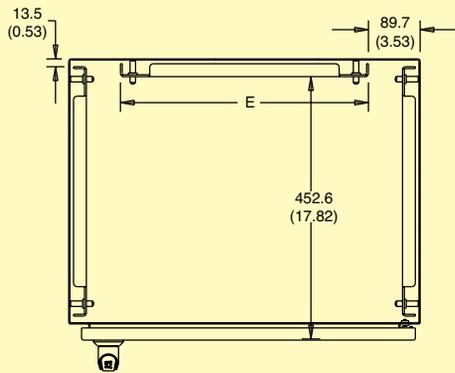


Section A-A

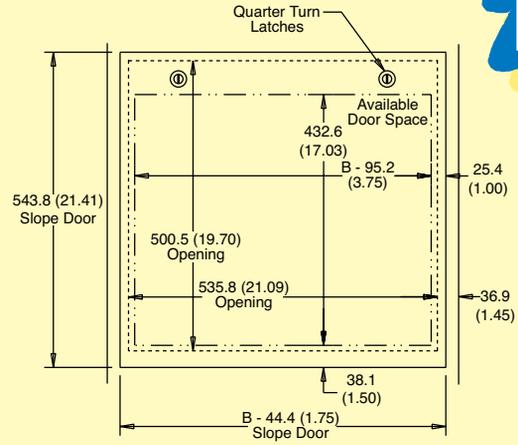

View B-B

Dimensions: mm (inch)

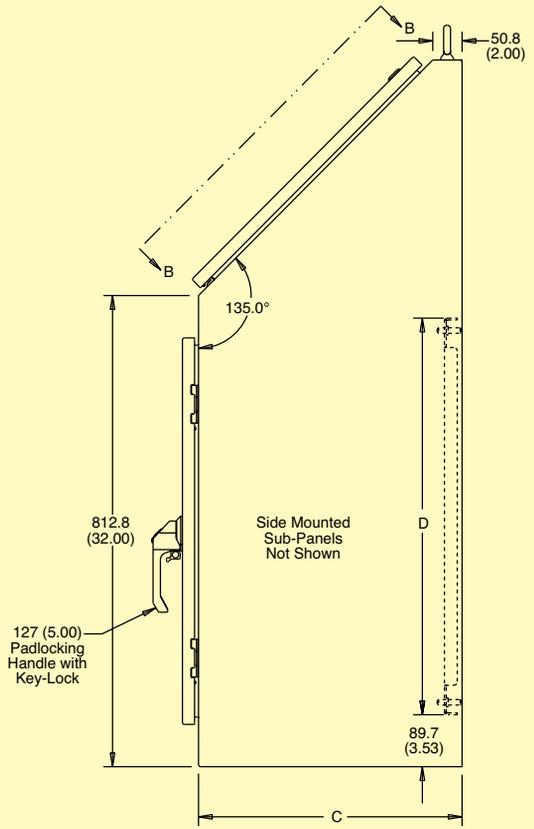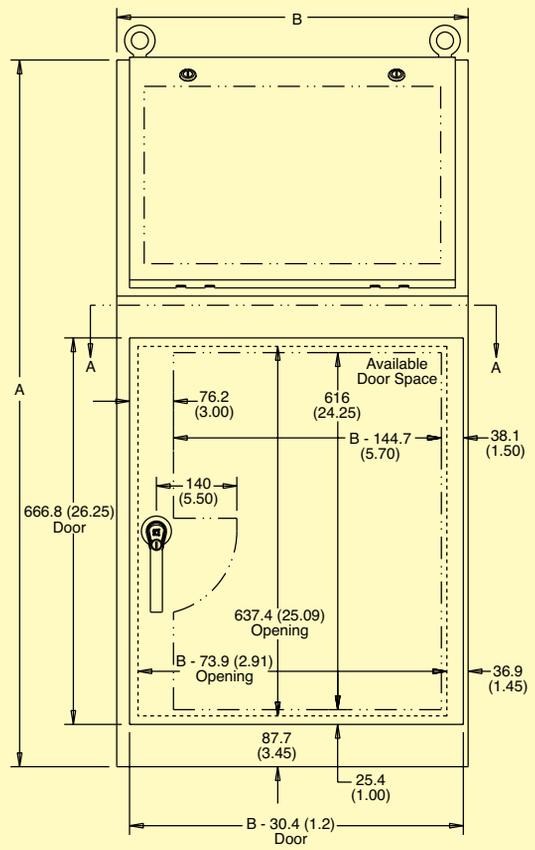

To Order Visit omega.com/sce_console9 for Pricing and Details

ENCLOSURES (inch)				SUB-PANEL			
MODEL NO.	HEIGHT (A)	WIDTH (B)	DEPTH (C)	MODEL NO.	QTY	HEIGHT (D)	WIDTH (E)
SCE-924B	48.00	24.00	18.00	SCE-30P20	3	27.00	17.00
SCE-936B	48.00	36.00	18.00	SCE-30P20	2	27.00	17.00
				SCE-30P30	1	27.00	27.00

Ordering Example: SCE-924B, Type 12 series 9 console.