


NEMA TYPE 4 ENVIROLINE® SERIES TWO-DOOR STEEL ENCLOSURES

*SCE-60EL and
SCE-72EL*

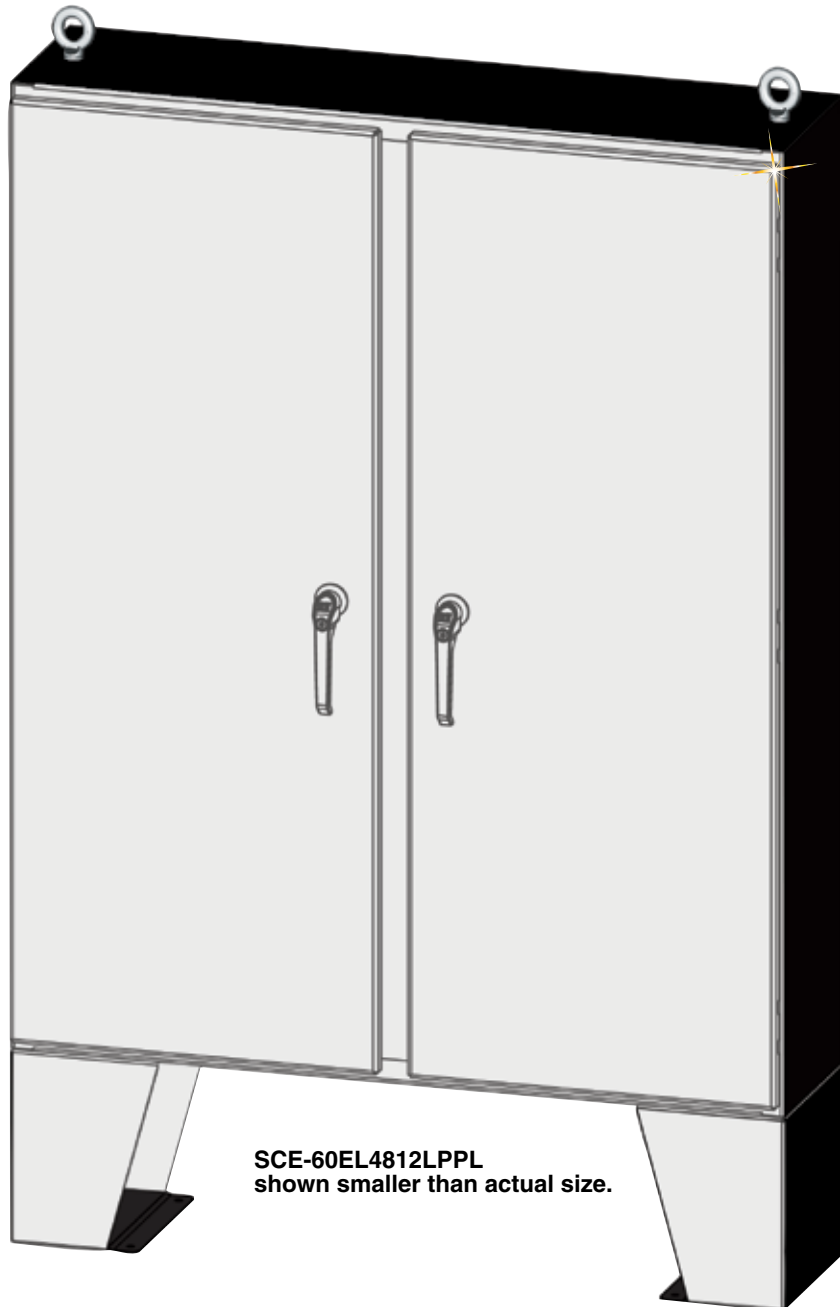

SCE-60EL4812LPPL
shown smaller than actual size.

- 0.104" Carbon Steel
- Seams Continuously Welded and Ground Smooth
- Oil-Resistant Gasket
- Flange Trough Collar Around All Sides of Door Opening
- Concealed Hinge
- Removable and Inchangeable Doors

- Black Quarter Turn Latches
- Lifting Eyes for Easy Handling
- Ground Studs on Door and Body
- Collar Studs Provided for Mounting Optional Panels
- 12" Removable Floor Stands
- Removable Centerposts

- No Door Stiffeners Required
- Padlocking or Keylocking Handle with 3-Point Operating Mechanism and Tamper-Resistant Hardware Included
- Provision for Mechanical Interlock

Application


Designed to house electrical and electronic controls, instruments and components. Provides protection from dust, oil and water. For outdoor application a drip shield is recommended.

Finish

ANSI-61 gray powder coating inside and out over phosphatized surfaces. Optional panels are powder coated white.

Industry Standards

NEMA Type 4, 12 & 13
UL Listed Type 4 & 12
CSA Type 4 & 12
IEC 60529 IP66

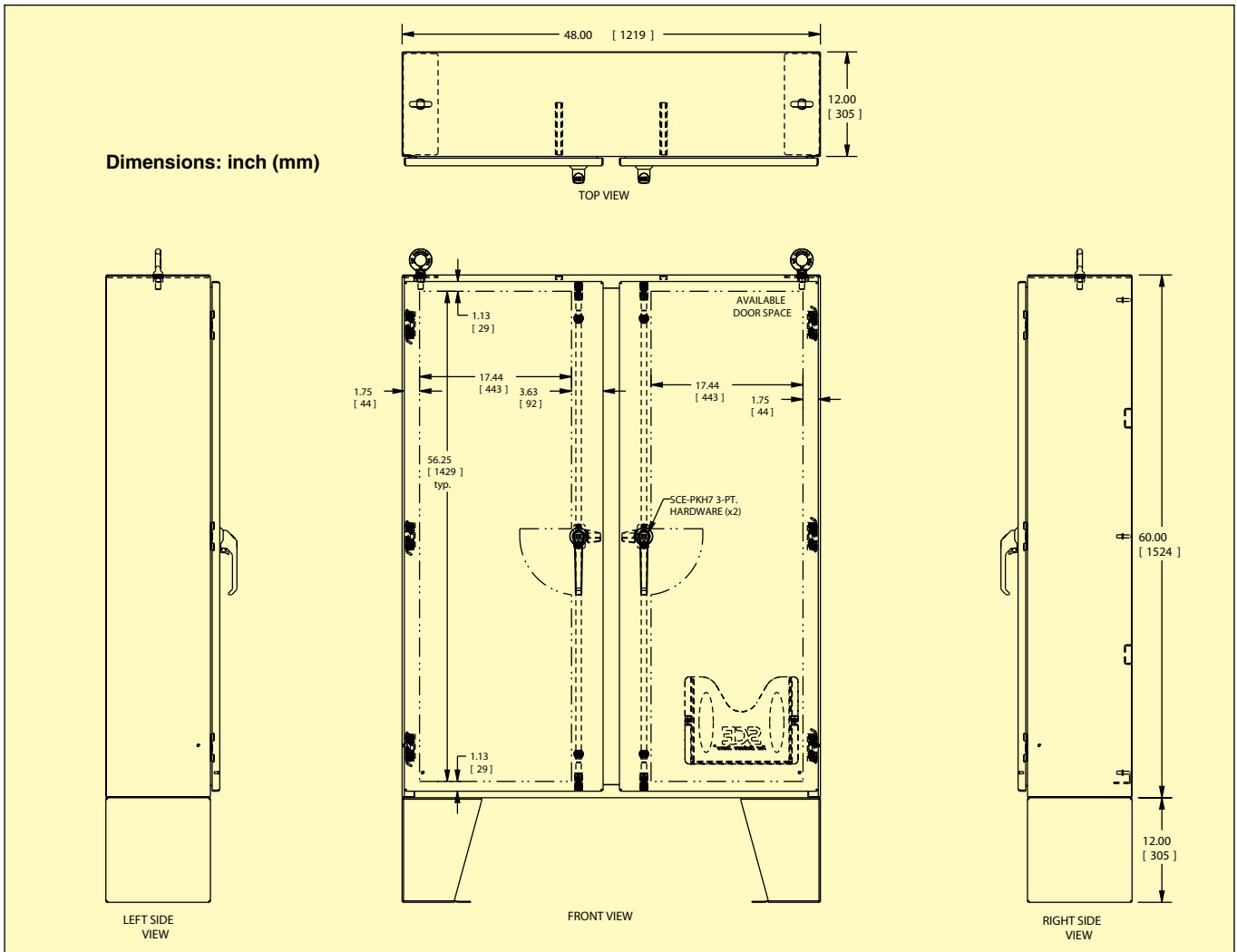

To Order

TYPE 4 ENVIROLINE SERIES TWO-DOOR ENCLOSURES

ENCLOSURES (inch)				SUB-PANEL (inch)		
MODEL NO.	HEIGHT (A)	WIDTH (B)	DEPTH (C)	MODEL NO.	HEIGHT (D)	WIDTH (E)
SCE-60EL4812LPPL	60.00	48.00	12.00	SCE-60P48	56.00	44.00
SCE-60EL4818LPPL	60.00	48.00	18.00	SCE-60P48	56.00	44.00
SCE-60EL6012LPPL	60.00	60.00	12.00	SCE-60P60	56.00	56.00
SCE-60EL6018LPPL	60.00	60.00	18.00	SCE-60P60	56.00	56.00
SCE-72EL6012LPPL	72.00	60.00	12.00	SCE-72P60	68.00	56.00
SCE-72EL6018LPPL	72.00	60.00	18.00	SCE-72P60	68.00	56.00
SCE-72EL7212LPPL	72.00	72.00	12.00	SCE-72P72	68.00	68.00
SCE-72EL7218LPPL	72.00	72.00	18.00	SCE-72P72	68.00	68.00
SCE-72EL7224LPPL	72.00	72.00	24.00	SCE-72P72	68.00	68.00

Ordering Example: SCE-60EL4812LPPL, Type 4 Enviroline® series two-door enclosure and SCE-60P48 sub-panel for 60 x 48" enclosure. SCE-72EL6012LPPL, Type 4 two-door enclosure with 3-point latching mechanism and keylock and padlocking handles plus SCE-72P60, sub-panel for 72 x 60" enclosure.