



NEMA TYPE 3R, 4 AND 12 FREE-STANDING SINGLE- DOOR, DUAL-ACCESS ENCLOSURES

SCE-FSDA



- 0.104" Carbon Steel
- Seams Continuously Welded and Ground Smooth, No Holes or Knockouts
- Strong, Rigid Construction
- Lifting Eyes for Easy Handling
- Black Zinc Die Cast Keylocking/ Padlocking Handle
- 3-Point Latching Mechanism
- Latch Rods Have Rollers for Easier Door Closing
- Concealed Hinge
- Flange Trough Collar Around All Sides of Door Opening
- Removable Print Pocket Provided On Door with 3-Point Latch
- Mounting Channels Welded Horizontally On Sides of Interior Body At Top, Bottom and Middle for Mounting Optional Panels or Rack Mounting Angles
- Oil Resistant Gasket
- Ground Stud On Door
- Removable and Interchangeable Doors

Application

Designed to house a variety of electrical and electronic controls and instruments. Provisions for optional surface mounting or rack mounting of almost any type of equipment. Provides protection from dust, dirt, water and oil. The enclosures are extra deep for applications requiring more interior space.

Finish

White powder coating inside and ANSI-61 recoatable gray finish outside over phosphatized surfaces. Optional panels are powder coated white.

Industry Standard IS3


NEMA Type 3R, 12 and 13
UL Listed Type 3R and 12
CSA Type 3R and 12
IEC 60529 IP 55

Industry Standard IS4

NEMA Type 3R, 4, 12 and 13
UL Listed Type 3R, 4 and 12
CSA Type 3R, 4 and 12
IEC 60529 IP 66

SCE-72EL2424FSDA
shown smaller than
actual size.



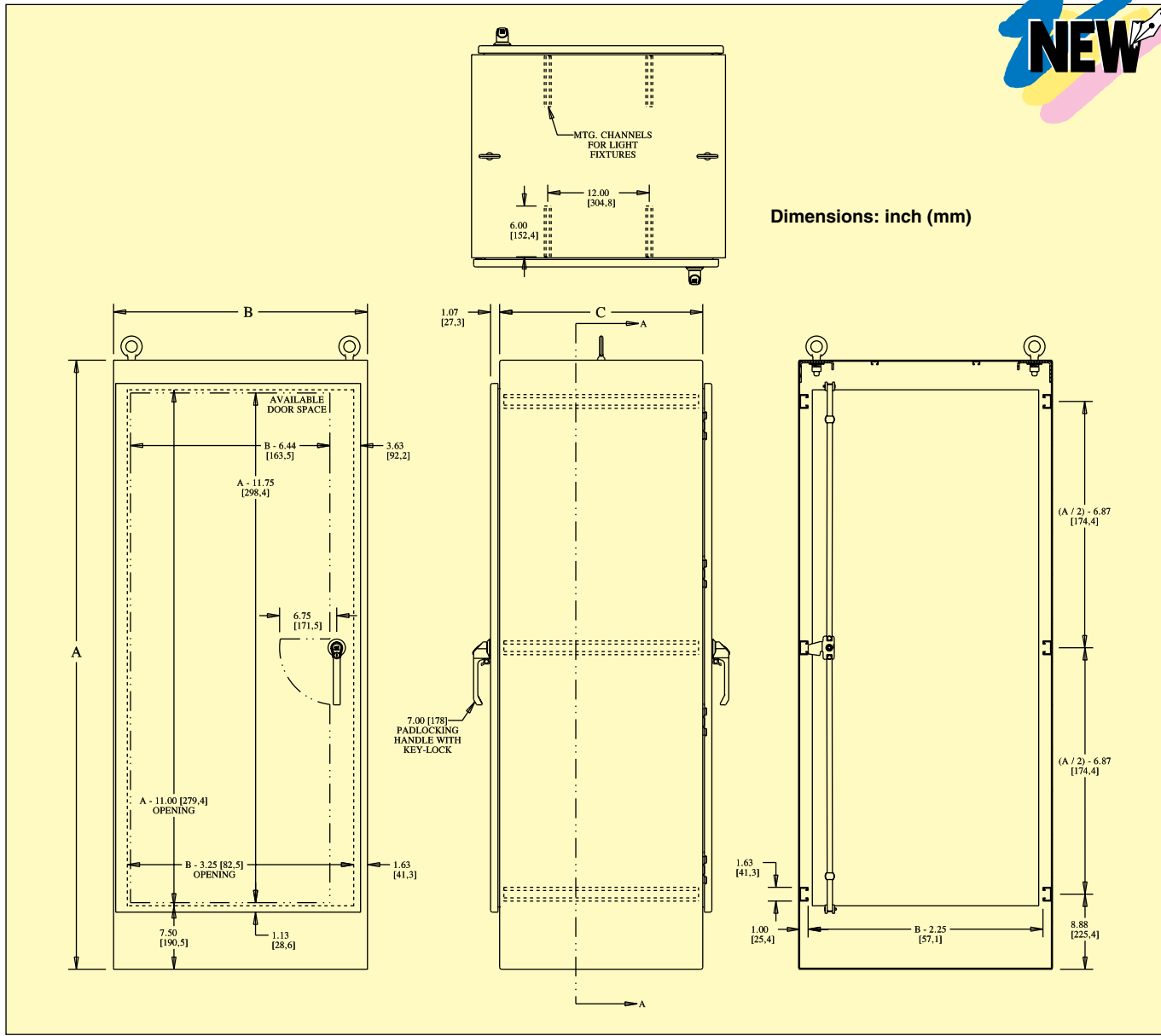

To Order Visit omega.com/sce_fsd for Pricing and Details

MODEL NO.	DESCRIPTION	INDUSTRY STANDARD	HEIGHT A (inch)	WIDTH B (inch)	DEPTH C (inch)
SCE-72EL2424FSDA	NEMA Type 3R and 4 free standing outdoor enclosure	IS4	72	24	24
SCE-72EL2430FSDA	NEMA Type 3R and 4 free standing outdoor enclosure	IS4	72	24	30
SCE-72EL2436FSDA	NEMA Type 3R and 4 free standing outdoor enclosure	IS4	72	24	36
SCE-72EL3024FSDA	NEMA Type 3R and 4 free standing outdoor enclosure	IS4	72	30	24
SCE-723624FSDA	NEMA Type 3R free standing outdoor enclosure	IS3	72	36	24
SCE-723636FSDA	NEMA Type 3R free standing outdoor enclosure	IS3	72	36	36
SCE-903624FSDA	NEMA Type 3R free standing outdoor enclosure	IS3	90	36	24
SCE-903636FSDA	NEMA Type 3R free standing outdoor enclosure	IS3	90	36	36

DRIP SHIELDS*

SCE-DS20N4	Drip shield for 18" wide outdoor enclosure (requires cutting)
SCE-DS24N4	Drip shield for 24" wide outdoor enclosure
SCE-DS30N4	Drip shield for 30" wide outdoor enclosure
SCE-DS36N4	Drip shield for 36" wide outdoor enclosure

* Note: Drip shield required for above enclosures to meet 3R rating.
 Ordering Example: SCE-72EL2424FSDA, Type 3R and 4 free standing, single-door, dual access, carbon steel enclosure.
 SCE-903636FSDA, Type 3R outdoor, dual access enclosure.