

# NEMA TYPE 3R AND 12 FREE-STANDING TWO-DOOR, DUAL-ACCESS ENCLOSURES

## SCE-FSDAD Series



- 0.104" Carbon Steel
- Seams Continuously Welded and Ground Smooth, No Holes or Knockouts
- Strong, Rigid Construction
- Lifting Eyes for Easy Handling
- Black Zinc Die Cast Keylocking/ Padlocking Handle
- 3-Point Latching Mechanism
- Latch Rods Have Rollers for Easier Door Closing
- Concealed Hinge
- Flange Trough Collar Around All Sides of Door Opening
- Removable Print Pocket Provided On Door With 3-Point Latch
- Mounting Channels Welded Horizontally On Sides of Interior Body At Top, Bottom and Middle For Mounting Optional Panels or Rack Mounting Angles
- Oil Resistant Gasket
- Removable and Interchangeable Doors



SCE-724824FSDAD shown smaller than actual size.

## Application

Designed to house a variety of electrical and electronic controls and instruments. Provides for optional surface mounting or rack mounting of almost any type of equipment. Provides protection from dust, dirt, water and oil. The enclosures are extra deep for applications requiring more interior space.


## Finish

White powder coating inside and ANSI-61 recoatable gray finish outside over phosphatized surfaces. Optional panels are powder coated white.

## Industry Standard IS3

NEMA Type 3R, Type 12 and Type 13  
UL Listed Type 3R and 12  
CSA Type 3R and 12  
IEC 60529 IP 55

**Note:** Drip shield required for NEMA 3R rating.

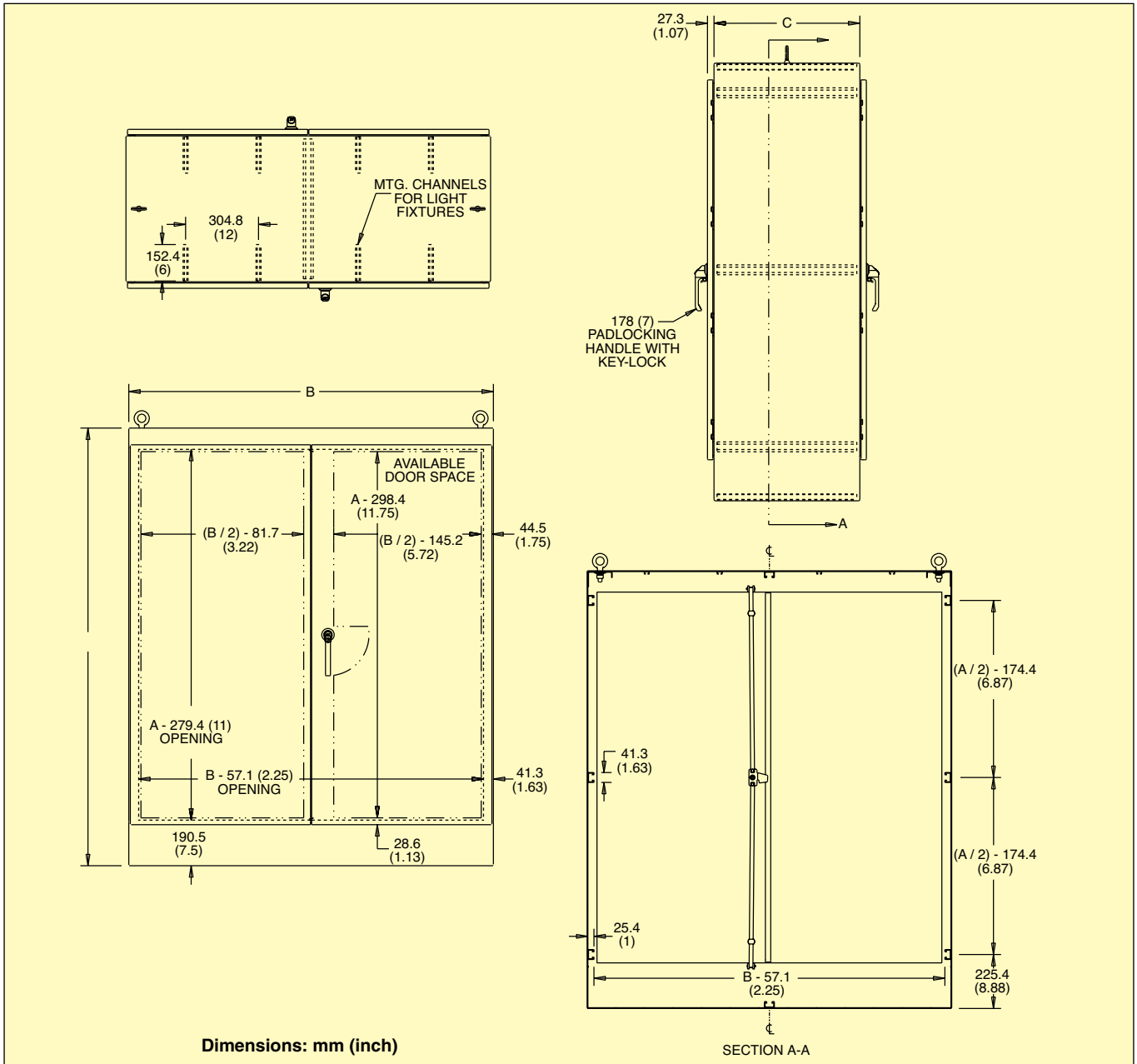

## To Order

MODEL NO.	DESCRIPTION	HEIGHT (inch) (A)	WIDTH (inch) (B)	DEPTH (inch) (C)
<b>DUAL ACCESS CARBON STEEL ENCLOSURES</b>				
SCE-724824FSDAD	Type 3R and 12 free-standing single-door	72.00	48.00	24.00
SCE-726024FSDAD	Type 3R and 12 free-standing single-door	72.00	60.00	24.00
SCE-726036FSDAD	Type 3R and 12 free-standing single-door	72.00	60.00	36.00
SCE-727224FSDAD	Type 3R and 12 free-standing single-door	72.00	72.00	24.00
SCE-907224FSDAD	Type 3R and 12 free-standing single-door	90.00	72.00	24.00
<b>DRIP SHIELDS*</b>				
SCE-DS48N4	Drip shield for 48" wide outdoor enclosure			
SCE-DS60N4	Drip shield for 60" wide outdoor enclosure			
SCE-DS72N4	Drip shield for 72" wide outdoor enclosure			

\* Drip shield required to meet NEMA 3R ratings.

Ordering Example: SCE-724824FSDAD Type 12 free-standing, two-door, dual access, carbon steel enclosure.