


NEMA TYPE 4 SINGLE-DOOR ENCLOSURES FOR FLANGE-MOUNTED DISCONNECTS

SCE-HS Series



- 0.075" Carbon Steel
- Seams Continuously Welded and Ground Smooth
- Continuous Hinge With Stainless Steel Hinge Pin
- Stainless Steel Clamps On 3 Sides of Door
- Flange Trough Collar Around All Sides of Door Opening
- Interior Print Pocket
- Collar Studs Provided for Mounting Optional Panels
- Oil-Resistant Gasket
- Disconnect Cutout Provided on Flange
- Ground Stud On Door
- No Door Stiffener Required
- Disconnect Switch (or Circuit Breaker) and Operating Mechanism Are Not Furnished with This Enclosure

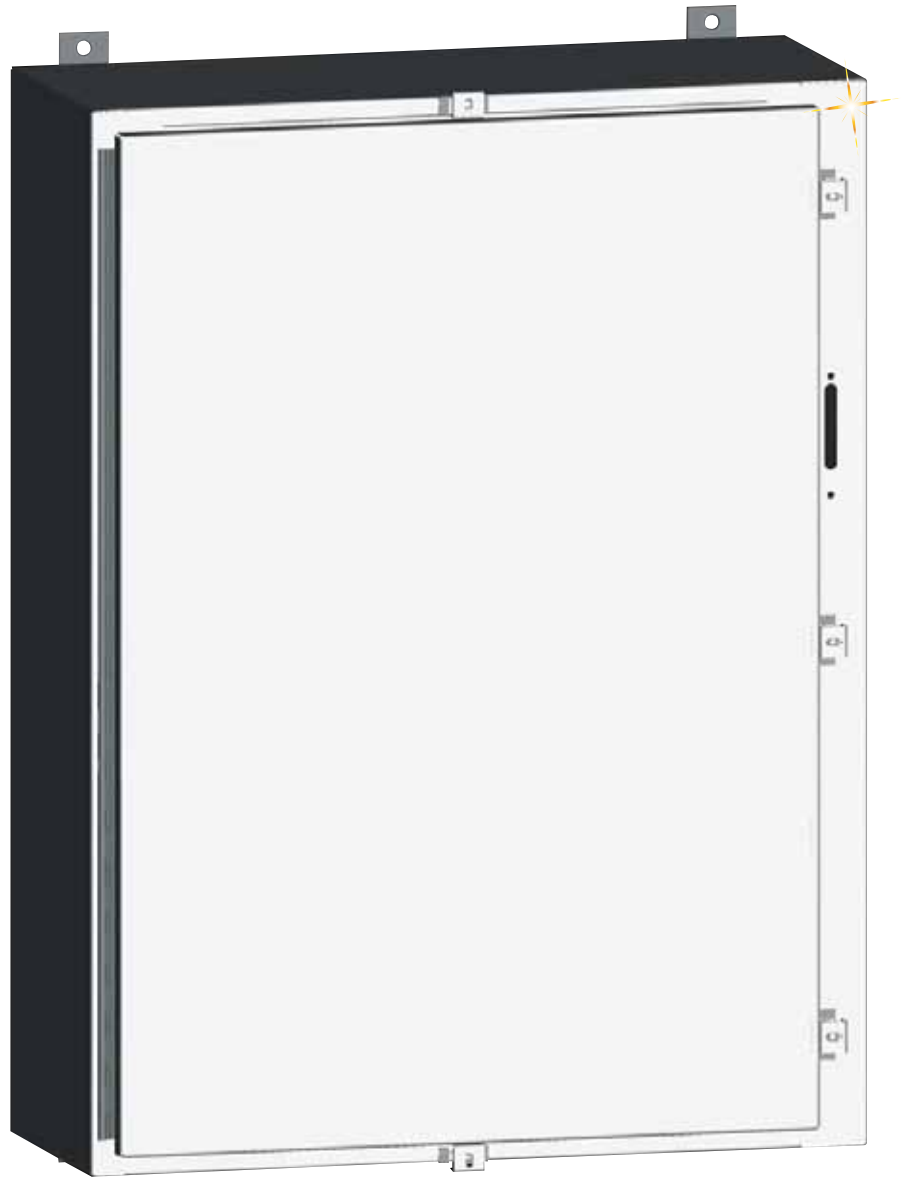

SCE-24HS2108LP shown smaller than actual size.

Application



Disconnect enclosure Type E designed to house most standard type disconnects. For outdoor application a drip shield is recommended.

Finish

ANSI-61 gray powder coating inside and out over phosphatized surfaces. Optional panels are powder coated white.

Industry Standards

NEMA Type 4, 12 & 13
UL Listed Type 4 & 12
CSA Type 4 & 12
IEC 60529 IP 66

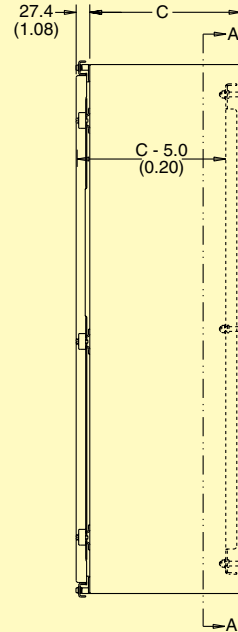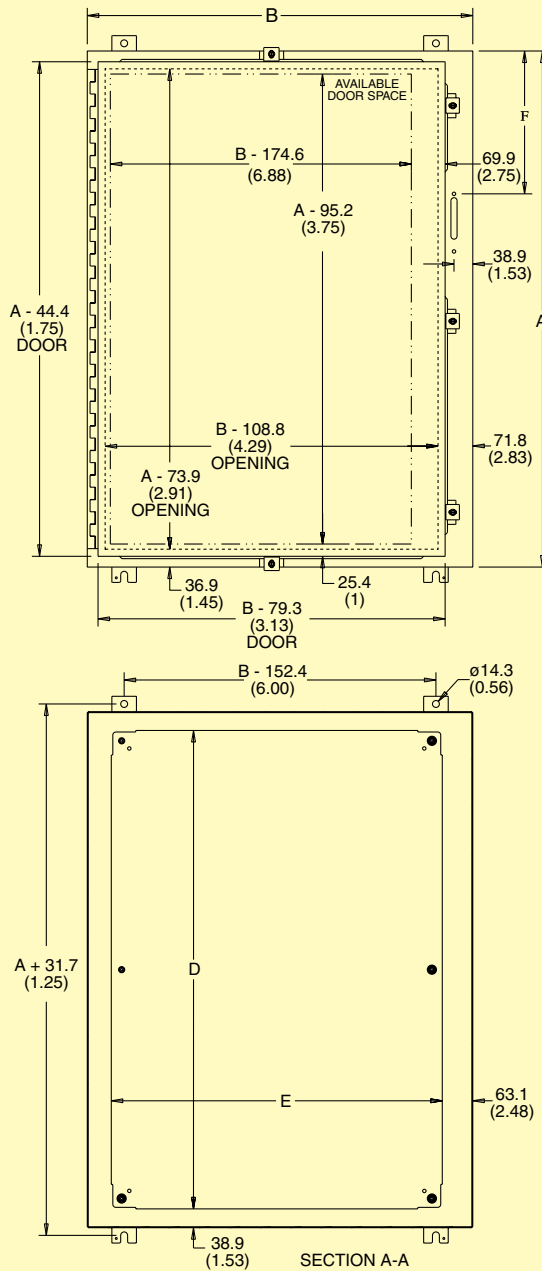

DISCONNECT NOTES:
 F = 219 (8.63) when C = 203 (8.00)
 F = 295 (11.63) when C = 304 (12.00)

CLAMPING NOTE:
 Enclosures > 1117 (44.00) in height
 require a fourth clamp located vertically
 on door

Dimensions: mm (inch)

To Order

TYPE 4 SINGLE-DOOR FLANGE-MOUNTED DISCONNECTS

MODEL NO.	ENCLOSURES (inch)			SUB-PANEL (inch)		
	HEIGHT (A)	WIDTH (B)	DEPTH (C)	MODEL NO.	HEIGHT (D)	WIDTH (E)
SCE-24HS2108LP	24.00	21.38	8.00	SCE-24P20	21.00	17.00
SCE-24HS2508LP	24.00	25.38	8.00	SCE-24P24	21.00	21.00
SCE-30HS2508LP	30.00	25.38	8.00	SCE-30P24	27.00	21.00
SCE-36HS2508LP	36.00	25.38	8.00	SCE-36P24	33.00	21.00
SCE-36HS3108LP	36.00	31.38	8.00	SCE-36P30	33.00	27.00
SCE-36HS3112LP	36.00	31.38	12.00	SCE-36P30	33.00	27.00
SCE-42HS3112LP	42.00	31.38	12.00	SCE-42P30	33.00	27.00
SCE-42HS3712LP	42.00	37.38	12.00	SCE-42P36	39.00	33.00
SCE-48HS3712LP	48.00	37.38	12.00	SCE-48P36	45.00	33.00
SCE-60HS3712LP	60.00	37.38	12.00	SCE-60P36	57.00	33.00

Ordering Examples: SCE-24HS2108LP, Type 4 single-door enclosure for flange-mounted disconnects.
 SCE-36HS3112LP, Type 4 single-door flange-mounted disconnect enclosure, 36 H x 31.38 W x 12" D, SCE-36P30, sub-panel.