




TYPE 4X 304 AND 316 SS TWO-DOOR ENCLOSURES

SCE-HSSLP Series

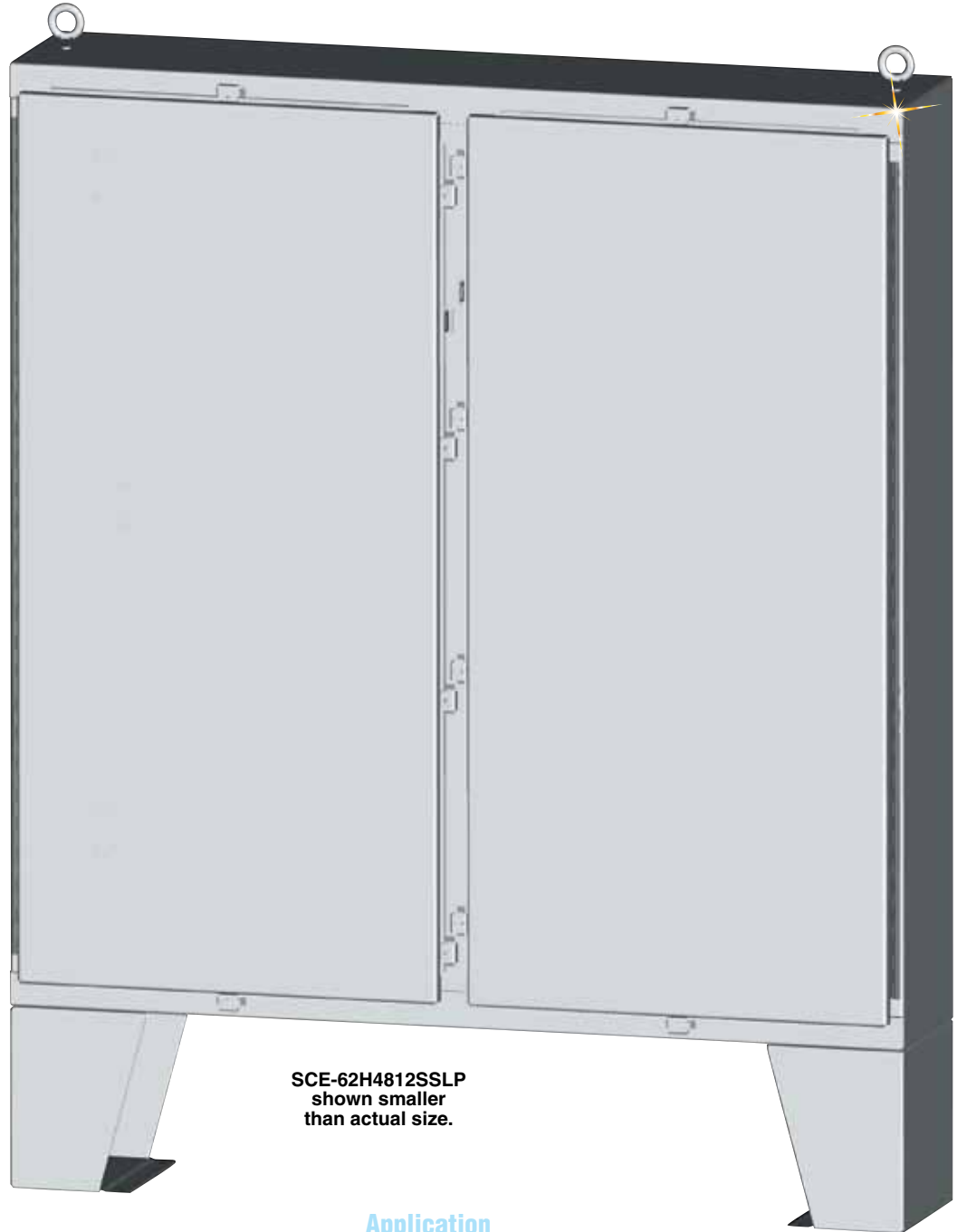

SCE-62H4812SSLP
shown smaller
than actual size.

- 0.104" Stainless Steel Type 304 and 316
- Seams Continuously Welded and Ground Smooth
- Stainless Steel Concealed Hinge
- Flange Trough Collar Around All Sides of Door Opening
- Interior Print Pocket
- Oil-Resistant Gasket
- Ground Stud On Door
- 12" Removable Floor Stands
- Hasp and Staple for Padlocking
- Removable Center Post
- Panel Supports
- Heavy Duty Lifting Eyes
- Stainless Steel Clamps On 3 Sides of Door
- No Door Stiffener Required
- Collar Studs Provided for Mounting Optional Sub-Panels

Application


Designed to house electrical equipment in damp and wet areas, corrosive atmospheres and for outdoor applications. For outdoor application a drip shield is recommended.

Finish

#4 brushed finish on all exterior surfaces. Optional panels are powder coated white.

Industry Standards

NEMA Type 4, 4X, 12 & 13; UL Listed Type 4, 4X & 12; CSA Type 4, 4X & 12; IEC 60529 IP 66

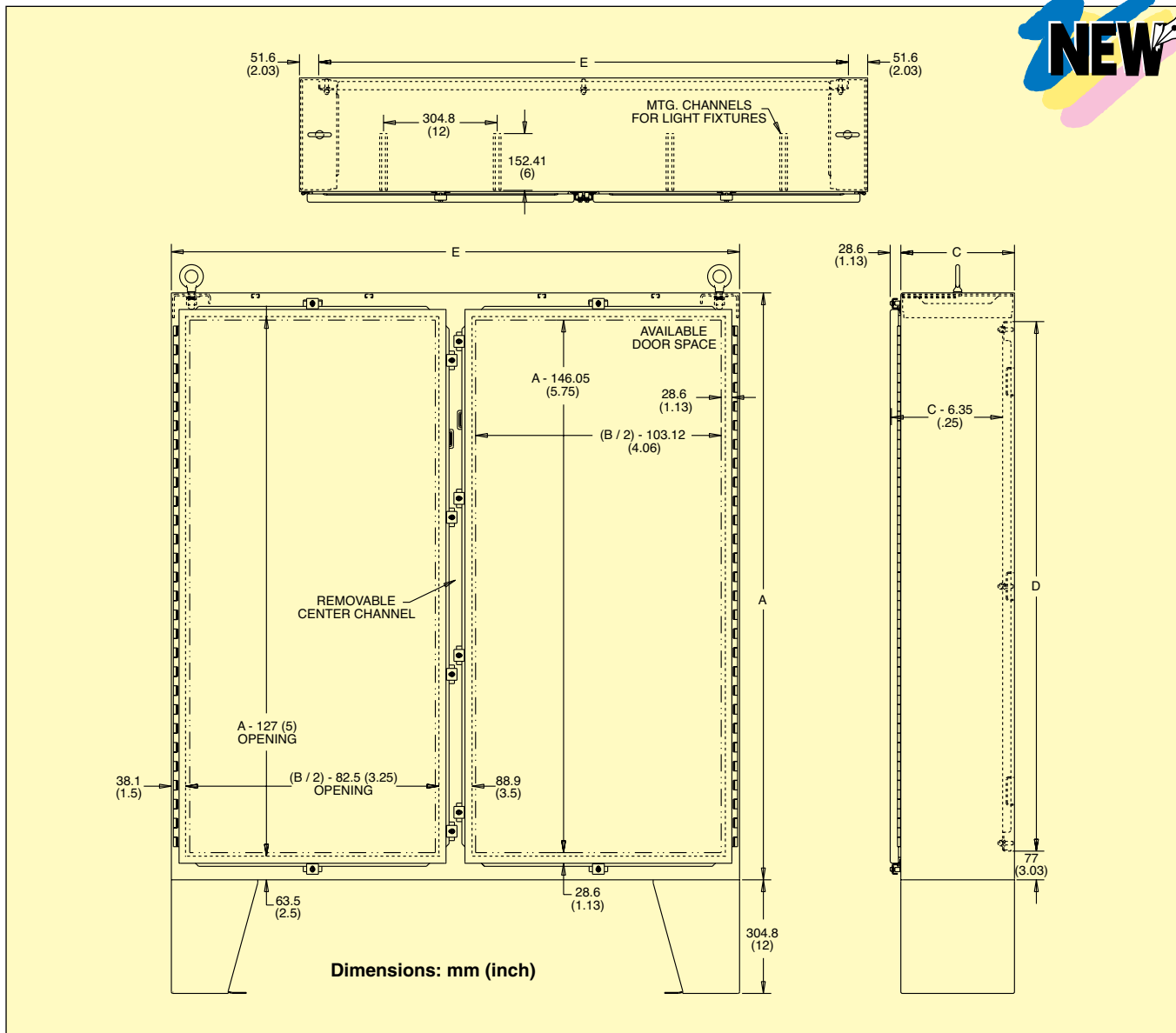

To Order Visit omega.com/sce_sslp2d for Pricing and Details

TYPE 4X TWO-DOOR 304 STAINLESS STEEL ENCLOSURES

ENCLOSURES (inch)				SUB-PANEL (inch)		
MODEL NO.	HEIGHT (A)	WIDTH (B)	DEPTH (C)	MODEL NO.	HEIGHT (D)	WIDTH (E)
SCE-62H4812SSLP	62.00	48.00	12.00	SCE-60P48	56.00	44.00
SCE-62H6012SSLP	62.00	60.00	12.00	SCE-60P60	56.00	56.00
SCE-74H6012SSLP	74.00	60.00	12.00	SCE-72P60	68.00	56.00
SCE-74H7212SSLP	74.00	72.00	12.00	SCE-72P72	68.00	56.00
SCE-74H7224SSLP	74.00	72.00	24.00	SCE-72P72	68.00	68.00

TYPE 4X TWO-DOOR 316 STAINLESS STEEL ENCLOSURES

ENCLOSURES (inch)				SUB-PANEL (inch)		
MODEL NO.	HEIGHT (A)	WIDTH (B)	DEPTH (C)	MODEL NO.	HEIGHT (D)	WIDTH (E)
SCE-62H4812SS6LP	62.00	48.00	12.00	SCE-60P48	56.00	44.00
SCE-62H6012SS6LP	62.00	60.00	12.00	SCE-60P60	56.00	56.00
SCE-74H6012SS6LP	74.00	60.00	12.00	SCE-72P60	68.00	56.00
SCE-74H7212SS6LP	74.00	72.00	12.00	SCE-72P72	68.00	68.00
SCE-74H7224SS6LP	74.00	72.00	24.00	SCE-72P72	68.00	68.00

Ordering Example: SCE-62H4812SSLP Type 4X two-door, 304 stainless steel enclosure.