

NEMA TYPE 4 SINGLE-DOOR ENCLOSURES

SCE-LP Series



- 0.075" Carbon Steel
- Seams Continuously Welded and Ground Smooth, No Holes or Knockouts
- Flange Trough Collar Around All Sides of Door Opening
- Door Clamps Are Quick and Easy to Operate
- Concealed Hinge
- Hasp and Staple for Padlocking
- Oil Resistant Gasket
- Collar Studs for Mounting Optional Panels
- Ground Stud on Door
- Removable Print Pocket Furnished if Height and Width of Enclosure is 24" or More



SCE-161206LP shown smaller than actual size.

Application

Designed to house electrical and electronic controls, instruments, and components. For use indoors or outdoors, provides protection from dust, dirt, oil and water.




Finish

ANSI-61 recoatable gray finish. Optional panels are powder coated white.

Industry Standard, IS2

NEMA Type 4, 12 and 13
UL Listed Type 4 and 12
CSA Type 4 and 12
IEC 60529 IP 66

B - 152.4
(6)

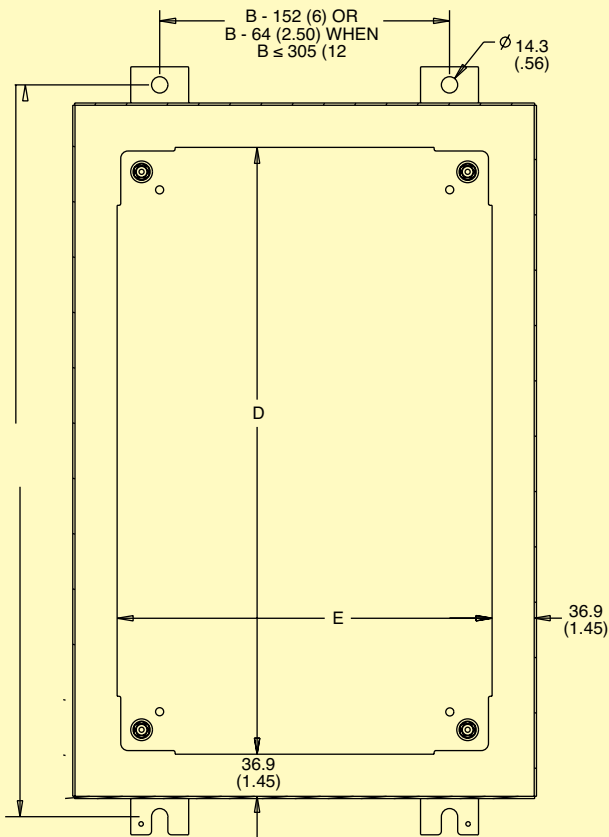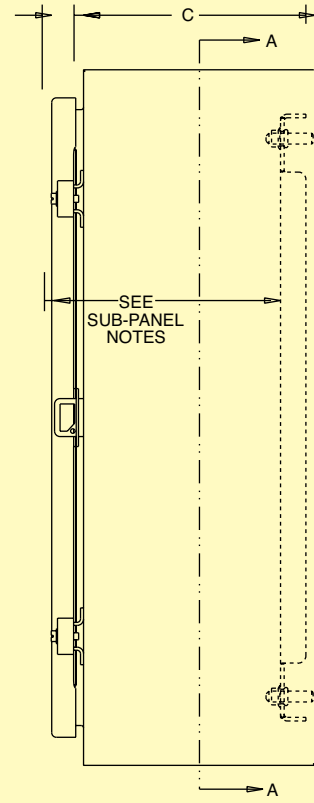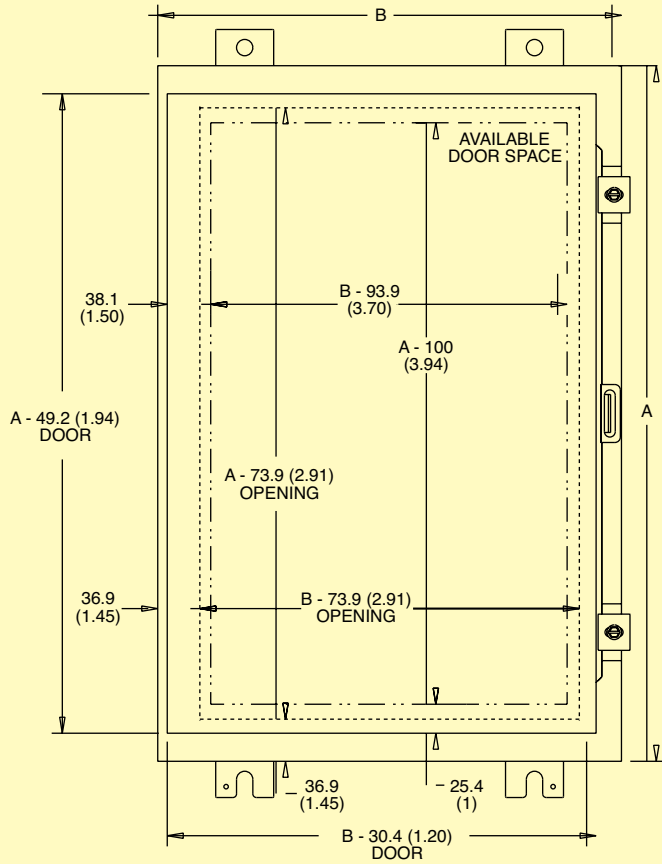

SECTION A-A

SUB-PANEL NOTES:
Dimensions are from the inside of the door
C + 8.1 (.32) for flat sub-panels
C - 4.5 (.18) for bent sub-panels

CLAMPING NOTE:
Enclosures > 610 (24) in height
require a third clamp centered vertically
on door

Dimensions: mm (inch)

To Order

TYPE 4 SINGLE-DOOR ENCLOSURES

ENCLOSURES (inch)				SUB-PANEL (inch)		
MODEL NO.	HEIGHT (A)	WIDTH (B)	DEPTH (C)	MODEL NO.	HEIGHT (D)	WIDTH (E)
SCE-122406LP	12.00	24.00	6.00	SCE-12P24	9.00	21.00
SCE-122408LP	12.00	24.00	8.00	SCE-12P24	9.00	21.00
SCE-161206LP	16.00	12.00	6.00	SCE-16P12	13.00	9.00
SCE-161208LP	16.00	12.00	8.00	SCE-16P12	13.00	9.00
SCE-161210LP	16.00	12.00	10.00	SCE-16P12	13.00	9.00
SCE-161606LP	16.00	16.00	6.00	SCE-16P16	13.00	13.00
SCE-161608LP	16.00	16.00	8.00	SCE-16P16	13.00	13.00
SCE-162006LP	16.00	20.00	6.00	SCE-20P16	17.00	13.00
SCE-162008LP	16.00	20.00	8.00	SCE-20P16	17.00	13.00
SCE-201206LP	20.00	12.00	6.00	SCE-20P12	17.00	9.00
SCE-201208LP	20.00	12.00	8.00	SCE-20P12	17.00	9.00
SCE-201606LP	20.00	16.00	6.00	SCE-20P16	17.00	13.00
SCE-201608LP	20.00	16.00	8.00	SCE-20P16	17.00	13.00
SCE-201610LP	20.00	16.00	10.00	SCE-20P16	17.00	13.00
SCE-201612LP	20.00	16.00	12.00	SCE-20P16	17.00	13.00
SCE-202006LP	20.00	20.00	6.00	SCE-20P20	17.00	17.00
SCE-202008LP	20.00	20.00	8.00	SCE-20P20	17.00	17.00
SCE-202010LP	20.00	20.00	10.00	SCE-20P20	17.00	17.00
SCE-202406LP	20.00	24.00	6.00	SCE-24P20	21.00	17.00
SCE-202408LP	20.00	24.00	8.00	SCE-24P20	21.00	17.00
SCE-203006LP	20.00	30.00	6.00	SCE-30P20	27.00	17.00
SCE-241206LP	24.00	12.00	6.00	SCE-12P24	9.00	21.00
SCE-241208LP	24.00	12.00	8.00	SCE-12P24	9.00	21.00
SCE-241210LP	24.00	12.00	10.00	SCE-12P24	9.00	21.00
SCE-241606LP	24.00	16.00	6.00	SCE-24P16	21.00	13.00
SCE-241608LP	24.00	16.00	8.00	SCE-24P16	21.00	13.00
SCE-242006LP	24.00	20.00	6.00	SCE-24P20	21.00	17.00
SCE-242008LP	24.00	20.00	8.00	SCE-24P20	21.00	17.00
SCE-242010LP	24.00	20.00	10.00	SCE-24P20	21.00	17.00
SCE-242012LP	24.00	20.00	12.00	SCE-24P20	21.00	17.00
SCE-242016LP	24.00	20.00	16.00	SCE-24P20	21.00	17.00
SCE-242406LP	24.00	24.00	6.00	SCE-24P24	21.00	21.00
SCE-242408LP	24.00	24.00	8.00	SCE-24P24	21.00	21.00
SCE-242410LP	24.00	24.00	10.00	SCE-24P24	21.00	21.00
SCE-242412LP	24.00	24.00	12.00	SCE-24P24	21.00	21.00
SCE-242416LP	24.00	24.00	16.00	SCE-24P24	21.00	21.00
SCE-243008LP	24.00	30.00	8.00	SCE-30P24	27.00	21.00
SCE-301606LP	30.00	16.00	6.00	SCE-30P16	27.00	13.00
SCE-302006LP	30.00	20.00	6.00	SCE-30P20	27.00	17.00
SCE-302008LP	30.00	20.00	8.00	SCE-30P20	27.00	17.00
SCE-302010LP	30.00	20.00	10.00	SCE-30P20	27.00	17.00
SCE-302406LP	30.00	24.00	6.00	SCE-30P24	27.00	21.00
SCE-302408LP	30.00	24.00	8.00	SCE-30P24	27.00	21.00
SCE-302410LP	30.00	24.00	10.00	SCE-30P24	27.00	21.00
SCE-302412LP	30.00	24.00	12.00	SCE-30P24	27.00	21.00
SCE-302416LP	30.00	24.00	16.00	SCE-30P24	27.00	21.00
SCE-302420LP	30.00	24.00	20.00	SCE-30P24	27.00	21.00

TYPE 4 SINGLE-DOOR ENCLOSURES (CONTINUED)						
ENCLOSURES (inch)				SUB-PANEL (inch)		
MODEL NO.	HEIGHT (A)	WIDTH (B)	DEPTH (C)	MODEL NO.	HEIGHT (D)	WIDTH (E)
SCE-302424LP	30.00	24.00	24.00	SCE-30P24	27.00	21.00
SCE-303008LP	30.00	30.00	8.00	SCE-30P30	27.00	27.00
SCE-303012LP	30.00	30.00	12.00	SCE-30P30	27.00	27.00
SCE-303608LP	30.00	36.00	8.00	SCE-36P30	33.00	27.00
SCE-361606LP	36.00	16.00	6.00	SCE-36P16	33.00	13.00
SCE-362406LP	36.00	24.00	6.00	SCE-36P24	33.00	21.00
SCE-362408LP	36.00	24.00	8.00	SCE-36P24	33.00	21.00
SCE-362410LP	36.00	24.00	10.00	SCE-36P24	33.00	21.00
SCE-362412LP	36.00	24.00	12.00	SCE-36P24	33.00	21.00
SCE-362416LP	36.00	24.00	16.00	SCE-36P24	33.00	21.00
SCE-363006LP	36.00	30.00	6.00	SCE-36P30	33.00	27.00
SCE-363008LP	36.00	30.00	8.00	SCE-36P30	33.00	27.00
SCE-363010LP	36.00	30.00	10.00	SCE-36P30	33.00	27.00
SCE-363012LP	36.00	30.00	12.00	SCE-36P30	33.00	27.00
SCE-363016LP	36.00	30.00	16.00	SCE-36P30	33.00	27.00
SCE-363020LP	36.00	30.00	20.00	SCE-36P30	33.00	27.00
SCE-363608LP	36.00	36.00	8.00	SCE-36P36	33.00	33.00
SCE-363612LP	36.00	36.00	12.00	SCE-36P36	33.00	33.00
SCE-363616LP	36.00	36.00	16.00	SCE-36P36	33.00	33.00
SCE-422408LP	42.00	24.00	8.00	SCE-42P24	39.00	21.00
SCE-423008LP	42.00	30.00	8.00	SCE-42P30	39.00	27.00
SCE-423010LP	42.00	30.00	10.00	SCE-42P30	39.00	27.00
SCE-423012LP	42.00	30.00	12.00	SCE-42P30	39.00	27.00
SCE-423016LP	42.00	30.00	16.00	SCE-42P30	39.00	27.00
SCE-423608LP	42.00	36.00	8.00	SCE-42P36	39.00	33.00
SCE-423610LP	42.00	36.00	10.00	SCE-42P36	39.00	33.00
SCE-423612LP	42.00	36.00	12.00	SCE-42P36	39.00	33.00
SCE-423616LP	42.00	36.00	16.00	SCE-42P36	39.00	33.00
SCE-482408LP	48.00	24.00	8.00	SCE-48P24	45.00	21.00
SCE-483008LP	48.00	30.00	8.00	SCE-48P30	45.00	27.00
SCE-483010LP	48.00	30.00	10.00	SCE-48P30	45.00	27.00
SCE-483016LP	48.00	30.00	16.00	SCE-48P30	45.00	27.00
SCE-483608LP	48.00	36.00	8.00	SCE-48P36	45.00	33.00
SCE-483610LP	48.00	36.00	10.00	SCE-48P36	45.00	33.00
SCE-483612LP	48.00	36.00	12.00	SCE-48P36	45.00	33.00
SCE-483616LP	48.00	36.00	16.00	SCE-48P36	45.00	33.00
SCE-483620LP	48.00	36.00	20.00	SCE-48P36	45.00	33.00
SCE-603608LP	60.00	36.00	8.00	SCE-60P36	57.00	33.00
SCE-603610LP	60.00	36.00	10.00	SCE-60P36	57.00	33.00
SCE-603612LP	60.00	36.00	12.00	SCE-60P36	57.00	33.00
SCE-603616LP	60.00	36.00	16.00	SCE-60P36	57.00	33.00
SCE-603620LP	60.00	36.00	20.00	SCE-60P36	57.00	33.00
SCE-723012LP	72.00	30.00	12.00	SCE-72P30	69.00	27.00
SCE-723016LP	72.00	30.00	16.00	SCE-72P30	69.00	27.00
SCE-723024LP	72.00	30.00	24.00	SCE-72P30	69.00	27.00
SCE-723612LP	72.00	36.00	12.00	SCE-72P36	69.00	33.00
SCE-723616LP	72.00	36.00	16.00	SCE-72P36	69.00	33.00

Ordering Examples: SCE-161206LP Type 4, single-door enclosure.

SCE-201206LP Type 4, single-door enclosure, 20 H x 12 W x 6" D, SCE-20P12, sub-panel.