



Feed Through Terminal Blocks



YBK-4T, shown actual size.

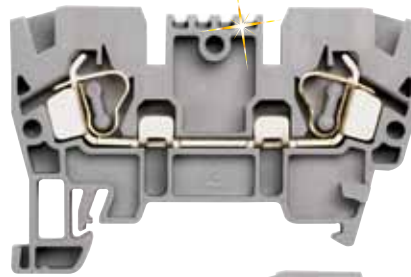

YBK-4, shown actual size.

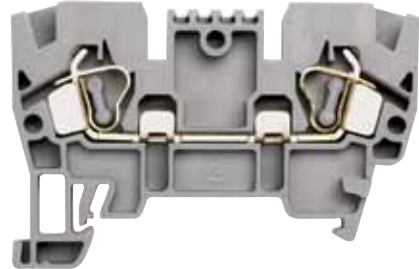

YBK Series



- ✔ Tension Clamp for Fast Wire Termination and Reliable Secure Connection
- ✔ 600V Rated, UL 94 V2 Polyamide 6.6
- ✔ Full Line of Accessories: End Plates, Cross Connectors and Marking Tags
- ✔ Stocked in Colors Gray, Blue and Red; Also Available in Yellow, Beige and Green

YBK Series feed through terminal blocks are tension clamp connection style and are DIN rail mounted. The tension clamp can easily be opened with a small screwdriver inserted next to the wire entry, then slip in the field wire and remove the screwdriver for a reliable and secure connection.

The YBK terminal blocks come in all wire ranges and no pre-treatment of the wire is necessary, even for stranded wire. A full line of accessories are available including end plates, end brackets, cross connectors and marking tags. The YBK series also includes 4 size grounding terminal blocks.

Specifications

Electrical Ratings	YBK-2.5	YBK-4	YBK-6	YBK-10
Voltage/Current	750V/22 A	750V/30 A	750V/40 A	750V/63 A
UL	600V/20 A	600V/26 A	600V/35 A	600V/55 A
Insulation Strip length	10 mm	12 mm	13 mm	13 mm
AWG	22-12	22-10	22-8	20-6
Width	5 mm	6 mm	8 mm	10 mm
End Plate-Partition	YBK-EP-2.5	YBK-EP-4	YBK-EP-6	YBK-EP-10
Cross-Connectors/2	OM-476222	OM-476232	OM-476242	OM-476252
Cross-Connectors/3	OM-476223	OM-476233	OM-476243	OM-476253
Cross-Connectors/4	OM-476224	OM-476234	OM-476244	OM-476254
Cross-Connectors/10	OM-476229	OM-476239	OM-476249	OM-476259
Ground Tension Clamp Terminal Blocks				
Electrical Ratings	YBK-2.5T	YBK-4T	YBK-6T	YBK-10T
Voltage/Current	750V/22 A	750V/30 A	750V/40 A	750V/63 A
UL	600V/20 A	600V/26 A	600V/35 A	600V/55 A
Insulation Strip Length	10 mm	12 mm	13 mm	13 mm
AWG	22-12	22-10	22-8	20-6
Width	5 mm	6 mm	8 mm	10 mm
End Plate-Partition	YBK-254T-EP	YBK-254T-EP	YBK-6T-EP	YBK-10T-EP



OM-476224 shown larger than actual size.

To Order

Feed Through Terminal Blocks

Model No.	Amps	AWG	Description
YBK-2.5	20	22-12	Feed through tension clamp terminal block
YBK-2.5	20	22-12	Feed through tension clamp terminal block
YBK-4	26	22-10	Feed through tension clamp terminal block
YBK-4	26	22-10	Feed through tension clamp terminal block
YBK-6	35	22-8	Feed through tension clamp terminal block
YBK-6	35	22-8	Feed through tension clamp terminal block
YBK-10	55	20-6	Feed through tension clamp terminal block
YBK-10	55	20-6	Feed through tension clamp terminal block
YBK-EP-2.5			End plate-partition for YBK-2.5
YBK-EP-4			End plate-partition for YBK-4
YBK-EP-6			End plate-partition for YBK-6
YBK-EP-10			End plate-partition for YBK-10
YBK-2.5T		22-12	Ground terminal block
YBK-4T		22-10	Ground terminal block
YBK-6T		22-8	Ground terminal block
YBK-10T		20-6	Ground terminal block
YBK-254T-EP			End plate for YBK-2.5T and 4T ground terminal
YBK-6T-EP			End plate for YBK-6T ground terminal
YBK-10T-EP			End plate for YBK-10T ground terminal
T-BLK-EB			DIN rail end bracket

Note: Add "-R" for red and "-B" for blue colored terminal blocks, no additional charge.

Accessories

Cross Connectors

Model No.	Positions	Model No.	Positions
OM-476222	2	OM-476242	2
OM-476223	3	OM-476243	3
OM-476224	4	OM-47624z4	4
OM-476229	10	OM-476249	10
OM-476232	2	OM-476252	2
OM-476233	3	OM-476253	3
OM-476234	4	OM-476254	4
OM-476239	10	OM-476259	10

Marking Tags

Model No.	Pcs/per card	Description
MKR-NO-PRINT	50	Marking tag without print
MKR-1-10	50	Marking tag 1 to 10
MKR-11-20	50	Marking tag 11 to 20
MKR-1-50	50	Marking tag 1 to 50
MKR-51-100	50	Marking tag 51 to 100
MKR-101-150	50	Marking tag 101 to 150
MKR-151-200	50	Marking tag 151 to 200
MKR-201-250	50	Marking tag 201 to 250

Ordering Examples: YBK-2.5, feed through tension clamp terminal block to 12 AWG wire, rated at 20 A, and YBK-EP-2.5, end plate for YBK-2.5 terminal.

YBK-2.5T, feed through ground terminal, and YBK-254T-EP, end plate partition for YBK-2.5T terminal.