

BENCHTOP DISSOLVED OXYGEN METERS




Model DOB-343

\$955

- ✓ For Saturation and Concentration Measurement
- ✓ Automatic Temperature Compensation
- ✓ Recorder Output
- ✓ Battery or AC Power Adaptor

Shown Smaller Than Actual Size

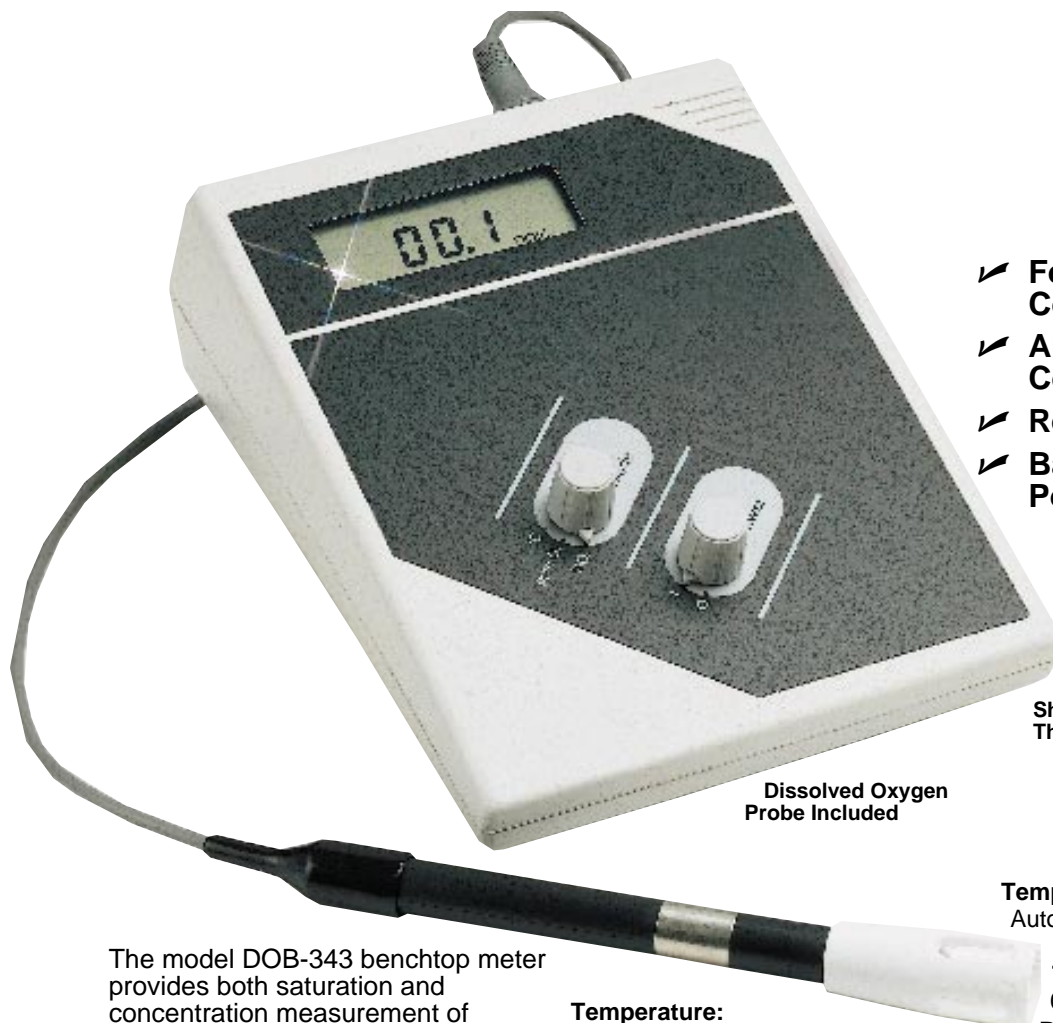

Dissolved Oxygen Probe Included

The model DOB-343 benchtop meter provides both saturation and concentration measurement of dissolved oxygen levels. The respective measuring ranges are 0-199.9% and 0-19.9 ppm. The sensor is a MacKareth type, and replacement capsules are easily installed. Automatic temperature compensation is provided by a thermistor located in the oxygen probe. Calibration is achieved by one adjustment made at any temperature which sets both percentage saturation and concentration readings. A recorder output is standard to facilitate recordkeeping. The DOB-343 comes complete with probe assembly, sensor capsule, stirrer bar, guard shield and ac power adaptor. An optional temperature probe is available for making temperature measurements. (Meter reads in °C only.)

SPECIFICATIONS

Measuring Ranges

% Saturation: 0 to 199.9 %
Concentration: 0 to 19.9 ppm

Temperature: -5 to 50°C (23 to 122°F)
Accuracy:
Saturation: ±2%
Concentration: ±0.2 ppm
Temperature: ±0.5°C (±0.9°F)

Temperature Compensation: Automatic with thermistor (0 to 50°C/32 to 122°F)
Temperature Resolution: 0.1°C (0.2°F)
Recorder Output: 0 to 200 mV
Power Supply: 9 V battery (1) or ac power adaptor
Meter Dimensions: 211 L x 152 W x 89 mm H (8.3 x 6 x 3.5")
Meter Weight: 600 g (1.32 lb)

To Order (Specify Model Number)

Model No.	Price	Description
DOB-343	\$955	Dissolved oxygen meter and accessories

Includes probe assembly, sensor capsule, stirrer bar, guard shield, ac power adaptor and operator's manual.

Ordering Example: DOB-343, dissolved oxygen measurement kit, and PHAT-343, temperature probe, \$955 + 80 = \$1035

Replacement Accessories

Model No.	Price	Description
PHOX-343	\$185	Probe assembly
PHAC-343	140	Sensor capsule for PHOX-343

Optional Accessory

Model No.	Price	Description
PHAT-343	\$80	Temperature probe



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters