

# ECONOMICAL PURGE ROTAMETERS

CAPACITIES: 0.1 to 20 GPH of Water,

0.5 to 100 SCFH of Air

**DISCONTINUED**


FL-1000 Series

**\$115**

All Models



- ✓ ±10% Full Scale Accuracy
- ✓ ±1% Full Scale Repeatability
- ✓ Low Pressure Drop
- ✓ Polycarbonate Construction
- ✓ Direct Reading Scales for Air and Water
- ✓ Fully Rotatable Line Connectors for Easy Hookup
- ✓ Convenient Panel Mounting
- ✓ Integral Flow Control Valve

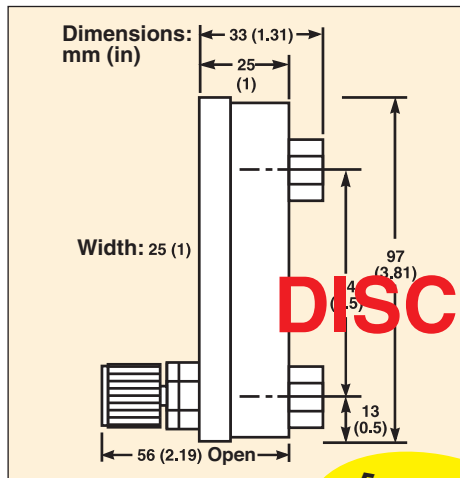

**DISCONTINUED**

For correlation with other fluids, see page B-8.



Many fittings of various materials and styles are available. See pages T-35 to T-66.

**DISCONTINUED**

FL-1006 shown with standard mounting bracket (included) \$115, shown actual size.

**DISCONTINUED**

Advanced concepts and design at a very low cost—that's the OMEGA® FL-1000 Series of flowmeters, made of high-impact polycarbonate.

These units are designed to provide a practical approach to low flow rate indication of non-corrosive liquids and gases at the lowest possible cost. The FL-1000 Series flowmeter is equipped with a standard flow control valve. The FL-1000 flowmeter features a single unit polycarbonate tube, bezel and integral float stops for high impact resistance, with easy-to-read design, and ribbed tube construction for increased performance.

## SPECIFICATIONS

**Meter Body, Clean-Out Plug, Float Stop:** FDA Approved Polycarbonate

**Floats:** 316 Stainless Steel (spherical)

**O-Rings:** Buna

**Line Connectors:** Stainless Steel

**Valve:** Stainless Steel

## Scales

**Nominal Length:** 37 mm (1.46")

**Display:** Direct reading for air or water

## Ratings

**Maximum Operating Pressure:** 100 psig

**Operating Temperature:** -29 to 54°C (-20 to 130°F). Fluid temperatures below 0°C (32°F) can cause frosting of plastic meter body

**Connections:** 1/8 FNPT, horizontal (inlet and outlet); fully rotatable

## Flush Panel Mount Cutout:

94 x 24 mm (3.72 x .94")

**Max Panel Thickness:** 4.76 mm (3/16")

## Pressure Drop:

FL-1002: 96" water

FL-1004: 136" water

FL-1006: 191" water

**Accuracy:** ±10% full scale

**Repeatability:** ±1% full scale

**DISCONTINUED**

**AVAILABLE FOR FAST DELIVERY!**

## To Order (Specify Model Number)

Air Model No.	Price	Range (SCFH)	Water Model No.	Price	Range (GPH)
FL-1002	\$115	0.5 to 5.5	FL-1012	\$115	0.1 to 1.1
FL-1004	115	2.0 to 20	FL-1014	115	0.5 to 4.5
FL-1006	115	10 to 100	FL-1016	115	2.0 to 20

Comes complete with operator's manual and mounting bracket.

**Ordering Examples:** FL-1002, air rotameter with 0.5 to 5.5 range, \$115.

FL-1014, water rotameter with 0.5 to 4.5 GPH, 316 SS, \$115.

**DISCONTINUED**

Recommended Reference Book: Flow Measurement Engineering Handbook, OP-9, \$145. See Section Y for Additional Books.



**DISCONTINUED**



#### UNITED STATES

[www.omega.com](http://www.omega.com)  
1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)  
Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)  
Deckenpfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)  
Manchester, England  
0800-488-488

#### FRANCE

[www.omega.fr](http://www.omega.fr)  
Guyancourt, France  
088-466-342

#### CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)  
Karviná, Czech Republic  
596-311-899

#### BENELUX

[www.omega.nl](http://www.omega.nl)  
Amstelveen, NL  
0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters