

POINT LEVEL SENSORS

Drum Level Indicators

LV-110 Series

- ✓ Compatible with Most Liquids and Chemicals
- ✓ Models Rated to Maximum 750 psi
- ✓ Drum Level Indicators Require No Electricity

The LV-110 Series drum level indicators are compact, self-contained liquid-level indicators designed for use in 55-gallon drums. A magnet-equipped float senses level, and the user can obtain a readout by removing the protective cap and reading the indicator measuring tape. LV-110 units can be used in either horizontal or vertical drums.

SPECIFICATIONS

Temperature Range:

316 SS: -40 to 149°C (-40 to 300°F)


Brass/Buna: To 82°C (180°F) in water, -40 to 110°C (-40 to 230°F) in oil

Pressure Rating: 750 psi for 316 SS float; 300 psi for Buna floats

Mounting: 2 NPT

Tube/Fitting Size: ½" OD tube

Mounting Attitude: Vertical ±30°

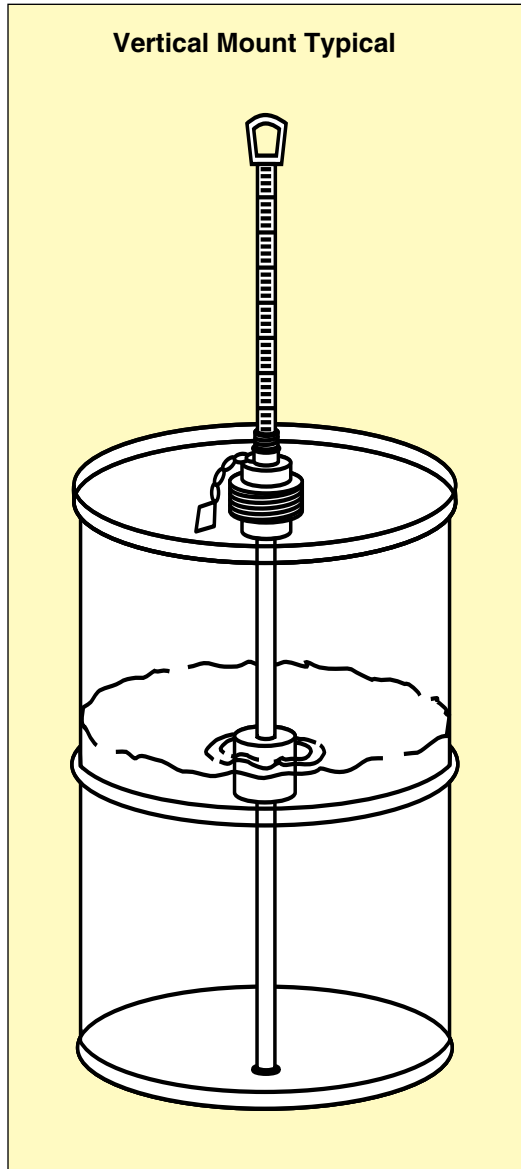

LV-113 shown smaller than actual size.



To Order			
Model No.	Length (L) Drum Position (inch)	Stem/Float	Float Specific Gravity
LV-110	22 horizontal	Brass/Buna	0.48
LV-111	22 horizontal	316 SS	0.64
LV-112	33 vertical	Brass/Buna	0.48
LV-113	33 vertical	316 SS	0.64
LV-115	33 vertical	PVC	0.8

Ordering Example: LV-113, 316 SS drum level indicator, 33" vertical.