

OMEGAFLEX®

COILED POLYURETHANE HOSE


with Strain Relief Fittings

OCH Series

- ✓ Made with Polyurethane Tubing
- ✓ Resists Abrasion and Kinking
- ✓ 6.4 mm (¼") Strain Relief Fitting on Each End—1 Rigid and 1 Swivel
- ✓ Ideal for Use with Air Tools
- ✓ Retractable Coil Returns to its Original Shape to Keep Areas Organized and Safe
- ✓ Variety of Colors to Choose From—Blue, Yellow, Green, and Red

The OMEGAFLEX coiled hose assembly with strain relief fittings offers the perfect solution to keep work areas free of loose supply hoses that can tangle and create a mess. These are manufactured with 10 mm (¾") OD by 6.4 mm (¼") ID polyurethane tubing. Each assembly comes with a 6.4 mm (¼") fitting on each side; one rigid and one swivel. For ease of identification when incorporating several hose assemblies we offer different colors: Blue, Red, Green, and Yellow.

OCH-3814-5-A-BL shown smaller than actual size.

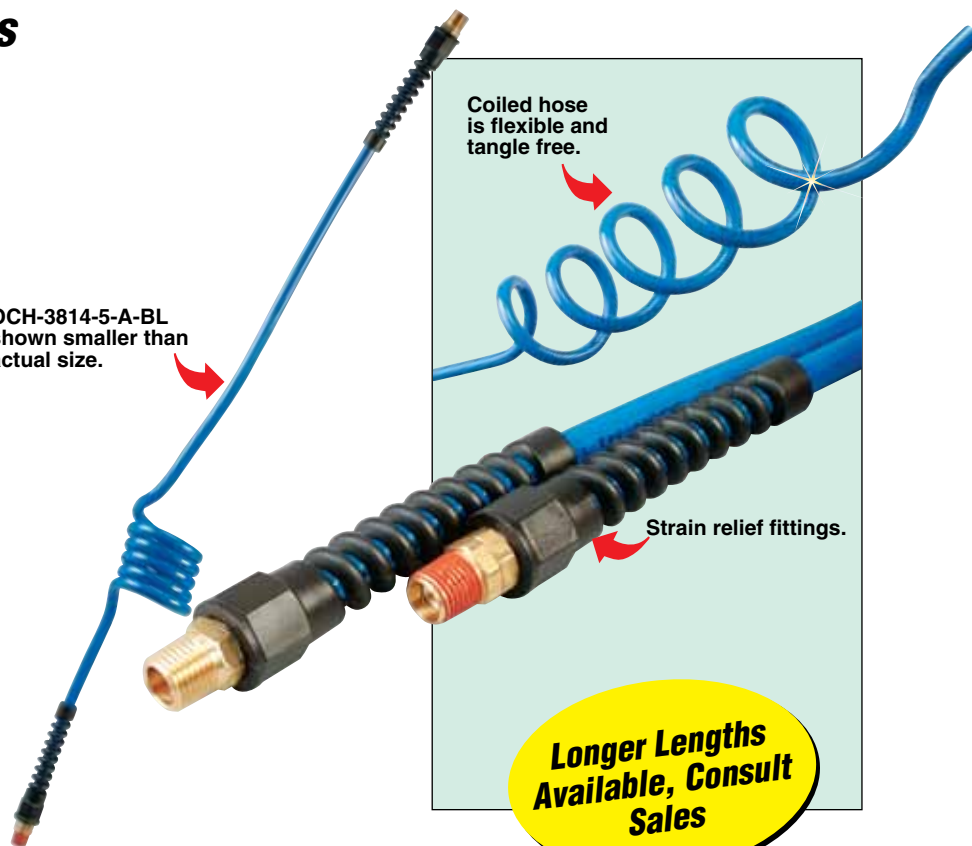

SPECIFICATIONS

Temperature Range: -40 to 52°C (-40 to 125°F)
Vacuum Rating: To 28" Hg
Working Pressure: 3:1 Safety factor
Working Length: 80 to 90% of material length

Color Options

Code	Color
-Y	Yellow
-GN	Green
-BL	Blue
-R	Red

Coiled Hose

To Order

Model No.	Color	Material Length m (ft)	Working Length m (ft)	Retracted Length mm (inch)	Coiled OD mm (inch)	Weight g (lbs)
OCH-3814-5-A-GN	Green	1.5 (5)	1.2 (4)	63.5 (2.5)	63.5 (2.5)	104 (0.23)
OCH-3814-10-A-GN	Green	3.0 (10)	2.4 (8)	152.4 (6)	63.5 (2.5)	186 (0.41)
OCH-3814-15-A-GN	Green	4.6 (15)	3.8 (12.5)	241.3 (9.5)	63.5 (2.5)	268 (0.59)
OCH-3814-5-A-R	Red	1.5 (5)	1.2 (4)	63.5 (2.5)	63.5 (2.5)	104 (0.23)
OCH-3814-10-A-R	Red	3.0 (10)	2.4 (8)	152.4 (6)	63.5 (2.5)	186 (0.41)
OCH-3814-15-A-R	Red	4.6 (15)	3.8 (12.5)	241.3 (9.5)	63.5 (2.5)	268 (0.59)
OCH-3814-5-A-Y	Yellow	1.5 (5)	1.2 (4)	63.5 (2.5)	63.5 (2.5)	104 (0.23)
OCH-3814-10-A-Y	Yellow	3.0 (10)	2.4 (8)	152.4 (6)	63.5 (2.5)	186 (0.41)
OCH-3814-15-A-Y	Yellow	4.6 (15)	3.8 (12.5)	241.3 (9.5)	63.5 (2.5)	268 (0.59)
OCH-3814-5-A-BL	Blue	1.5 (5)	1.2 (4)	63.5 (2.5)	63.5 (2.5)	104 (0.23)
OCH-3814-10-A-BL	Blue	3.0 (10)	2.4 (8)	152.4 (6)	63.5 (2.5)	186 (0.41)
OCH-3814-15-A-BL	Blue	4.6 (15)	3.8 (12.5)	241.3 (9.5)	63.5 (2.5)	268 (0.59)

Note: Specifications listed are meant only as a guide. Each user must test the tubing under their operating conditions to determine the tubing's suitability for the particular application. Refer to the color options chart for color codes.

Ordering Examples: OCH-3814-10-A-Y, OMEGAFLEX coiled hose, 3 m (10') material length, yellow.

OCH-3814-5-A-R, OMEGAFLEX coiled hose, 1.5 m (5') material length, red.