




Handheld Portable pH/mV Meter

PHH-152

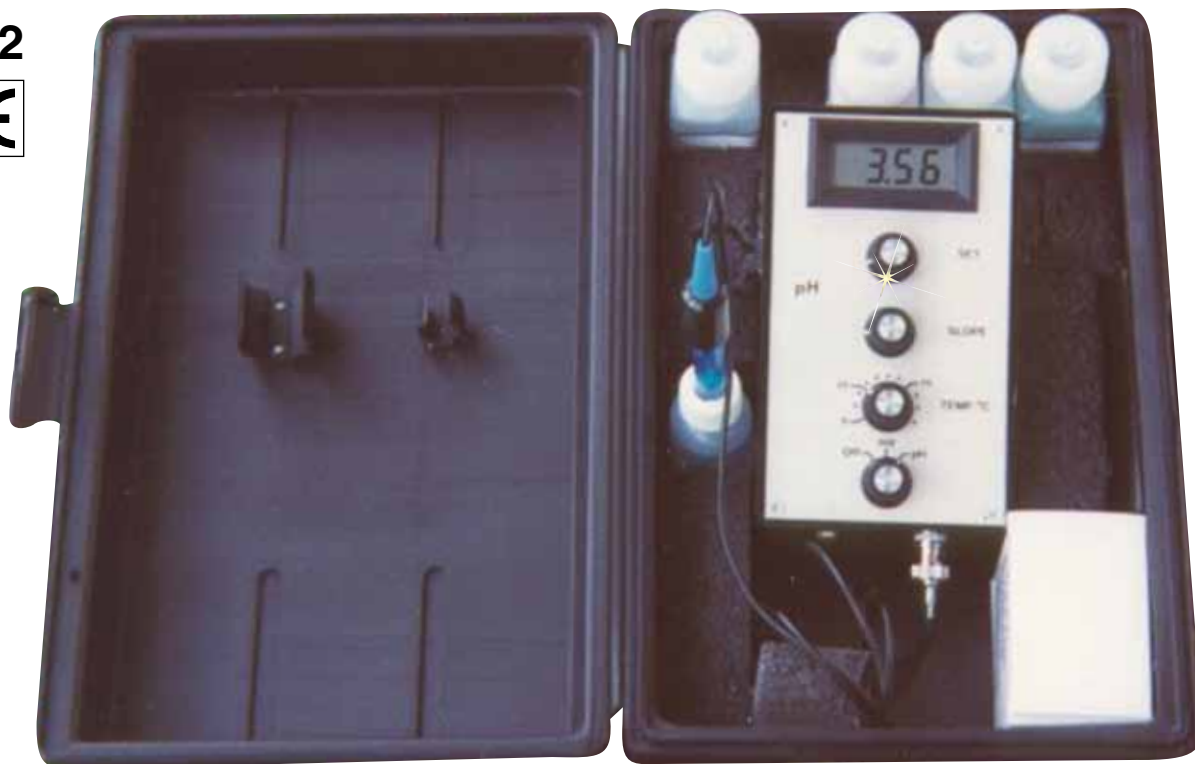

PHH-152 kit shown smaller than actual size.

- ✓ Easy to Use
- ✓ Complete Kit with Rugged Carrying Case
- ✓ 4 pH Sample Size Buffer Solutions Included
- ✓ Precision Electrode Included
- ✓ Economical Price

Specifications

Instrument

Range: 0 to 14 pH / ± 1999 mV

Accuracy: ± 0.02 pH / ± 2 mV

Resolution: 0.1 pH / 1 mV

Display: 3½ Digit LCD, 1.3 cm (0.5") tall

Temperature Comp: Manual

Temperature Range: 0 to 100°C (32 to 212°F)

Power: 8 "AA" NiCad rechargeable batteries (included)

Battery Life: 400 Hours

Power Adaptor/ Recharger: Included

Dimensions: 15 H x 7.6 W x 5 cm D (6 x 3 x 2")

Weight: 1.8 kg (4 lb)

Electrode Type: General purpose

Electrode Connection: BNC

pH Probe Dimensions:

12.5 mm (½") Diameter,

150 mm (5") long with 1.8 m (6') cable

The PHH-152 measures the pH/mV of most solutions. The meter includes all the functions necessary for precise and accurate pH/mV measurements, including set and slope knobs for two or three point calibration, a manual temperature adjustment allowing for temperature compensation and a 3½ digit display.

Rechargeable batteries and an ac adaptor/charger allow versatility for use in the field and in the lab. The batteries will last approximately 400 hours before recharging is required. The LCD display will give a "BAT" reading to indicate when the batteries are low.

To Order

Model No.	Description
PHH-152	Handheld pH meter with kit
PHE-1304	General purpose pH electrode
PHE-1411	Double junction electrode 12.5 D x 150 mm L (0.5 x 5")
ORE-1411	Double junction ORP probe
PHA-4	4.00 pH buffer solution, 500 mL (1 pint) bottle
PHA-7	7.00 pH buffer solution, 500 mL (1 pint) bottle
PHA-10	10.00 pH buffer solution, 500 mL (1 pint) bottle
PHAB-PH	5 each individual use packets of pH4, pH7, pH10, and deionized water
PHA-D1	500 mL (1 pint) bottle of deionized water

Kit comes complete with meter, electrode, 4 sample size buffers (pH4, pH7, pH10, D1 water), 8 "AA" rechargeable batteries, power adaptor, carrying case and operator's manual.

Ordering Examples: PHH-152, handheld pH/mV kit.

PHH-152, handheld pH/mV kit, PHA-4, 4.00 pH 4 buffer, and PHA-7, 7.00 pH 7 buffer.

Order Online

omega.com®

Over 100,000 Products Available!