


SEMI-CYLINDRICAL CERAMIC HEATERS

CRWS Series

- ✓ Rated to 982°C (1800°F)
- ✓ Helically Wound Iron-Chrome-Aluminum Wire

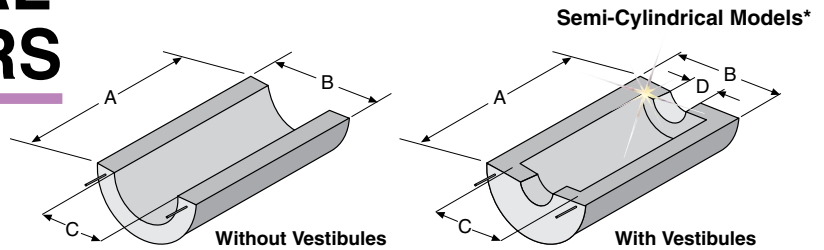

To Order

		Dimensions in cm (")				Without Vestibules	With Vestibules
Watts	Volts	A*	B	C	D	Model No.	Model No.
300	60	15 (6)	10 (4)	5 (2)	4 (1.5)	CRWS-62/60-A	CRWS-62/60-C-A
600	120	30 (12)	10 (4)	5 (2)	4 (1.5)	CRWS-122/120-A	CRWS-122/120-C-A
900	120	46 (18)	10 (4)	5 (2)	4 (1.5)	CRWS-182/120-A	CRWS-182/120-C-A
1200	240	61 (24)	10 (4)	5 (2)	4 (1.5)	CRWS-242/240-A	CRWS-242/240-C-A
425	120	15 (6)	13 (5)	8 (3)	5 (2)	CRWS-63/120-A	CRWS-63/120-C-A
850	120	30 (12)	13 (5)	8 (3)	5 (2)	CRWS-123/120-A	CRWS-123/120-C-A
1275	240	46 (18)	13 (5)	8 (3)	5 (2)	CRWS-183/240-A	CRWS-183/240-C-A
1700	240	61 (24)	13 (5)	8 (3)	5 (2)	CRWS-243/240-A	CRWS-243/240-C-A
565	120	15 (6)	15 (6)	10 (4)	6 (2.5)	CRWS-64/120-A	CRWS-64/120-C-A
1130	120	30 (12)	15 (6)	10 (4)	6 (2.5)	CRWS-124/120-A	CRWS-124/120-C-A
1700	240	46 (18)	15 (6)	10 (4)	6 (2.5)	CRWS-184/240-A	CRWS-184/240-C-A
2250	240	61 (24)	15 (6)	10 (4)	6 (2.5)	CRWS-244/240-A	CRWS-244/240-C-A
650	120	15 (6)	23 (9)	13 (5)	9 (3.5)	CRWS-65/120-A	CRWS-65/120-C-A
1300	240	30 (12)	23 (9)	13 (5)	9 (3.5)	CRWS-125/120-A	CRWS-125/120-C-A
1950	240	46 (18)	23 (9)	13 (5)	9 (3.5)	CRWS-185/240-A	CRWS-185/240-C-A
2600	240	61 (24)	23 (9)	13 (5)	9 (3.5)	CRWS-245/240-A	CRWS-245/240-C-A
850	120	15 (6)	25 (10)	15 (6)	10 (4)	CRWS-66/120-A	CRWS-66/120-C-A
1700	240	30 (12)	25 (10)	15 (6)	10 (4)	CRWS-126/240-A	CRWS-126/240-C-A
2550	240	46 (18)	25 (10)	15 (6)	10 (4)	CRWS-186/240-A	CRWS-186/240-C-A
3400	240**	61 (24)	25 (10)	15 (6)	10 (4)	CRWS-246/240-A	CRWS-246/240-C-A
920	240	15 (6)	28 (11)	18 (7)	13 (5)	CRWS-67/240-A	CRWS-67/240-C-A
1840	240	30 (12)	28 (11)	18 (7)	13 (5)	CRWS-127/240-A	CRWS-127/240-C-A
2760	240	46 (18)	28 (11)	18 (7)	13 (5)	CRWS-187/240-A	CRWS-187/240-C-A
3680	240**	61 (24)	28 (11)	18 (7)	13 (5)	CRWS-247/240-A	CRWS-247/240-C-A
1100	240	15 (6)	30 (12)	20 (8)	15 (6)	CRWS-68/240-A	CRWS-68/240-C-A
2200	240	30 (12)	30 (12)	20 (8)	15 (6)	CRWS-128/240-A	CRWS-128/240-C-A
3300	240	46 (18)	30 (12)	20 (8)	15 (6)	CRWS-188/240-A	CRWS-188/240-C-A
4400	240**	61*** (24)	30 (12)	20 (8)	15 (6)	CRWS-248/240-A	CRWS-248/240-C-A
2250	240	30 (12)	36 (14)	25 (10)	20 (8)	CRWS-1210/240-A	CRWS-1210/240-C-A
3400	240**	46 (18)	36 (14)	25 (10)	20 (8)	CRWS-1810/240-A	CRWS-1810/240-C-A
4500	240**	61*** (24)	36 (14)	25 (10)	20 (8)	CRWS-2410/240-A	CRWS-2410/240-C-A
2700	240	30 (12)	41 (16)	30 (12)	25 (10)	CRWS-1212/240-A	CRWS-1212/240-C-A
4050	240**	46 (18)	41 (16)	30 (12)	25 (10)	CRWS-1812/240-A	CRWS-1812/240-C-A
5400	240**	61*** (24)	41 (16)	30 (12)	25 (10)	CRWS-2412/240-A	CRWS-2412/240-C-A
3400	240**	30 (12)	48 (19)	38 (15)	33 (13)	CRWS-1215/240-A	CRWS-1215/240-C-A
5100	240**	46 (18)	48 (19)	38 (15)	33 (13)	CRWS-1815/240-A	CRWS-1815/240-C-A
6800	240**	61*** (24)	48 (19)	38 (15)	33 (13)	CRWS-2415/240-A	CRWS-2415/240-C-A
4100	240**	30 (12)	56 (22)	46 (18)	41 (16)	CRWS-1218/240-A	CRWS-1218/240-C-A
6150	240**	46 (18)	56 (22)	46 (18)	41 (16)	CRWS-1818/240-A	CRWS-1818/240-C-A
8200	240**	61*** (24)	56 (22)	46 (18)	41 (16)	CRWS-2418/240-A	CRWS-2418/240-C-A
4750	240**	30 (12)	64 (25)	53 (21)	48 (19)	CRWS-1221/240-A	CRWS-1221/240-C-A
7125	240**	46 (18)	64 (25)	53 (21)	48 (19)	CRWS-1821/240-A	CRWS-1821/240-C-A
9500	240**	61*** (24)	64 (25)	53 (21)	48 (19)	CRWS-2421/240-A	CRWS-2421/240-C-A

* Add 3" for units with vestibules. ** Dual 240 Vac circuits.

*** Using two 30 cm (12") long heaters; the indicated wattage is a total of two 30 cm (12") long heaters.

Ordering Example: CRWS-67/240-A, 920 Watt, 240 Vac heater, 15 cm (6") long, 18 cm (7") ID.