

# HEAVY DUTY PORTABLE HEATERS

## HF Series

- ✓ 1.9, 2, 3, 4 kW
- ✓ Lightweight
- ✓ Quick Response Element
- ✓ Quiet, Smooth-Running Motor and Fan
- ✓ Built-In Overheat Protection
- ✓ On-Off Toggle Switch (AC Models)




HF203G/120V shown smaller than actual size.

**Housing is heavy-gauge steel** with handle and rubber feet. Finish is heat-resistant green Hammerloid.

**Overheat protection.** All heaters have integral, automatic thermal cutout. DC heaters are equipped with a DC magnetic contactor with thermal cutout wired in series with holding coil.

**Dimensions.** 11 $\frac{3}{8}$ " (29 cm) wide, 13 $\frac{3}{16}$ " (33 cm) tall, 8" (20 cm) deep

**Cord and plug.** AC and DC HF heaters are supplied with 1.8 m (6') cord and grounded polarized plug except 240VDC HF-403D, 120VAC HF-303 and 120VDC HF-303D **Thermostat for automatic heating.** See Type WR.

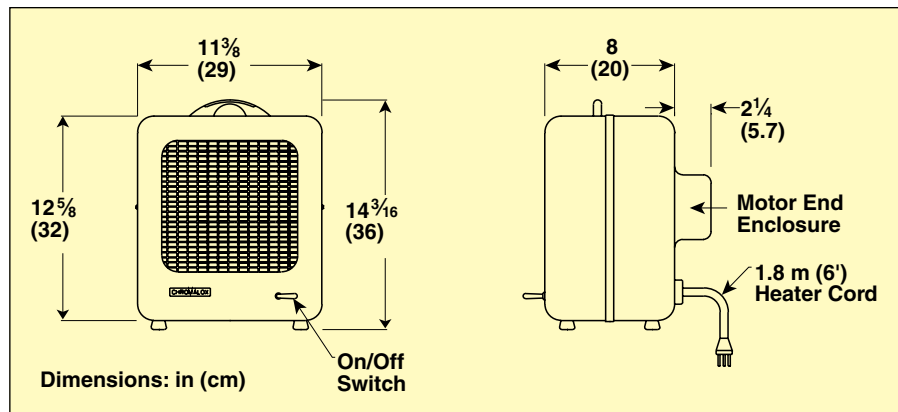

## To Order

kW	Volts	Phase	Output BTU/hr	Amps	Air temp. rise °F*	Air spd. ft/min.*	Model No.	Wt.* lb (kg)
<b>AC (supplied with on-off switch)</b>								
1.9	120	1	6483	15.8	46	140	HF203G/120V	16½ (7)
2	240	1	6824	8.3	46	140	HF203G/240V	16½ (7)
3	120	1	10236	25	70	140	HF303H/120V***	19 (9)
3	240	1	10236	12.5	70	140	HF303G/240V	19 (9)
4	240	1	13648	16.7	92	140	HF403G/240V	19 (9)
<b>DC</b>								
1.9	120	1	6483	15.8	46	140	HF203EG/120V	16½ (7)
2	240	1	6824	8.3	46	140	HF203DG/240V	16½ (7)
3	120	1	10236	25	70	140	HF303D/120V***	19 (9)
3	240	1	10236	12.5	70	140	HF303DG/240V	19 (9)
4	240	1	13648	16.7	92	140	HF403D/240V**	19 (9)

\*Approximate. \*\*Without cord and plug. \*\*\*Cord only, no plug.

**Ordering Example:** HF203G/120V, heavy duty portable heaters, 1.9 kW, 120 Vac.