

HEATING TAPES WITH BUILT-IN THERMOSTAT

HTWT101-002-60F



- ✓ Built-In Thermostat Set at 16°C (60°F)
- ✓ Moisture and Chemical Resistant
- ✓ Suitable for Electrically Conductive Surfaces

SPECIFICATIONS

Thermostat Setting: 16°C (60°F)

Max Exposure Temperature: 232°C (450°F)

Nominal Watts per square mm (inch): 0.009 (6.0)


Outer Sheath: Extruded silicone rubber

Construction: Kapton® wrapped fiberglass, knit and braided

Width: 25.4 mm (1")

Power Cord: 1.8 m (6') with plug on 120V models, stripped lead ends on 240V models

Power: 120 or 240 Vac

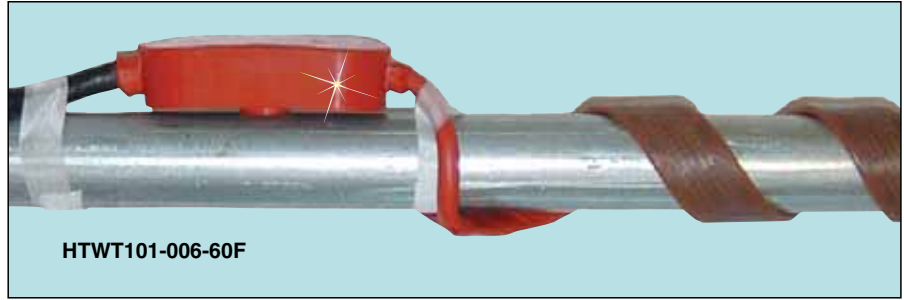

To Order

Model No.	Length mm (in)	Wattage	Voltage
HTWT101-002-60F	610 (24)	104	120
HTWT101-004-60F	1220 (48)	209	120
HTWT101-006-60F	1829 (72)	313	120
HTWT101-008-60F	2438 (96)	418	120
HTWT101-010-60F	3048 (120)	522	120
HTWT102-004-60F	1220 (48)	209	240
HTWT102-006-60F	1829 (72)	313	240
HTWT102-008-60F	2438 (96)	418	240
HTWT102-010-60F	3048 (120)	522	240

Comes complete with operator's manual.

All heating tapes are 25.4 mm (1") wide and come with a thermostat set at 16°C (60°F).

HEATING TAPES WITH PERCENTAGE CONTROLLER

HTWC100 Series

- ✓ Reliable
- ✓ Integral Percentage Controller
- ✓ Silicone Rubber Encapsulated Heating Tape
- ✓ Maximum Exposure Temperature up to 232°C (450°F)

The tape consists of a flexible heating strip 1" wide and of varying lengths with a permanently incorporated temperature controller. Standard tapes are available for either 120 or 240V operation and develop 72 watts per lineal foot. These tapes are completely safe when operated according to directions, and with reasonable care, will give long service.

This economical semi-automatically controlled heating tape has been developed for use in small scale heating applications.

SPECIFICATIONS

Power: 120 or 240V

Wattage: 72 watts/lineal foot

Heating Element: Fine gage stranded resistance wires insulated with fiberglass yarn and completely enclosed in a silicone rubber extrusion

Controller: Rugged and dependable percentage controller. Includes power cord and 2 prong plug



To Order

Model Number	Watts	Volts	Size
HTWC101-002	144	120	1" x 2'
HTWC101-004	288	120	1" x 4'
HTWC101-006	432	120	1" x 6'
HTWC101-008	576	120	1" x 8'
HTWC101-010	720	120	1" x 10'
HTWC102-002	144	240	1" x 2'
HTWC102-004	288	240	1" x 4'
HTWC102-006	432	240	1" x 6'
HTWC102-008	576	240	1" x 8'
HTWC102-010	720	240	1" x 10'

Comes complete with operator's manual.