
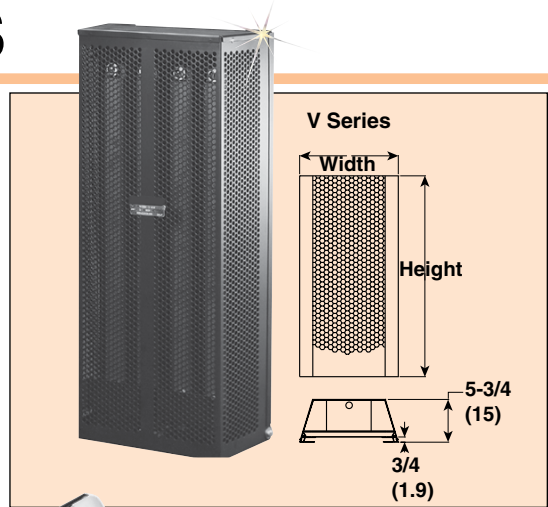


RUGGED WALL MOUNTED CONVECTION HEATERS

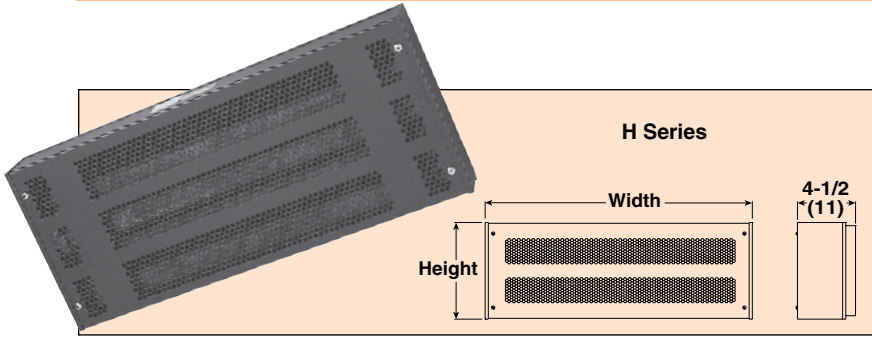

H & V SERIES

- ✓ Time Tested, Heavy Duty
- ✓ EH & HVT Models, UL Listed
- ✓ Abuse-Proof, Maintenance Free
- ✓ 120, 240 and 480V

FEATURES

Heavy-duty construction. These heaters are equipment answers of the highest dependability for plant areas starting with the very smallest and including unmanned areas. Heat source in all models is one or more reliable OMEGALUX® strip heaters with internal baffling. Cases are perforated, heavy-gauge steel.

EH AND HVT SERIES—0.250 TO 1 kW (U.L. LISTED)

One or two OMEGALUX® strip heaters are mounted on a baffled back plate. Perforated sheet housing has tough, attractive, buckskin brown wrinkle finish. On-off switch or thermostat can be wired into the EH Series. See Section P for our large selection of controllers.


H SERIES—1 TO 3 kW

Heat source is two or four OMEGALUX strip heaters. Heated air is discharged horizontally. Extra-heavy construction. Finish is hard black enamel.

V SERIES—3 TO 4.5 kW

Four or six OMEGALUX strip heaters are mounted vertically behind a perforated steel grille to provide a high volume of rising warm air. Controls may be wall-mounted thermostats. Case has hard black enamel finish.

Dimensions: in (cm)

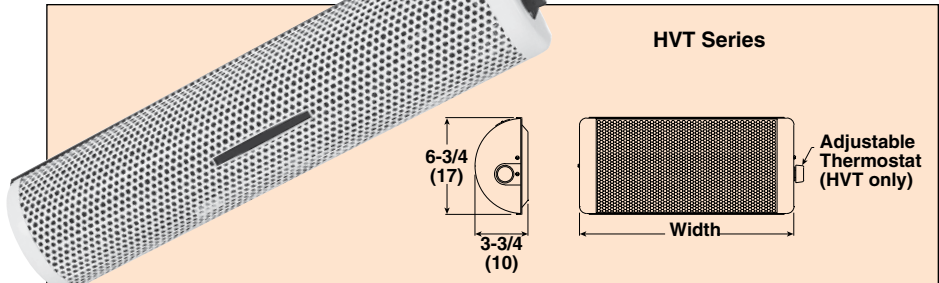

Controls are not furnished (except HVT models) but ON/OFF switch or thermostat can be either wired into the unit or separately wall mounted. See Controllers in Section P.

SPECIFICATIONS

Power: 120, 240, 480 Vac

Watts: 0.25 to 4.5 kW

Controllers: Model HVT has integral adjustable thermostat, 40 to 90°F

To Order

kW	Volts	No. Elem.	Dimensions: inch (cm)			Model No.	Wt. lb
			A	B	C		
EH Series							
0.25	120	1	14 ⁵ / ₈ (37)	6 ³ / ₄ (17)	3 ³ / ₄ (10)	EH-1221/120	7
0.50	120	2	14 ⁵ / ₈ (37)	6 ³ / ₄ (17)	3 ³ / ₄ (10)	EH-1251/120	7
0.50	240	2	14 ⁵ / ₈ (37)	6 ³ / ₄ (17)	3 ³ / ₄ (10)	EH-1251/240	7
HVT Series with 52° to 110°F Adjustable Thermostat							
0.5	120	1	28 ⁵ / ₈ (73)	6 ³ / ₄ (17)	3 ³ / ₄ (10)	HVT-1251/120	13
1.0	120	2	28 ⁵ / ₈ (73)	6 ³ / ₄ (17)	3 ³ / ₄ (10)	HVT-2411/120	15
H Series							
1.0	120	2	20 ³ / ₄ (53)	7 ¹ / ₂ (19)	4 ¹ / ₂ (11)	H-1801/120	28
1.5	240	2	26 ¹ / ₂ (67)	7 ¹ / ₂ (19)	4 ¹ / ₂ (11)	H-2405/240	30
2.0	120	4	26 ¹ / ₂ (67)	11 ¹ / ₄ (29)	4 ¹ / ₂ (11)	H-2406/120	32
2.0	240	4	26 ¹ / ₂ (67)	11 ¹ / ₄ (29)	4 ¹ / ₂ (11)	H-2406/240	32
2.0	480	4	26 ¹ / ₂ (67)	11 ¹ / ₄ (29)	4 ¹ / ₂ (11)	H-2406/480	32
3.0	240	4	26 ¹ / ₂ (67)	11 ¹ / ₄ (29)	4 ¹ / ₂ (11)	H-2407/240	32
3.0	480	4	26 ¹ / ₂ (67)	11 ¹ / ₄ (29)	4 ¹ / ₂ (11)	H-2407/480	32
V Series							
3.0	240	4	27 (69)	12 ³ / ₄ (32)	5 ³ / ₄ (15)	V-2030/240	34
4.5	240	6	27 (69)	17 ³ / ₄ (45)	5 ³ / ₄ (15)	V-2040/240	44
4.5	480	6	27 (69)	17 ³ / ₄ (45)	5 ³ / ₄ (15)	V-2040/480	44