

## HEAVY DUTY LABORATORY HOT PLATES

ROPH Series  
Starts at  
**\$329**



- ✓ Models Available with 3 Heat Setting or with Infinite Control
- ✓ 120 and 240V Models from 660 to 2000 Watts
- ✓ Premium Quality Construction
- ✓ 1.8 m (6'), 3-Conductor Cord with Distinct NEMA Type Plug
- ✓ UL Listed




ROPH-144, \$383, shown smaller than actual size.

### APPLICATIONS

- ✓ Continuous Heavy Duty Laboratory Work
- ✓ For Heating Beakers and Pans
- ✓ Evaporations
- ✓ Dehydrations

### FEATURES

Flat, rugged cast heating element is designed for heavy duty service. It is unaffected by physical and thermal shock. Spill-overs cannot damage the heating unit

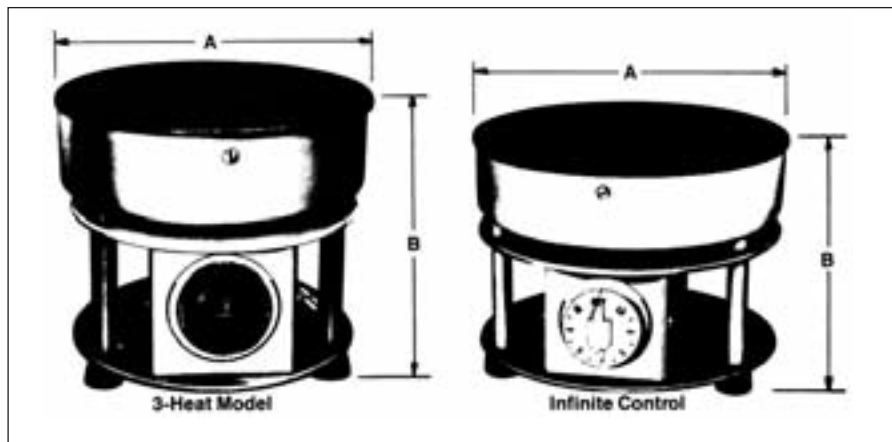

### STURDY FRAME

Enclosed switch in a terminal box which protects it from excess heat, and assures safety and long life

Six foot, 3-conductor cord, supplied with all models, has NEMA type plug-in device

3-heat switch Low medium or high temperature settings

Infinite control Devices have HI, LO and infinite control positions to 100% of rated wattage. LO provides a nominal output of 5% rated wattage

With Infinite Control

**MOST POPULAR MODEL HIGHLIGHTED!**

To Order (Specify Model Number)										
Watts	Volts	Max Surface Dim cm (in)		NEMA Plug	Temp °F			Model No.	Price	Weight kg (lb)
		A	B		Hi	Med	Lo			
600	120	18 (7)	15.7 (6 <sup>3</sup> / <sub>16</sub> )	5-15P	700	-	-	ROPH-64	\$329	2 (6.5)
1000	120	18 (7)	15.7 (6 <sup>3</sup> / <sub>16</sub> )	5-15P	900	-	-	ROPH-104	329	2 (6.5)
1200	120	18 (7)	15.7 (6 <sup>3</sup> / <sub>16</sub> )	5-15P	970	-	-	ROPH-124	329	2 (6.5)
1400	120	22 (8 <sup>1</sup> / <sub>2</sub> )	15.7 (6 <sup>3</sup> / <sub>16</sub> )	5-15P	875	-	-	ROPH-144	383	4.5 (10.0)

Comes complete with power cord and operators manual.

Ordering Examples: ROPH-144, hot plate 1400 W, \$383. ROPH-64, hot plate, 600 W, \$329.



#### UNITED STATES

[www.omega.com](http://www.omega.com)  
1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)  
Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)  
Deckenpfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)  
Manchester, England  
0800-488-488

#### FRANCE

[www.omega.fr](http://www.omega.fr)  
Guyancourt, France  
088-466-342

#### CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)  
Karviná, Czech Republic  
596-311-899

#### BENELUX

[www.omega.nl](http://www.omega.nl)  
Amstelveen, NL  
0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters