

SILICONE RUBBER HEATERS

Square/Rectangular Heat Blankets


SRMU Series Starts at

\$44

9 to 12" Widths

SRMU100909, \$44.

SRMU051011-P, \$57.

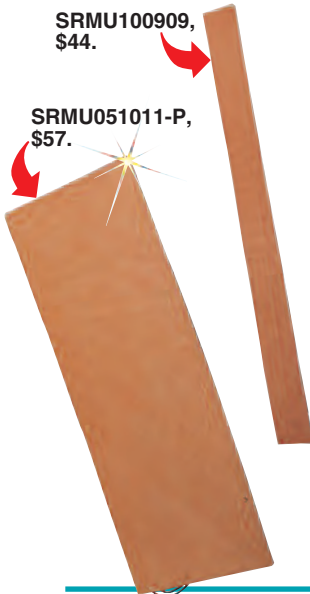

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)						
Width cm (")	Length cm (")	2.5 Watts/in ² (0.39 Watts/cm ²)	5 Watts/in ² (0.78 Watts/cm ²)	10 Watts/in ² (1.55 Watts/cm ²)	Price no PSA	Price with PSA*
22.86 (9)	22.86 (9)	SRMU020909	SRMU050909	SRMU100909	\$44	\$48
22.86 (9)	25.40 (10)	SRMU020910	SRMU050910	SRMU100910	46	51
22.86 (9)	27.94 (11)	SRMU020911	SRMU050911	SRMU100911	49	54
22.86 (9)	30.48 (12)	SRMU020912	SRMU050912	SRMU100912	52	57
25.40 (10)	25.40 (10)	SRMU021010	SRMU051010	SRMU101010	49	54
25.40 (10)	27.94 (11)	SRMU021011	SRMU051011	SRMU101011	52	57
25.40 (10)	30.48 (12)	SRMU021012	SRMU051012	SRMU101012	54	59
25.40 (10)	45.72 (18)	SRMU021018	SRMU051018	N/A	69	76
25.40 (10)	60.69 (24)	SRMU021024	SRMU051024	N/A	84	92
25.40 (10)	76.20 (30)	SRMU021030	SRMU051030	N/A	99	109
25.40 (10)	91.44 (36)	SRMU021036	SRMU051036	N/A	114	126
25.40 (10)	106.68 (42)	SRMU021042	N/A	N/A	129	142
124.40 (10)	121.92 (48)	SRMU021048	N/A	N/A	143	157
27.94 (11)	27.94 (11)	SRMU021111	SRMU051111	SRMU101111	54	58
27.94 (11)	30.48 (12)	SRMU021112	SRMU051112	SRMU101112	58	64
30.48 (12)	20.32 (12)	SRMU021212	SRMU051212	N/A	61	66
30.48 (12)	22.86 (18)	SRMU021218	SRMU051218	N/A	78	86
30.48 (12)	25.40 (24)	SRMU021224	SRMU051224	N/A	95	105
30.48 (12)	27.94 (30)	SRMU021230	N/A	N/A	114	126
30.48 (12)	30.48 (36)	SRMU021236	N/A	N/A	132	145
30.48 (12)	45.72 (42)	SRMU021242	N/A	N/A	149	164
30.48 (12)	60.96 (48)	SRMU021248	N/A	N/A	167	184

* To order with PSA (Pressure Sensitive Adhesive) add suffix "-P" to Model Number. To custom order 96" leads, add suffix "-096" to model number and \$45 to price.

Ordering Example: SRMU020608-P, 2.5 watt/in² 6 x 8" heater, \$40.

Silicone Rubber Enclosed Heaters

SREH Series Starts at

\$25


- ✓ Moisture Resistant
- ✓ Chemical Resistant
- ✓ Radiation Resistant

SREH series enclosure heaters feature our serpentine wound heating element laminated between two layers of 15 mil fiberglass reinforced silicone rubber and bonded to an aluminum mounting plate. The mounting plate comes with two 11 mm (7/16") holes for mounting. The built-in air sensing thermostat regulates the temperature in the enclosure to prevent condensation or freezing. The SREH enclosure heaters can be mounted vertically or horizontally, however optimal control is achieved when mounted vertically.

SPECIFICATIONS

Operating Voltage: 120 Vac
Leads: 122 cm (48") PFA
Heating Element: Laminated between two layers of, 0.015 mil, fiberglass reinforced silicone rubber

SREH600, \$25, shown smaller than actual size.

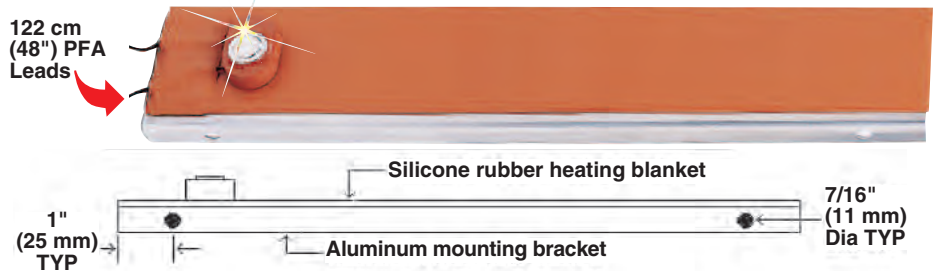

Silicone Rubber Density: 16.8 oz/yd² (0.06 grams/cm²) per layer
Overall Thickness: (blanket and bracket) 1/4" (0.64 cm)
Maximum Energized Exposure Temperature: 232°C (450°F)

Maximum De-energized Exposure Temperature: 260°C (500°F)
Minimum Exposure Temperature: -51°C (-60°F)
Dielectric Strength: > 2000V
Approvals: UR Pending

To Order (Specify Model Number)						
Width cm (")	Length cm (")	Total Watts	Thermostat		Model Number (120 Vac)	Price
			Opens	Closes		
6.4 (2.5)	15.24 (6)	60	N/A	N/A	SREH600	\$25
6.4 (2.5)	15.24 (6)	60	15°C (60°F)	4°C (40°F)	SREH640	78
6.4 (2.5)	15.24 (6)	60	60°C (140°F)	43°C (110°F)	SREH6110	78
6.4 (2.5)	15.24 (6)	60	82°C (180°F)	65°C (150°F)	SREH6150	78
6.4 (2.5)	30.48 (12)	120	N/A	N/A	SREH1200	32
6.4 (2.5)	30.48 (12)	120	15°C (60°F)	4°C (40°F)	SREH1240	87
6.4 (2.5)	30.48 (12)	120	140°F (60°C)	43°C (110°F)	SREH12110	87
6.4 (2.5)	30.48 (12)	120	180°F (82°C)	65°C (150°F)	SREH12150	87

Ordering Example: SREH1240, 30.48 cm (12"), 120 Watt heater with 15°C (60°F) setpoint thermostat, \$87.



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters