

# IMMERSION HEATERS FOR SMALL TANK APPLICATIONS

TMW-2 Series



TMW-210A/120 shown smaller than actual size.


- ✓ 1 1/4 NPT Brass Screw Plug
- ✓ Copper Sheath Element
- ✓ 64 to 86 W/in<sup>2</sup>
- ✓ 750 to 5,000 Watts
- ✓ 120 and 240V, Single Phase
- ✓ Without Terminal Cover
- ✓ Without Thermowell

## APPLICATION

- ✓ Clean Water Heating



TMW-207A/120 shown smaller than actual size.

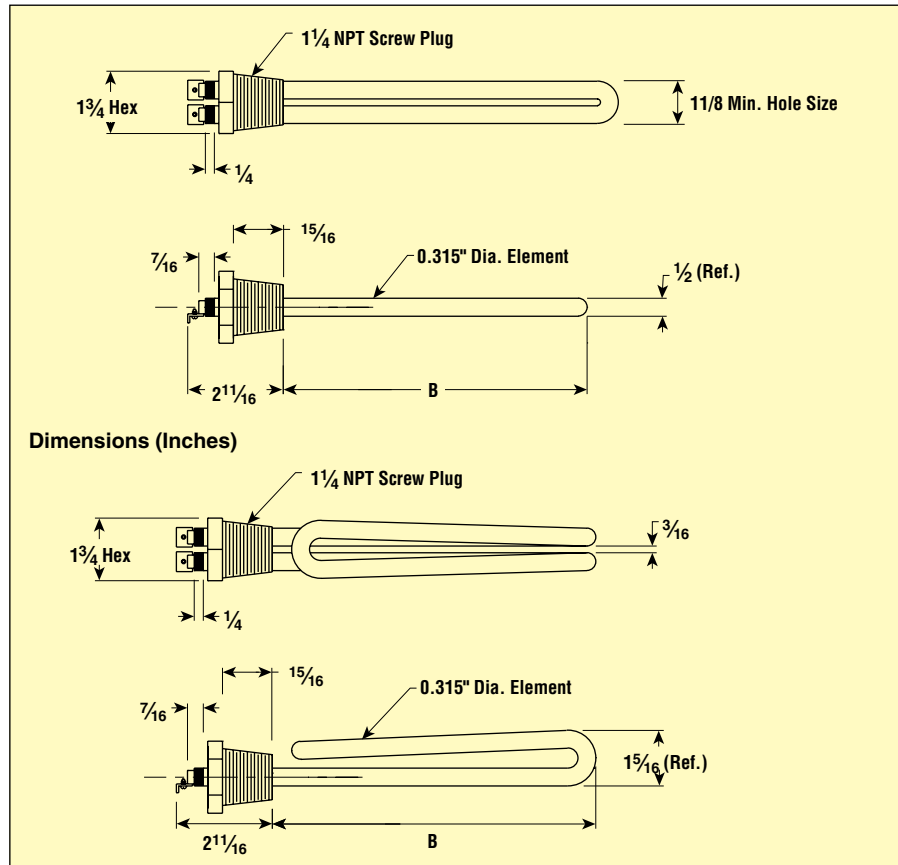

## To Order

Watts	Volts	Phase	W/in <sup>2</sup>	Dim B (In.)	Model No.	Weight lb.
<b>Straight Element</b>						
750	120	1	64	6 1/8	TMW-207A/120	0.5
750	240	1	64	6 1/8	TMW-207A/240	0.5
1000	120	1	85	6 1/8	TMW-210A/120	0.5
1000	240	1	85	6 1/8	TMW-210A/240	0.5
1250	120	1	82	7 7/8	TMW-212A/120	1
1250	240	1	82	7 7/8	TMW-212A/240	1
1500	120	1	86	9 1/16	TMW-215A/120	1.25
1500	240	1	86	9 1/16	TMW-215A/240	1.25
<b>Foldback Element</b>						
2000	120	1	85	6 5/8	TMW-220A/120	1.5
2000	240	1	85	6 5/8	TMW-220A/240	1.5
2500	240	1	80	8 1/2	TMW-225A/240	2
3000	240	1	78	10 3/16	TMW-230A/240	2.25
4000	240	1	77	13 9/16	TMW-240A/240	2.5
5000	240	1	76	16 15/16	TMW-250A/240	3

Ordering Example: TMW-212A/120, 120V, single phase, 1250 W heater.