

FOOD EQUIPMENT HEATERS WITH LOW LIQUID CUTOUT


TTUH-CO Series




- ✓ Brass Flange
- ✓ Copper Sheath
- ✓ High Watt Density
- ✓ Without Contactor
- ✓ Integral Low Liquid Thermal Cutout

FEATURES

The TTUH-CO series heater is mounted through a 6 cm (2 5/16") diameter opening in bottom of vessel. Heater is inserted with gasket through top of vessel or through hand hole. Mount combination terminal box and clamp over the element flange and use bolt to draw mounting clamp tightly to the tank.

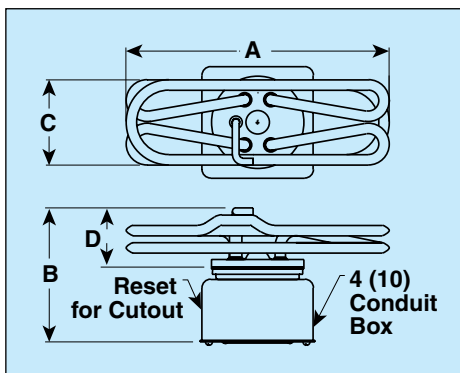

Dimensions: inch (cm)

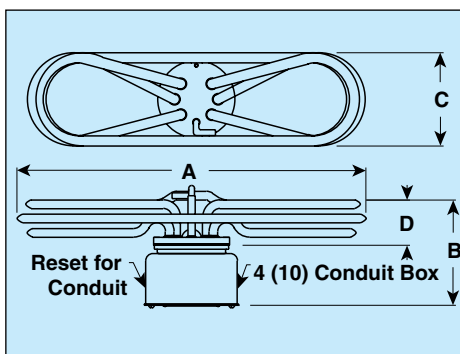

TTUH-CO-15/208V shown smaller than actual size.



TTUH-CO-303/240/3P shown smaller than actual size.

To Order

kW	W/in ²	Dimensions: inch (cm)				Model No.	Wt. lb (kg)
		A	B	C	D		
TTUH-CO Series — Single Phase W/cutout — 2 1/2" Minimum Liquid Depth							
1.5	62	7 7/16 (19)	4 13/16 (12)	3 1/16 (8)	2 3/8 (6)	TTUH-CO-15/*	3 (1)
2	60	9 7/16 (23)	4 13/16 (12)	3 1/16 (8)	2 1/8 (5)	TTUH-CO-20/*	3 (1)
2.5	40	6 3/4 (17)	4 13/16 (12)	3 1/16 (8)	2 1/8 (5)	TTUH-CO-25/*	3 1/8 (1)
3	55	6 3/4 (17)	4 13/16 (12)	3 1/16 (8)	2 1/8 (5)	TTUH-CO-30/*	3 1/4 (1)
4	64	9 1/2 (24)	4 13/16 (12)	3 1/16 (8)	2 1/8 (5)	TTUH-CO-40/*	3 7/8 (2)
5	70	12 3/4 (32)	5 3/8 (14)	4 (10)	2 11/16 (7)	TTUH-CO-50/*	5 (2)
6	73	14 1/2 (37)	5 3/8 (14)	4 (10)	2 11/16 (7)	TTUH-CO-60/*	6 (3)
7	85	14 1/2 (37)	5 3/8 (14)	4 (10)	2 11/16 (7)	TTUH-CO-70/240	6 (3)
TTUH-CO Series — Three Phase with Cutout — 3" Minimum Liquid Depth							
3	55	8 3/4 (22)	5 1 1/16 (15)	3 1/8 (8)	2 3/4 (7)	TTUH-CO-303/*/3P	4 (2)
4	74	8 3/4 (22)	5 1 1/16 (15)	3 1/8 (8)	2 3/4 (7)	TTUH-CO-403/*/3P	5 (2)
5	73	11 (28)	5 1 3/16 (15)	3 1/8 (8)	2 3/4 (7)	TTUH-CO-503/**/3P	5 (2)
6	72	11 1/16 (28)	5 3/4 (16)	4 1/16 (10)	3 (8)	TTUH-CO-603/*/3P	5 (2)
7	78	11 1/16 (28)	5 3/4 (16)	4 1/16 (10)	3 (8)	TTUH-CO-703/208/3P	4 1/2 (2)
8	69	14 1/2 (37)	5 3/4 (16)	4 1/16 (10)	3 (8)	TTUH-CO-803/208/3P	6 (3)
9	78	14 1/2 (37)	5 3/4 (16)	4 1/16 (10)	3 (8)	TTUH-CO-903/208/3P	6 (3)

* Designate voltage, i.e. insert "208" for 208V or "240" for 240V.

/** Designate voltage, i.e., "208" for 208V or "240" for 240V, or "480" for 480V.

Note: Other kW rating and voltages are available. Contact OMEGALUX®.

Ordering Examples: TTUH-CO-15/208, 1.5 kW heater powered by 208 Vac.

TTUH-CO-303/240/3P, 3 kW heater powered by 240 Vac 3 phase.

When mounting in a closed tank, a hand hole should be cut in the side of the tank only large enough to insert the heater and reach to the bottom of the tank to insert in the 6 cm (2 5/16") diameter mounting hole. See To Order table for heater dimensions.

SPECIFICATIONS

Wattage: 1.5 to 9 kW

Power: 208 and 240 or 480V, 1 and 3 Phase

Watt Density: 40 to 85 W/in²

Note: All models have an integral low-liquid cutout to protect the heater.

CAUTION AND WARNING!

Fire and electrical shock may result if products are used improperly or installed or used by non-qualified personnel. See inside back cover for additional warning.