

LOW-PRESSURE DIAPHRAGM GAUGES


PGL Series



- ✓ Corrosion-Resistant Bronze Diaphragm
- ✓ 150% Overpressure Protection
- ✓ Recalibration Screw on Dial
- ✓ 2-1-2 ANSI Grade A Accuracy*

SPECIFICATIONS

Dial: 64 mm (2.5") Dia.
Pointer: Black aluminum
Movement: Brass
Element: Bronze diaphragm
Connection: ¼ NPT
Window: Polycarbonate
Media: Clean, dry, non-corrosive gas only

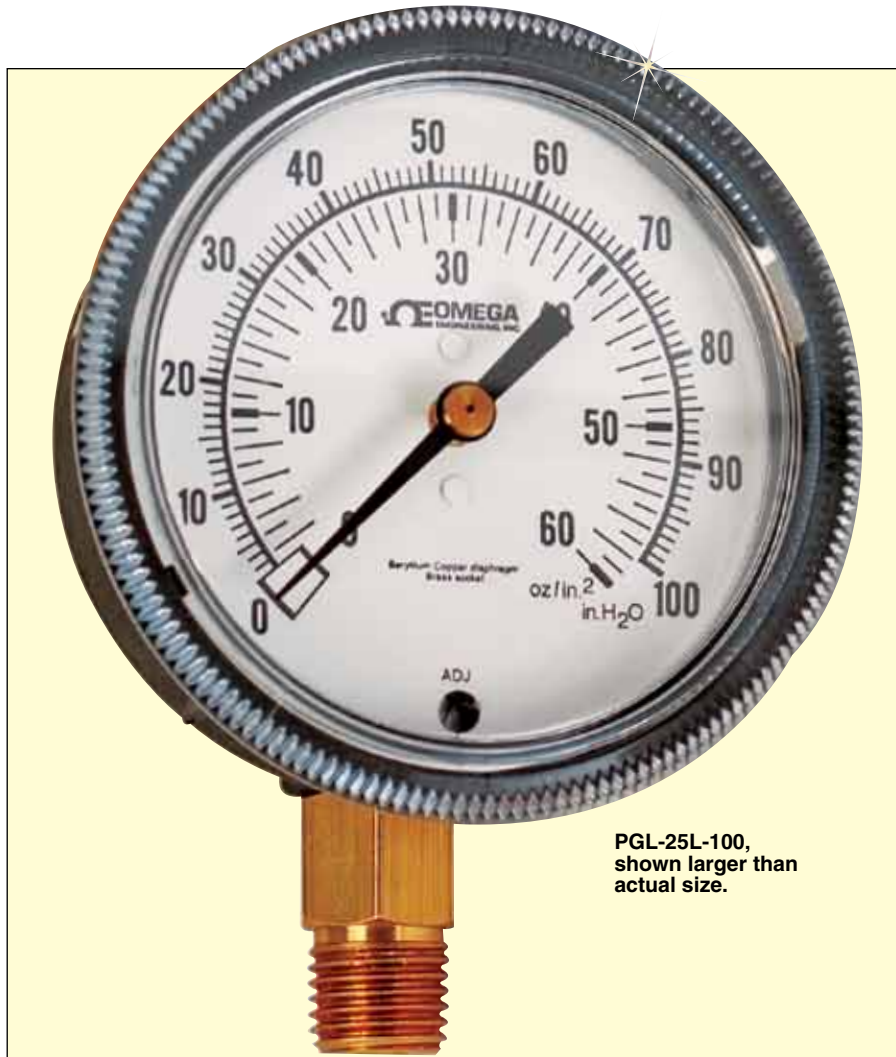

PGL-25L-100, shown larger than actual size.

To Order

MODEL NO.	RANGE/GRADUATIONS					
	OUTER SCALE	INNER SCALE	INNER SCALE		OUTER SCALE	
			FIG. INTERVALS	MINOR GRAD.	FIG INTERVALS	MINOR GRAD.
PGL-25L-10	0/10 inH ₂ O	—	1	0.1	—	—
PGL-25L-15	0/15 inH ₂ O	0/9 oz/in ²	1	0.2	5	0.2
PGL-25L-35	0/35 inH ₂ O	0/20 oz/in ²	5	0.5	5	0.5
PGL-25L-60	0/60 inH ₂ O	0/35 oz/in ²	5	0.5	5	0.5
PGL-25L-100	0/100 inH ₂ O	0/60 oz/in ²	10	1	10	1
PGL-25L-160	0/160 inH ₂ O	—	20	2	—	—
PGL-25L-200	0/200 inH ₂ O	—	20	2	—	—
PGL-25L-300	0/300 inH ₂ O	—	50	5	—	—

* 2% first 10%, 1% middle 80%, 2% last 10%.

Note: Cannot be oxygen cleaned.

Ordering Example: PGL-25L-100, low-pressure gauge with 0 to 100 inH₂O range.