

# POCKET TEST GAUGES

## 76 mm (3") DIAL AND STAINLESS STEEL CASE

### PGT Series



- ✓ 0.5% FS Accuracy
- ✓ Ideal "Tool Box" Test Gauge
- ✓ All Stainless Steel Construction

#### SPECIFICATIONS

**Accuracy:** 0.5% FS  
**Case:** Polished stainless steel  
**Dial:** White background with mirrored band  
**Pointer:** Adjustable with knife-edge tip  
**Movement:** Stainless steel  
**Element:** 316 Stainless steel  
**Connection:** ¼ NPT



PGT-30L-300 cover included, shown actual size.

#### To Order

MODEL NO.	DIAL DIA. mm (inch)	RANGE	GRADUATIONS FIGURE	
			MAJOR	MINOR
PGT-30L-15	76 (3)	0 to 15	1	0.1
PGT-30L-30	76 (3)	0 to 30	2	0.2
PGT-30L-60	76 (3)	0 to 60	5	0.5
PGT-30L-100	76 (3)	0 to 100	10	1
PGT-30L-150	76 (3)	0 to 150	10	1
PGT-30L-200	76 (3)	0 to 200	20	2
PGT-30L-300	76 (3)	0 to 300	20	2
PGT-30L-400	76 (3)	0 to 400	50	2
PGT-30L-600	76 (3)	0 to 600	50	5
PGT-30L-1000	76 (3)	0 to 1000	100	10

*Ordering Examples: PGT-30L-100, pocket test gauge with 0 to 100 psi range, and stainless steel cover.  
 PGT-30L-300, pocket test gauge with 0 to 300 psi range, and stainless steel cover.*

# LOW-PRESSURE DIAPHRAGM GAUGES


## PGL Series



- ✓ Corrosion-Resistant Bronze Diaphragm
- ✓ 150% Overpressure Protection
- ✓ Recalibration Screw on Dial
- ✓ 2-1-2 ANSI Grade A Accuracy\*

### SPECIFICATIONS

**Dial:** 64 mm (2.5") Dia.  
**Pointer:** Black aluminum  
**Movement:** Brass  
**Element:** Bronze diaphragm  
**Connection:** ¼ NPT  
**Window:** Polycarbonate  
**Media:** Clean, dry, non-corrosive gas only

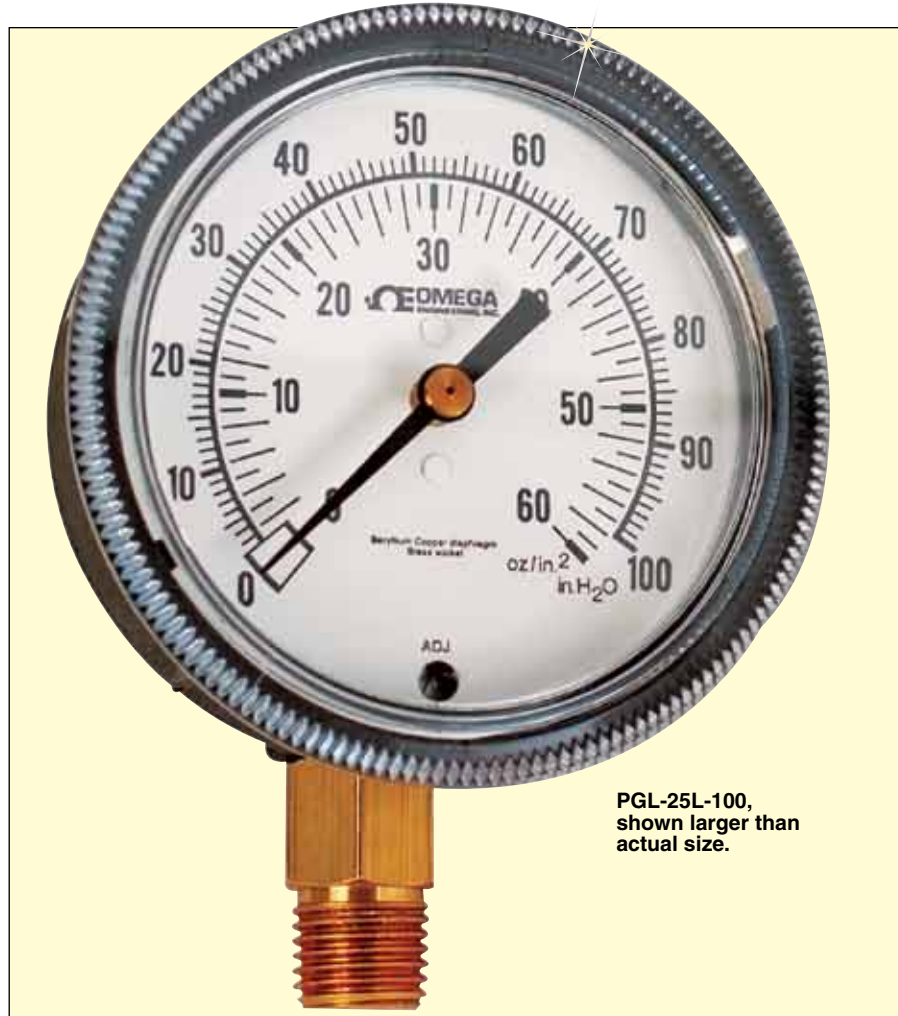

PGL-25L-100, shown larger than actual size.

### To Order

MODEL NO.	RANGE/GRADUATIONS					
	OUTER SCALE	INNER SCALE	INNER SCALE		OUTER SCALE	
			FIG. INTERVALS	MINOR GRAD.	FIG INTERVALS	MINOR GRAD.
PGL-25L-10	0/10 inH <sub>2</sub> O	—	1	0.1	—	—
PGL-25L-15	0/15 inH <sub>2</sub> O	0/9 oz/in <sup>2</sup>	1	0.2	5	0.2
PGL-25L-35	0/35 inH <sub>2</sub> O	0/20 oz/in <sup>2</sup>	5	0.5	5	0.5
PGL-25L-60	0/60 inH <sub>2</sub> O	0/35 oz/in <sup>2</sup>	5	0.5	5	0.5
PGL-25L-100	0/100 inH <sub>2</sub> O	0/60 oz/in <sup>2</sup>	10	1	10	1
PGL-25L-160	0/160 inH <sub>2</sub> O	—	20	2	—	—
PGL-25L-200	0/200 inH <sub>2</sub> O	—	20	2	—	—
PGL-25L-300	0/300 inH <sub>2</sub> O	—	50	5	—	—

\* 2% first 10%, 1% middle 80%, 2% last 10%.

**Note:** Cannot be oxygen cleaned.

**Ordering Example:** PGL-25L-100, low-pressure gauge with 0 to 100 inH<sub>2</sub>O range.