


PRECISION STRAIN GAGE



PRE-WIRED STRAIN GAGES

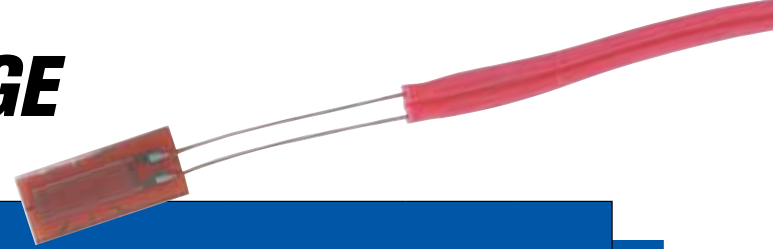

To Order

ENCAPSULATED WITH 2 LEAD WIRES, 1 M (3') LOMG, ATTACHED

MODEL NO. Pkg of 10	NOM. RESISTANCE (Ω)	DIMENSIONS mm (inch)†				MAX V* (Vrms)	TERMINATION	TEMP COMP	TERM PAD
		GRID		CARRIER					
		A	B	C	D				
KFG-02-120-C1-11 L1M2R	120	0.2 (0.008)	1.3 (0.051)	3.3 (0.13)	2.4 (0.094)	1	2 wire	STE	1
KFG-1N-120-C1-11L1M2R	120	1.0 (0.039)	0.7 (0.028)	4.2 (0.17)	1.4 (0.055)	1.5	2 wire	STE	2
KFG-2N-120-C1-11L1M2R	120	2.0 (0.079)	0.9 (0.035)	5.3 (0.21)	1.4 (0.055)	2	2 wire	STE	2
KFG-3-120-C1-11L1M2R	120	3.0 (0.12)	1.3 (0.051)	7.4 (0.29)	2.8 (0.11)	4	2 wire	STE	3
KFG-3-350-C1-11L1M2R	350	3.0 (0.12)	1.3 (0.051)	7.4 (0.29)	2.8 (0.11)	15	2 wire	STE	3
KFG-5-120-C1-11L1M2R	120	5.0 (0.2)	1.4 (0.055)	9.4 (0.37)	2.8 (0.11)	8	2 wire	STE	3
KFG-5-350-C1-11L1M2R	350	5.0 (0.2)	1.4 (0.055)	9.4 (0.37)	2.8 (0.11)	20	2 wire	STE	4
KFG-10-120-C1-11L1M2R	120	10.00 (0.39)	3.0 (0.12)	16.0 (0.63)	5.2 (0.2)	15	2 wire	STE	4
KFG-30-120-C1-11 L1M2R	120	30.0 (1.18)	3.3 (0.13)	37.0 (1.46)	5.2 (0.2)	25	2 wire	STE	5

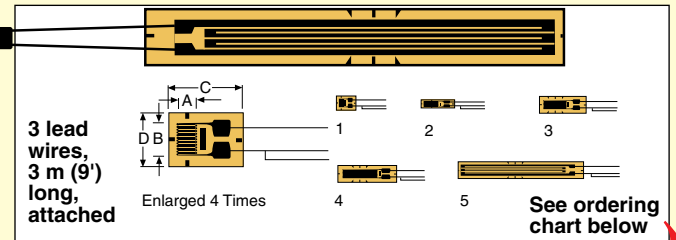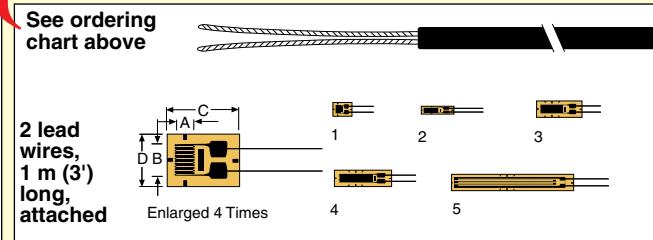

To Order

ENCAPSULATED WITH 3 LEAD WIRES, 3 m (9') LOMG, ATTACHED

MODEL NO. Pkg of 10	NOM. RESISTANCE (Ω)	DIMENSIONS mm (inch)†				MAX V* (Vrms)	TERMINATION	TEMP COMP	TERM PAD
		GRID		CARRIER					
		A	B	C	D				
KFG-02-120-C1-11 L3M3R	120	0.2 (0.008)	1.3 (0.051)	3.3 (0.13)	2.4 (0.094)	1	3 wire	STE	1
KFG-1N-120-C1-11L3M3R	120	1.0 (0.039)	0.7 (0.028)	4.2 (0.17)	1.4 (0.055)	1.5	3 wire	STE	2
KFG-2N-120-C1-11L3M3R	120	2.0 (0.079)	0.9 (0.035)	5.3 (0.21)	1.4 (0.055)	2	3 wire	STE	2
KFG-3-120-C1-11L3M3R	120	3.0 (0.12)	1.3 (0.051)	7.4 (0.29)	2.8 (0.11)	4	3 wire	STE	3
KFG-3-350-C1-11L3M3R	350	3.0 (0.12)	1.3 (0.051)	7.4 (0.29)	2.8 (0.11)	15	3 wire	STE	3
KFG-5-120-C1-11L3M3R	120	5.0 (0.2)	1.4 (0.055)	9.4 (0.37)	2.8 (0.11)	8	3 wire	STE	3
KFG-5-350-C1-11L3M3R	350	5.0 (0.2)	1.4 (0.055)	9.4 (0.37)	2.8 (0.11)	20	3 wire	STE	4
KFG-10-120-C1-11L3M3R	120	10.00 (0.39)	3.0 (0.12)	16.0 (0.63)	5.2 (0.2)	15	3 wire	STE	4
KFG-30-120-C1-11 L3M3R	120	30.0 (1.18)	3.3 (0.13)	37.0 (1.46)	5.2 (0.2)	25	3 wire	STE	5

DISCOUNT SCHEDULE

1 to 10 pkgs.	Net
11 to 24 pkgs.5%
25 to 49 pkgs.	10%
50 and up and OEM ..	Consult Factory

† For dimensions key, visit us online. **Note:** For strain gage accessories, visit us online.
Ordering Example: KFG-02-120-C1-11L1M2R, package of 10 pre-wired strain gages, encapsulated with 2 lead wires attached.