




Most Popular Commodity Thermowells

Special Low Prices


If you do not see the thermowell you require in high volume, consult OMEGA® Custom Engineering Department for a quotation.

Series 260L—Lagging Extension Type

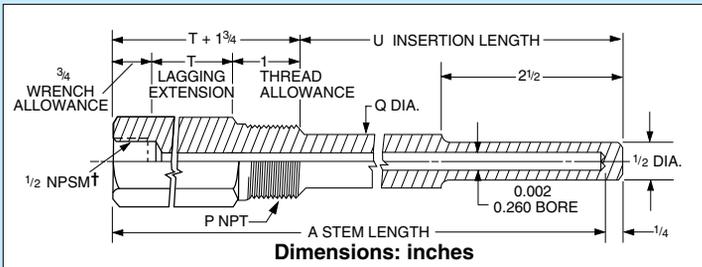

† NPSM internal pipe thread will accept both NPT and NPS male threads.


Series 260S—General Use

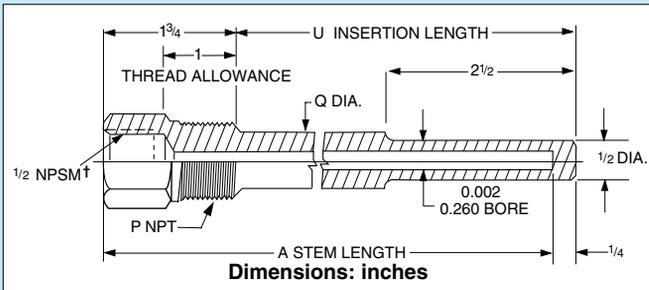

† NPSM internal pipe thread will accept both NPT and NPS male threads.

All models shown close to actual size.

Series 260—Limited Space Type

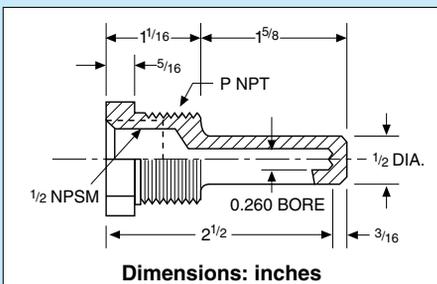



Most Popular Commodity Thermowells

If you do not see the thermowell you require in high volume, consult OMEGA® Custom Engineering Department for a quotation.



Consult OMEGA for all your high volume thermowell applications.

We produce these wells in high volume for significant cost savings. They are made from the finest materials and meet our stringent quality standards.

Connection Size: ½ and ¾ NPT are standard. Other thread sizes are available upon request.

Materials: Brass (ASTM B-16); stainless steel A.I.S.I. 304 and A.I.S.I. 316. Wells are also available in special materials; prices on request.

Protective Coatings for Thermowells: OMEGA can add a protective coating of PFA.

Contact OMEGA Custom Engineering for a quotation.



To Order Visit omega.com/260_commodity for Pricing and Details					
Ext Thread	Model Number	Material	Well Type	Insert Length	Stem Length
½ NPT	1/2-260L-U21/2-304SS-F	304 SS	260L	2½"	6"
	1/2-260L-U21/2-316SS-F	316 SS	260L	2½"	6"
½ NPT	1/2-260S-U21/2-304SS-F	304 SS	260S	2½"	4"
	1/2-260S-U21/2-316SS-F	316 SS	260S	2½"	4"
	1/2-260S-U21/2-BRASS-F	Brass	260S	2½"	4"
	1/2-260S-U41/2-304SS-F	304 SS	260S	4½"	6"
	1/2-260S-U41/2-316SS-F	316 SS	260S	4½"	6"
	1/2-260S-U71/2-304SS-F	304 SS	260S	7½"	9"
¾ NPT	3/4-260L-U21/2-304SS-F	304 SS	260L	2½"	6"
	3/4-260L-U41/2-304SS-F	304 SS	260S	4½"	9"
¾ NPT	3/4-260S-U21/2-304SS-F	304 SS	260S	2½"	4"
	3/4-260S-U21/2-316SS-F	316 SS	260S	2½"	4"
	3/4-260S-U21/2-BRASS-F	Brass	260S	2½"	4"
	3/4-260S-U41/2-304SS-F	304 SS	260S	4½"	6"
	3/4-260S-U41/2-316SS-F	316 SS	260S	4½"	6"
	3/4-260S-U71/2-304SS-F	304 SS	260S	7½"	9"
¾ NPT	3/4-260A-U15/8-304SS-F	304 SS	260A	1 5/8"	2½"

10 piece minimum order. Prices subject to change due to fluctuations in material and other costs. Check for price at time of order.

Ordering Example: Quantity 10, 3/4-260S-U712-304SS-F, 304 stainless steel thermowell with ¾ NPT external thread, 0.260" internal diameter, 7½" insertion length and a 9" stem length.

For Assistance in Choosing Head and Well Assemblies, See Guide at omega.com. These wells are compatible with OMEGA® NB1, NB2; PR-12, PR14, and NPT-style probes; as well as DialTemp™ Thermometers. PFA coating available, see omega.com.

Increase Response Rate!
Use OT-201 Conductive Silicon Paste;
see omega.com.

Pressure-Temperature rating—lb per square inch

Material	Temperature — °F						
	70°	200°	400°	600°	800°	1000°	1200°
Brass	2810	2530	440	—	—	—	—
A.I.S.I. 304	4120	3740	3400	3280	3180	2750	990
A.I.S.I. 316	4120	4120	3850	3760	3680	3080	1490

Discount Schedule	
1-10.....	Net
11-24.....	10%
25-100.....	20%
101 and up.....	Consult Sales

Discounts apply to similar thermowells.

See omega.com For Maximum Fluid Velocity.