

# Non-Reversible OMEGALABEL<sup>®</sup> Temperature Monitors

## Button Series


4 temperature ratings on each label.  
Temperatures are read clockwise starting at the "V" mark:

**Outside Diameter:** 8 mm (0.3")

**Indicating Window:** 1.2 mm (0.05")

To order package of 30, add suffix "-30" to model number.

**Ordering Example:** BUA2-180/82-30, button series label 82 to 99°C (180 to 210°F), package of 30.

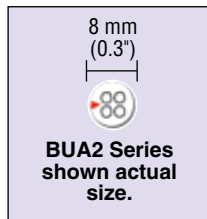

Model No. (Pkg 10)	Temperature Ratings				
BUA2-120/49	°C	49	54	60	66
	°F	120	130	140	150
BUA2-140/60	°C	60	66	71	77
	°F	140	150	160	170
BUA2-180/82	°C	82	88	93	99
	°F	180	190	220	210
BUA2-175/79	°C	79	93	107	121
	°F	175	200	225	250

## Specifications

**Accuracy:** Up to 99°C (210°F) is ±2°C (1.8°F); From 100°C (212°F) to 154°C (309°F) is ±2°C (2.7°F); From 160°C (320°F) to 280°C (536°F) is ±2% and ±2°C (1.8°F)

## Series 6M

6 temperature ratings on each label:

**6MA:** 6°C (10°F) between each rating


**6MB:** 13.9°C (25°F) between each rating

**Actual Size:** 32 x 10 mm (1.3 x 0.4")

**Indicating Window:** 0.4 x 3 mm (0.02 x 0.13")

To order package of 30, add suffix "-30" to model number.

**Ordering Example:** 6MA-130/54-30, 6 temperature rating 54 to 82°C (130 to 180°F), package of 30.

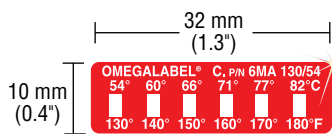

Model No. (Pkg 10)	Temperature Ratings						
6MA-100/38	°C	38	43	49	54	60	66
	°F	100	110	120	130	140	150
6MA-130/54	°C	54	60	66	71	77	82
	°F	130	140	150	160	170	180
6MA-160/71	°C	71	77	82	88	93	99
	°F	160	170	180	190	200	210
6MA-190/88	°C	88	93	99	104	110	116
	°F	190	200	210	220	230	240
6MA-220/104	°C	104	110	116	121	127	132
	°F	220	230	240	250	260	270
6MA-250/21	°C	121	127	132	138	143	149
	°F	250	260	270	280	290	300
6MB-100/38	°C	38	52	66	79	93	107
	°F	100	125	150	175	200	225
6MB-175/79	°C	79	93	107	121	135	149
	°F	175	200	225	250	275	300

## Series 8M

8 temperature ratings on each label:

**8MA:** 5.6°C (10°F) between each rating


**8MB:** 13.9°C (25°F) between each rating

**Actual Size:** 42 x 10 mm (1.6 x 0.4")

**Indicating Window:** 0.4 x 3 mm (0.02 x 0.13")

To order package of 30, add suffix "-30" to model number

**Ordering Example:** 8MA-180/82-30, 8 temperature rating, 82 to 121°C (180 to 250°F), package of 30.

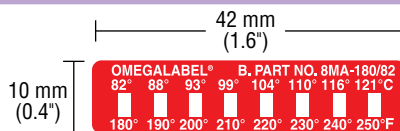

Model No. (Pkg 10)	Temperature Ratings								
8MA-100/38	°C	38	43	49	54	60	66	71	77
	°F	100	110	120	130	140	150	160	170
8MA-140/60	°C	60	66	71	77	82	88	93	99
	°F	140	150	160	170	180	190	200	210
8MA-180/82	°C	82	88	93	99	104	110	116	121
	°F	180	190	200	210	220	230	240	250
8MA-230/110	°C	110	116	121	127	132	138	143	149
	°F	230	240	250	260	270	280	290	300
8MB-100/38	°C	38	52	66	79	93	107	121	135
	°F	100	125	150	175	200	225	250	275

## ML4C Series, Mini Labels


4 temperature ratings per label:

**Actual Size:** 12 x 5 mm (0.5 x 0.2")

**Indicating Circle:** 1.5 mm (0.06")

To order package of 30, add suffix "-30" to model number.

**Ordering Example:** ML4C-40-30, mini label, 4 temperature rating (40 to 49°C), package of 30.

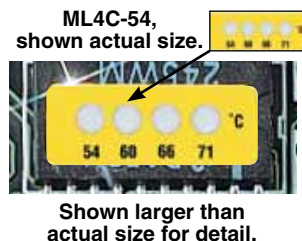

Model No. (Pkg 10)	Temperature Ratings				
ML4C-40	°C	40	43	46	49
ML4C-54	°C	54	60	66	71
ML4C-77	°C	77	82	88	93
ML4C-99	°C	99	104	110	116
ML4C-121	°C	121	127	132	138
ML4C-143	°C	143	149	154	160
ML4C-166	°C	166	171	177	182
ML4C-188	°C	188	193	199	204
ML4C-210	°C	210	216	224	232
ML4C-241	°C	241	249	254	260