

UL Listed Twisted Shielded Extension Grade Thermocouple Wire



TWSH-UL Wire
1000' Spool



ANSI color code shown To order IEC color code visit us online




- ✓ UL Listed Type PLTC, 300V; Listed Under UL Subject 13, File E153789
- ✓ Extruded PVC Single Conductor and Duplex Insulation
- ✓ ANSI Color Coded
- ✓ Aluminized Polyester Shield with Drain Wire Reduces Electrical Noise
- ✓ Resistant to Moisture, Abrasion, Chemicals, and UV Light

For Longer Lengths Consult Sales for Price and Delivery!

OMEGA™ twisted/shielded thermocouple wire is ideal for systems sensitive to induced voltages and electrical noise. The wire conductors are insulated with color-coded PVC, then twisted with a tin/copper drain wire.


Next, an aluminized polyester tape is wrapped around the wires, followed by a final layer of PVC coating. The wire is UL listed for Power Limited Tray Cable (PLTC) applications.

Note: Overbraiding wire invalidates UL rating.

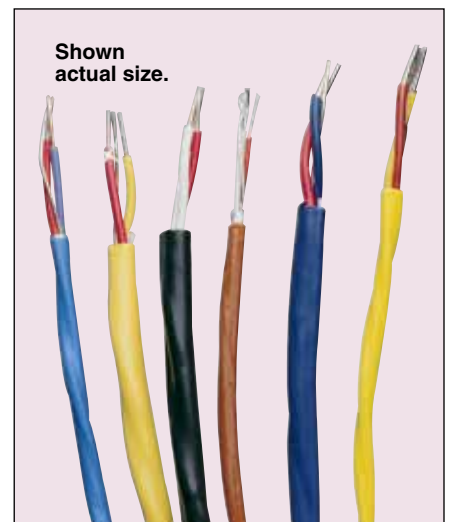

Shown actual size.

Wire is shielded and supplied with an integral tin/copper drain wire.

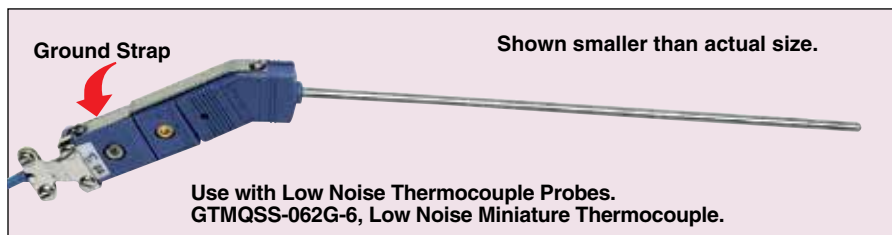

Ground Strap

Shown smaller than actual size.

Use with Low Noise Thermocouple Probes. GTMQSS-062G-6, Low Noise Miniature Thermocouple.

Extension Grade
CHROMEGLA™
ALOMEGA™
 Duplex
KX
 ANSI Type KX

All models shown smaller than actual size.



ANSI Color Code: Positive Wire, Yellow; Negative Wire, Red; Overall, Yellow

To Order

Model Number	AWG	Bare Conductor Diameter		Nominal Insulation Thickness				Nominal Overall Size		Approx Ship Wt kg/300 m (lb/1000') spool
				Conductor		Overall				
		inches	mm	inches	mm	inches	mm	inches	mm	
EXPP-K-16-TWSH-UL	16	0.051	1.3	0.020	0.51	0.035	0.89	0.290	7.4	22.2 (49)
EXPP-K-16S-TWSH-UL	16S	0.060	1.5	0.020	0.51	0.035	0.89	0.290	7.4	22.7 (50)
EXPP-K-20-TWSH-UL	20	0.032	0.81	0.015	0.38	0.035	0.89	0.225	5.7	12.7 (28)
EXPP-K-20S-TWSH-UL	20S	0.038	0.97	0.015	0.38	0.035	0.89	0.230	5.7	13.6 (30)

Ordering Example: EXPP-K-20-TWSH-UL-1000, 1000' of extension grade thermocouple wire, 20 gage, type KX, twisted shielded, UL listed.

Extension Grade
 Iron/Constantan
 Duplex
JX
 ANSI Type JX

ANSI Color Code: Positive Wire, White; Negative Wire, Red; Overall, Black



Model Number	AWG	Bare Conductor Diameter		Nominal Insulation Thickness				Nominal Overall Size		Approx Ship Wt kg/300 m (lb/1000') spool
				Conductor		Overall				
		inches	mm	inches	mm	inches	mm	inches	mm	
EXPP-J-16-TWSH-UL	16	0.051	1.3	0.020	0.51	0.035	0.89	0.290	7.4	22.2 (49)
EXPP-J-16S-TWSH-UL	16S	0.060	1.5	0.020	0.51	0.035	0.89	0.290	7.4	22.7 (50)
EXPP-J-20-TWSH-UL	20	0.032	0.81	0.015	0.38	0.035	0.89	0.225	5.7	12.7 (28)
EXPP-J-20S-TWSH-UL	20S	0.038	0.97	0.015	0.38	0.035	0.89	0.230	5.8	13.6 (30)

Ordering Example: EXPP-J-20-TWSH-UL-1000, 1000' of extension grade thermocouple wire, twisted shielded, type JX, 20 gage, UL listed.

Extension Grade
 Copper/Constantan
 Duplex
TX
 ANSI Type TX

ANSI Color Code: Positive Wire, Blue; Negative Wire, Red; Overall, Blue



Model Number	AWG	Bare Conductor Diameter		Nominal Insulation Thickness				Nominal Overall Size		Approx Ship Wt kg/300 m (lb/1000') spool
				Conductor		Overall				
		inches	mm	inches	mm	inches	mm	inches	mm	
EXPP-T-16-TWSH-UL	16	0.051	1.3	0.020	0.51	0.035	0.89	0.290	7.4	22.2 (49)
EXPP-T-16S-TWSH-UL	16S	0.060	1.5	0.020	0.51	0.035	0.89	0.290	7.4	22.7 (50)
EXPP-T-20-TWSH-UL	20	0.032	0.81	0.015	0.38	0.035	0.89	0.225	5.7	12.7 (28)
EXPP-T-20S-TWSH-UL	20S	0.038	0.97	0.015	0.38	0.035	0.89	0.230	5.8	13.6 (24)

Ordering Example: EXPP-T-20-TWSH-UL-500, 500' of extension grade thermocouple wire, twisted shielded, type TX, 20 gage, UL listed.

Extension Grade
CHROMEGLA™
 Constantan
 Duplex
EX
 ANSI Type EX

ANSI Color Code: Positive Wire, Purple; Negative Wire, Red; Overall, Purple



Model Number	AWG	Bare Conductor Diameter		Nominal Insulation Thickness				Nominal Overall Size		Approx Ship Wt kg/300 m (lb/1000') spool
				Conductor		Overall				
		inches	mm	inches	mm	inches	mm	inches	mm	
EXPP-E-16-TWSH-UL	16	0.051	1.3	0.020	0.51	0.035	0.89	0.290	7.4	22.2 (49)
EXPP-E-16S-TWSH-UL	16S	0.060	1.5	0.020	0.51	0.035	0.89	0.290	7.4	22.7 (50)
EXPP-E-20-TWSH-UL	20	0.032	0.81	0.015	0.38	0.035	0.89	0.225	5.7	12.7 (28)
EXPP-E-20S-TWSH-UL	20S	0.038	0.97	0.015	0.38	0.035	0.89	0.230	5.8	13.6 (24)

Ordering Example: EXPP-E-20-TWSH-UL-1000, 1000' of extension grade thermocouple wire, twisted shielded, type EX, 20 gage, UL listed.