


General-Purpose, Thermometers


Economical, Ideal for School and Laboratory Applications!

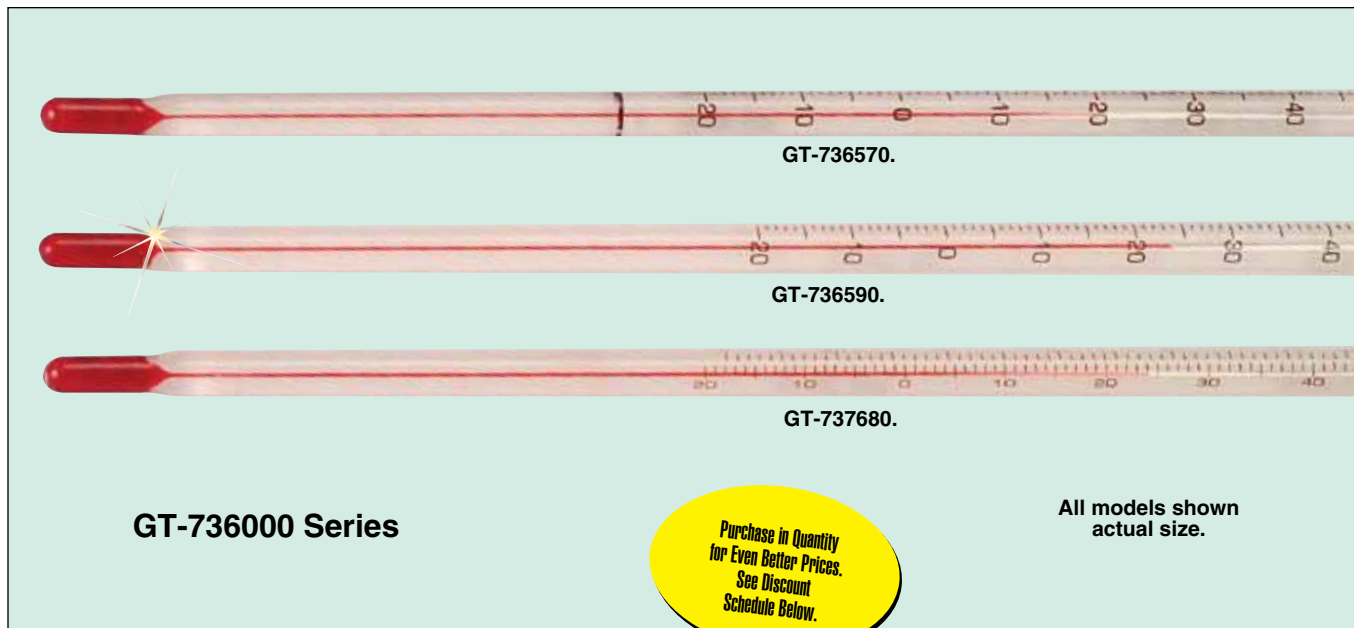

Red Liquid-Filled Models
Partial and Total Immersion Styles
305 mm (12") and 150 mm (6") Lengths
Variety of Single and Dual
Temperature Ranges

*Perfect Where
 Glass Thermometers
 are Purchased
 Frequently!*

Economical glass-bulb thermometers are ideal for school and laboratory applications. These general-purpose, easy-to-read white back units are available with red liquid filling, in a variety of ranges and styles.

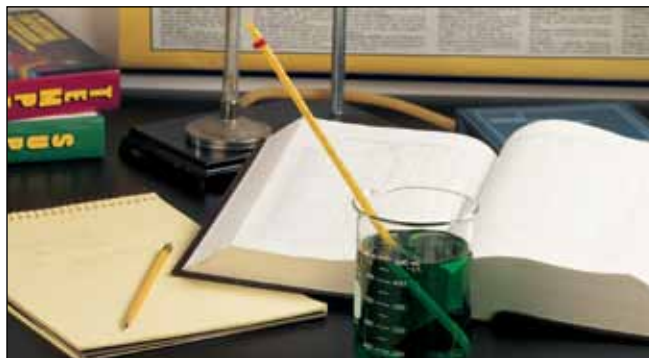

Available with red safety liquid, in a variety of ranges and styles.

| Discount Schedule for Economical Thermometers | |
|---|-----|
| 11 to 24 Units | 10% |
| 25 to 49 Units | 15% |
| 50 to 99 | 20% |

| To Order | | | |
|--|-----------------------------|-----------|-------------|
| Visit omega.com/gt-736000_thermometers for Pricing and Details | | | |
| Model No. | Length Range | mm (inch) | Div |
| Red Organic Safety, White Back, Partial Immersion Calibrated at 76 mm | | | |
| GT-736570 | -20 to 110°C | 305 (12) | 1° |
| GT-736580 | -20 to 150°C | 305 (12) | 1° |
| GT-737000 | 0 to 230°F | 305 (12) | 2° |
| GT-736780 | -20 to 110°C/ 0 to 230°F | 305 (12) | 1°C/ 2°F |
| Red Organic Safety, White Back, Total Immersion | | | |
| GT-736590 | -20 to 110°C | 305 (12) | 1° |
| GT-736600 | -20 to 150°C | 305 (12) | 1° |
| GT-737680 | -20 to 110°C/ 0 to 230°F | 305 (12) | 1°C/ 2°F |
| Low Range Red Organic Safety, White Back, Total Immersion | | | |
| GT-736620 | -50 to 50°C | 305 (12) | 1° |
| Student Red Organic Safety, Partial Immersion Calibrated at 76 mm | | | |
| GT-736630 | -10 to 110°C | 150 (6) | 1° |
| GT-738640 | -10 to 110°C/ 0 to 230°F | 150 (6) | 1°C/ 2°F |

Comes complete in a protective plastic shipping tube.
Ordering Example: GT-737680, dual range [-20 to 110°C (0 to 230°F)] total immersion, red safety thermometer.