

SANITARY TEMPERATURE SENSORS

Food Service Thermometer

- ✓ Simple to Operate
- ✓ Waterproof Case
- ✓ Type T and Thermistor Models
- ✓ Long Battery Life (Typically 500 Hours), Battery Included
- ✓ Rugged Case for Use in Harsh Environments
- ✓ Ergonomic Design
- ✓ "Hold" Function
- ✓ °F or °C Settings
- ✓ Isolated Battery Compartment

Waterproof!

HH2106T/2146T Series




Optional†

The HH2106T and HH2146T build on the success of the HH2000 series thermometers.

This generation marks an evolutionary step in the development of OMEGA's digital thermometers and probes. These thermometers are completely waterproof and incorporate the Food Industry standard Lumberg connector for thermistor and thermocouple probes.

HH2146TC and THX-HH2146T penetration probe, sold separately, see ordering chart below. Shown smaller than actual size.

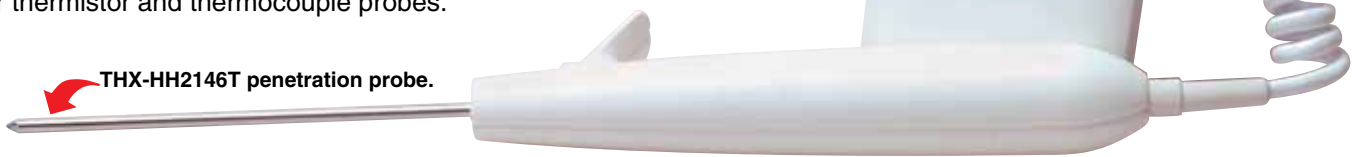

THX-HH2146T penetration probe.

Specifications

GENERAL

Battery: 2 "AA" size (included)
Dimensions: 155 H x 65 W x 35 mm D (6.1 x 2.5 x 1.4")
Weight: 250 g (8 oz)

HH2146TC/HH2146TF

Sensor Type: Thermistor, THX-HH2146T
Connector Type: Lumberg
Probe: 316 stainless steel
Setting: HH2146TC reads in °C; HH2146TF reads in °F

Instrument Accuracy: ±0.5°C (0.4°F) over range -20 to 70°C (-4 to 158°F), ±0.8°C (1.4°F) elsewhere

Hold Function: Yes
Range: -40 to 120°C (-40 to 248°F)


HH2106TC/HH2106TF

Sensor Type: Type T thermocouple, THX-HH2106T

Connector Type: Lumberg
Probe: 316 stainless steel
Setting: HH2106TC reads in °C; HH2106TF reads in °F

Instrument Accuracy: ±0.2°C (0.4°F) over range -20 to 70°C (-4 to 158°F), ±0.1% rdg, ±0.2°C (0.4°F) elsewhere

Hold Function: Yes
Range: -250 to 400°C (-418 to 752°F)

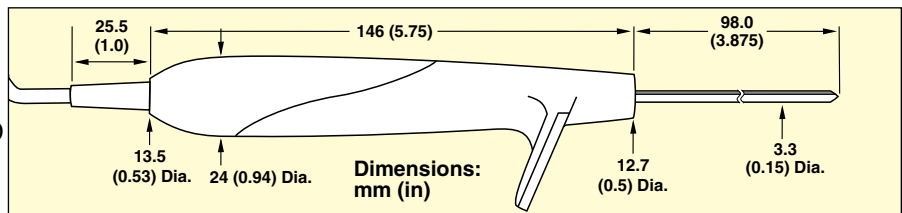

OMEGACARESM extended warranty program is available for models shown on this page. Ask your sales representative for full details when placing an order. OMEGACARESM covers parts, labor and equivalent loaners.

To Order

Model No.	Description
HH2146TC	Series 400 thermistor handheld thermometer, °C
HH2146TF	Series 400 thermistor handheld thermometer, °F
HH2106TC	Type T thermocouple handheld thermometer, °C
HH2106TF	Type T thermocouple handheld thermometer, °F
HH-NIST†	NIST-traceable calibration, no points
CAL-3-HH†	NIST-traceable calibration with points

Probes

Model No.	Description
THX-HH2146T	Penetration probe (for HH2146TC or HH2146TF)
THX-HH2106T	Penetration probe (for HH2106TC or HH2106TF)

Comes complete with 2 "AA" batteries, rubber boot and operator's manual. Order probe separately above.

Ordering Examples: HH2146TC and THX-HH2146T, handheld thermometer in °C, thermistor sensor type with penetration probe. OCW-3, OMEGACARESM extends standard 2-year warranty to a total of 5 years.

HH2106TF, Type T handheld thermometer in °F.