


# Quick Disconnect



# Thermocouples with Removable Standard Size Connectors

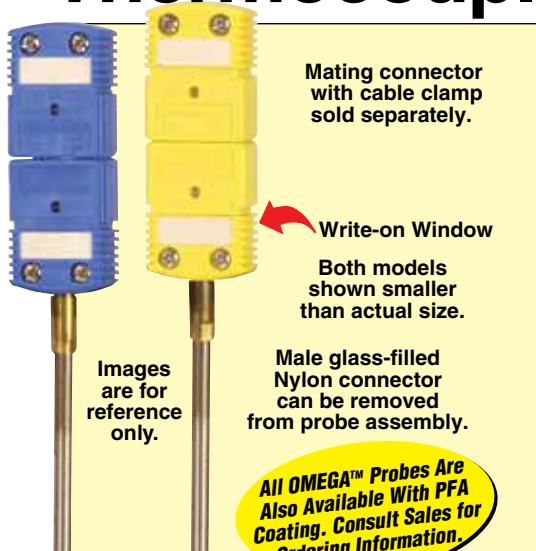

Mating connector with cable clamp sold separately.

Write-on Window

Both models shown smaller than actual size.

Male glass-filled Nylon connector can be removed from probe assembly.

Images are for reference only.

All OMEGA™ Probes Are Also Available With PFA Coating. Consult Sales for Ordering Information.



- ✓ Standard Size OSTW Probe Termination
- ✓ 300 mm (12"), 450 mm (18") and 600 mm (24") Lengths in Stock†
- ✓ Choice of 304, 316, 321 SS, Inconel Sheath or Super OMEGACLAD™ XL Sheath
- ✓ Diameters from 1.5 to 6.0 mm (1/16 to 1/4")
- ✓ Connector Body Rated to 180°C (356°F)

Note: Minor discoloration of connector may occur between 150°C (302°F) and 180°C (356°F). Electrical properties are not affected.

Omega™ quick disconnect thermocouple Assemblies feature standard size OSTW thermocouple connectors, with probes from 1/16 to 1/4". These probes are available with grounded, ungrounded or exposed junctions with 304, 316, or 321 stainless steel or Inconel sheaths.

## To Order

Thermocouple Alloy	Sheath Dia. mm (inch)	Model No. 300 mm (12") Length	Model No. 450 mm (18") Length	Model No. 600 mm (24") Length
IRON-CONSTANTAN Inconel Sheath <b>J</b>	1.5 (1/16)	ICIN-116(*)-12	ICIN-116(*)-18	ICIN-116(*)-24
	3.0 (1/8)	ICIN-18(*)-12	ICIN-18(*)-18	ICIN-18(*)-24
	4.5 (3/16)	ICIN-316(*)-12	ICIN-316(*)-18	ICIN-316(*)-24
	6.0 (1/4)	ICIN-14(*)-12	ICIN-14(*)-18	ICIN-14(*)-24
IRON-CONSTANTAN 304 SS Sheath <b>J</b>	1.5 (1/16)	ICSS-116(*)-12	ICSS-116(*)-18	ICSS-116(*)-24
	3.0 (1/8)	ICSS-18(*)-12	ICSS-18(*)-18	ICSS-18(*)-24
	4.5 (3/16)	ICSS-316(*)-12	ICSS-316(*)-18	ICSS-316(*)-24
	6.0 (1/4)	ICSS-14(*)-12	ICSS-14(*)-18	ICSS-14(*)-24
CHROMEGLA™ ALOMEGA™ Inconel Sheath <b>K</b>	1.5 (1/16)	CAIN-116(*)-12	CAIN-116(*)-18	CAIN-116(*)-24
	3.0 (1/8)	CAIN-18(*)-12	CAIN-18(*)-18	CAIN-18(*)-24
	4.5 (3/16)	CAIN-316(*)-12	CAIN-316(*)-18	CAIN-316(*)-24
	6.0 (1/4)	CAIN-14(*)-12	CAIN-14(*)-18	CAIN-14(*)-24
CHROMEGLA™ ** ALOMEGA™ 304 SS Sheath <b>K</b>	1.5 (1/16)	CASS-116(*)-12	CASS-116(*)-18	CASS-116(*)-24
	3.0 (1/8)	CASS-18(*)-12	CASS-18(*)-18	CASS-18(*)-24
	4.5 (3/16)	CASS-316(*)-12	CASS-316(*)-18	CASS-316(*)-24
	6.0 (1/4)	CASS-14(*)-12	CASS-14(*)-18	CASS-14(*)-24
CHROMEGLA™- CONSTANTAN Inconel Sheath <b>E</b>	1.5 (1/16)	CXIN-116(*)-12	CXIN-116(*)-18	CXIN-116(*)-24
	3.0 (1/8)	CXIN-18(*)-12	CXIN-18(*)-18	CXIN-18(*)-24
	4.5 (3/16)	CXIN-316(*)-12	CXIN-316(*)-18	CXIN-316(*)-24
	6.0 (1/4)	CXIN-14(*)-12	CXIN-14(*)-18	CXIN-14(*)-24
CHROMEGLA™- CONSTANTAN 304 SS Sheath <b>E</b>	1.5 (1/16)	CXSS-116(*)-12	CXSS-116(*)-18	CXSS-116(*)-24
	3.0 (1/8)	CXSS-18(*)-12	CXSS-18(*)-18	CXSS-18(*)-24
	4.5 (3/16)	CXSS-316(*)-12	CXSS-316(*)-18	CXSS-316(*)-24
	6.0 (1/4)	CXSS-14(*)-12	CXSS-14(*)-18	CXSS-14(*)-24
COPPER- CONSTANTAN Inconel Sheath <b>T</b>	1.5 (1/16)	CPIN-116(*)-12	CPIN-116(*)-18	CPIN-116(*)-24
	3.0 (1/8)	CPIN-18(*)-12	CPIN-18(*)-18	CPIN-18(*)-24
	4.5 (3/16)	CPIN-316(*)-12	CPIN-316(*)-18	CPIN-316(*)-24
	6.0 (1/4)	CPIN-14(*)-12	CPIN-14(*)-18	CPIN-14(*)-24
COPPER- CONSTANTAN 304 SS Sheath <b>T</b>	1.5 (1/16)	CPSS-116(*)-12	CPSS-116(*)-18	CPSS-116(*)-24
	3.0 (1/8)	CPSS-18(*)-12	CPSS-18(*)-18	CPSS-18(*)-24
	4.5 (3/16)	CPSS-316(*)-12	CPSS-316(*)-18	CPSS-316(*)-24
	6.0 (1/4)	CPSS-14(*)-12	CPSS-14(*)-18	CPSS-14(*)-24
OMEGALLOY™ ** NICROSIL-NISIL Inconel Sheath <b>N</b>	1.5 (1/16)	NNIN-116(*)-12	NNIN-116(*)-18	NNIN-116(*)-24
	3.0 (1/8)	NNIN-18(*)-12	NNIN-18(*)-18	NNIN-18(*)-24
	4.5 (3/16)	NNIN-316(*)-12	NNIN-316(*)-18	NNIN-316(*)-24
	6.0 (1/4)	NNIN-14(*)-12	NNIN-14(*)-18	NNIN-14(*)-24

Note: Length of probe is measured from the bottom of the brass block to the tip of the probe.

† Other lengths available, consult Sales department.

\* Specify junction type: "E" (Exposed), "G" (Grounded) or "U" (Ungrounded). To order with 316, 316L or 321 stainless steel sheath, change "SS" in model number to "316SS", "316LSS" or "321SS" respectively, no additional charge. To order replacement probe, no connector, add "-RP" to model number for reduced cost. \*\* To order Super OMEGACLAD™ XL, change "IN" to "XL" for additional cost.

Ordering Example: CAXL-18U-12, quick disconnect probe, Type K (CHROMEGLA™-ALOMEGA™), Super OMEGACLAD™ XL sheath, 3 mm (1/8") OD, ungrounded junction, 300 mm (12") length.

A321SS-18G-12, quick disconnect probe, Type K (CHROMEGLA™-ALOMEGA™), 321 SS sheath, 1/8" OD grounded junction.

Thermocouple Alloy	Model No. 300 mm (12") Length	Model No. 450 mm (18") Length	Model No. 600 mm (24") Length	Mating Connector Model No.	Cable Clamp Model No.	Safety Clip Model No.
IRON-CONSTANTAN Inconel Sheath <b>J</b>	ICIN-116(*)-12 ICIN-18(*)-12 ICIN-316(*)-12 ICIN-14(*)-12	ICIN-116(*)-18 ICIN-18(*)-18 ICIN-316(*)-18 ICIN-14(*)-18	ICIN-116(*)-24 ICIN-18(*)-24 ICIN-316(*)-24 ICIN-14(*)-24	OSTW-J-F		
IRON-CONSTANTAN 304 SS Sheath <b>J</b>	ICSS-116(*)-12 ICSS-18(*)-12 ICSS-316(*)-12 ICSS-14(*)-12	ICSS-116(*)-18 ICSS-18(*)-18 ICSS-316(*)-18 ICSS-14(*)-18	ICSS-116(*)-24 ICSS-18(*)-24 ICSS-316(*)-24 ICSS-14(*)-24			
CHROMEGLA™ ALOMEGA™ Inconel Sheath <b>K</b>	CAIN-116(*)-12 CAIN-18(*)-12 CAIN-316(*)-12 CAIN-14(*)-12	CAIN-116(*)-18 CAIN-18(*)-18 CAIN-316(*)-18 CAIN-14(*)-18	CAIN-116(*)-24 CAIN-18(*)-24 CAIN-316(*)-24 CAIN-14(*)-24	OSTW-K-F		
CHROMEGLA™** ALOMEGA™ 304 SS Sheath <b>K</b>	CASS-116(*)-12 CASS-18(*)-12 CASS-316(*)-12 CASS-14(*)-12	CASS-116(*)-18 CASS-18(*)-18 CASS-316(*)-18 CASS-14(*)-18	CASS-116(*)-24 CASS-18(*)-24 CASS-316(*)-24 CASS-14(*)-24			
CHROMEGLA™ CONSTANTAN Inconel Sheath <b>E</b>	CXIN-116(*)-12 CXIN-18(*)-12 CXIN-316(*)-12 CXIN-14(*)-12	CXIN-116(*)-18 CXIN-18(*)-18 CXIN-316(*)-18 CXIN-14(*)-18	CXIN-116(*)-24 CXIN-18(*)-24 CXIN-316(*)-24 CXIN-14(*)-24	OSTW-E-F	PCLM	SFCL
CHROMEGLA™ CONSTANTAN 304 SS Sheath <b>E</b>	CXSS-116(*)-12 CXSS-18(*)-12 CXSS-316(*)-12 CXSS-14(*)-12	CXSS-116(*)-18 CXSS-18(*)-18 CXSS-316(*)-18 CXSS-14(*)-18	CXSS-116(*)-24 CXSS-18(*)-24 CXSS-316(*)-24 CXSS-14(*)-24			
COPPER-CONSTANTAN Inconel Sheath <b>T</b>	CPIN-116(*)-12 CPIN-18(*)-12 CPIN-316(*)-12 CPIN-14(*)-12	CPIN-116(*)-18 CPIN-18(*)-18 CPIN-316(*)-18 CPIN-14(*)-18	CPIN-116(*)-24 CPIN-18(*)-24 CPIN-316(*)-24 CPIN-14(*)-24	OSTW-T-F		
COPPER-CONSTANTAN 304 SS Sheath <b>T</b>	CPSS-116(*)-12 CPSS-18(*)-12 CPSS-316(*)-12 CPSS-14(*)-12	CPSS-116(*)-18 CPSS-18(*)-18 CPSS-316(*)-18 CPSS-14(*)-18	CPSS-116(*)-24 CPSS-18(*)-24 CPSS-316(*)-24 CPSS-14(*)-24			
OMEGALLOY™** NICROSIL-NISIL Inconel Sheath <b>N</b>	NNIN-116(*)-12 NNIN-18(*)-12 NNIN-316(*)-12 NNIN-14(*)-12	NNIN-116(*)-18 NNIN-18(*)-18 NNIN-316(*)-18 NNIN-14(*)-18	NNIN-116(*)-24 NNIN-18(*)-24 NNIN-316(*)-24 NNIN-14(*)-24	OSTW-N-F		

All Accessories Sold Separately.

\* Specify junction type: "E" (Exposed), "G" (Grounded) or "U" (Ungrounded).

\*\* To order Super OMEGACLAD™ XL, change "IN" to "XL" for additional cost.