

# Standard Conduit Box Connector Systems



## JPCB

- ✓ Quick Disconnect
- ✓ Color-Coded
- ✓ 5 Standard Rectangular Connectors or 6 Round Connector Terminals
- ✓ 3-Prong Models Also Available
- ✓ Quick Release Snap Action Handle
- ✓ 3/4 NPT Fittings



JPCB-5-K-F.

JPCB-5-K-M.

To Order	
Model No.	Description
JPCB-5-(*)-M	5-circuit standard conduit box, male
JPCB-5-(*)-F	5-circuit standard conduit box, female
TJPCB-4-(*)-M	4-circuit 3-prong conduit box, male
TJPCB-4-(*)-F	4-circuit 3-prong conduit box, female
RJPCB-6-(*)-M	6-circuit round connector conduit box, male
RJPCB-6-(*)-F	6-circuit round connector conduit box, female



Optional supply of standard size SPJ-CAP-12 package of 12 Wire and cable clamp (JB-CC) sold separately.




Wire and cable clamp (JB-CC) sold separately.

\*Specify Calibration: J, K, T, E, R/S or U, ANSI color coded.

All models shown smaller than actual size.

## Miniature Conduit Box Connector Systems

- ✓ 3/4 NPT Fittings
- ✓ Quick Disconnect Miniature Connectors
- ✓ Color-Coded
- ✓ Up to 6 Positions Available
- ✓ Straight, Right Hand, Left Hand and Butt End Configurations

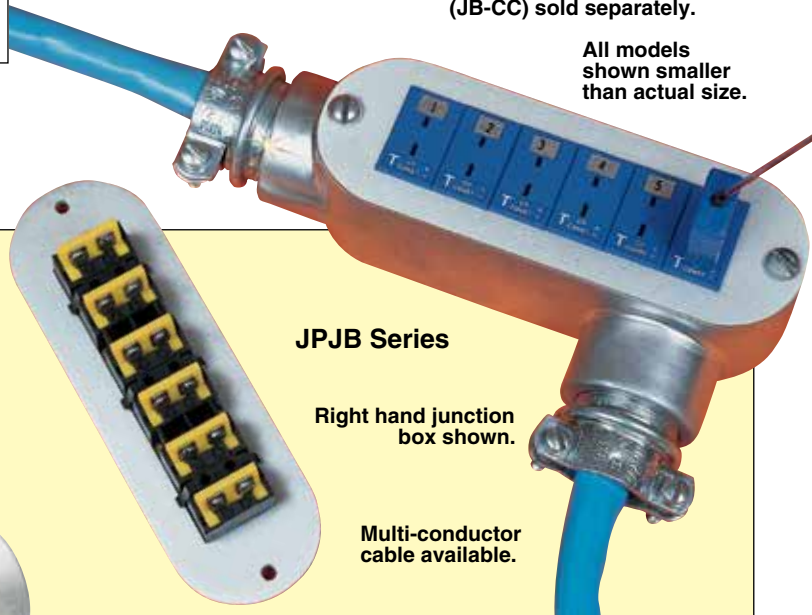

JPJB Series

Right hand junction box shown.

Multi-conductor cable available.

JPJB-6-K-ST.



Dust Cap

Optional miniature dust cap MPJ-CAP-12, package of 12.

Model No.	Description
JPJB-(†)-(*)-ST	Junction box, straight
JPJB-(†)-(*)-RH	Junction box, right hand
JPJB-(†)-(*)-LH	Junction box, left hand
JPJB-(†)-(*)-BE	Junction box, butt end

† Specify number of positions, 1, 2, 3, 4, 5 or 6.

\* Specify Calibration: J, K, T, E, R/S, N or U.

Ordering Example: JPJB-5-T-RH, 5-position junction box, Type T, right hand configuration.