

Jack Panels

With Miniature 3-Prong Connectors



MTP Series

ANSI color code shown	To order IEC color code visit us online
-----------------------	-----------------------------------------




Shown slightly smaller than actual size.

Male connector and wire sold separately.

- ✓ **Compact Design for MTP Series Connectors**
- ✓ **Perfect for Shielded Thermocouples, RTD's and 700 Series Thermistors**
- ✓ **2.4 mm ($\frac{3}{32}$ " Panel Thickness**
- ✓ **Available in J, K, T, E, N, and U Calibrations**

Panel Mounting Bracket for MTP Connector Model MTACL.
Panel Opening: 23.72 H x 8.08 mm W (0.93 x 0.32")

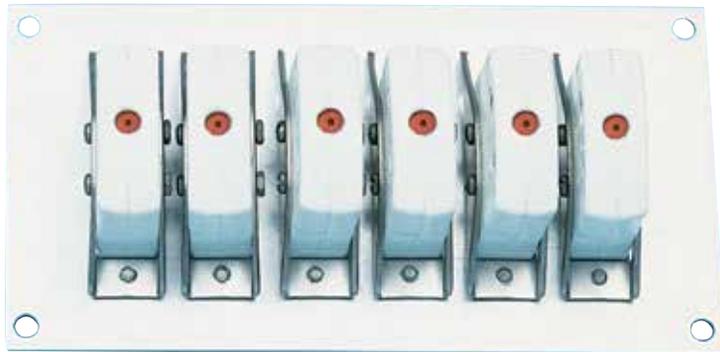

Prices for J, K, T, E, N, or U calibrations are available on our website:

To order individual Additional connectors, specify MTP-(*)-F. and specify MTACL mounting bracket for an additional cost.

Consult Custom Engineering Department for information on custom color-coded anodized panels. Non-standard Panels: \$1,000 minimum order. Contact custom@omega.com for pricing and availability.

To Order

Circuits Per Row		1 Row (1 $\frac{1}{4}$ " H)	2 Rows (3 $\frac{1}{4}$ " H)	3 Rows (4 $\frac{3}{8}$ " H)	4 Rows (6 $\frac{1}{8}$ " H)
6 (4 $\frac{3}{8}$ " L)	Model No.	MTP1-06-(*)	MTP2-12-(*)	MTP3-18-(*)	MTP4-24-(*)
12** (8 $\frac{1}{8}$ " L)	Model No.	MTP1-12-(*)	MTP2-24-(*)	MTP3-36-(*)	MTP4-48-(*)
18** (11 $\frac{1}{8}$ " L)	Model No.	MTP1-18-(*)	MTP2-36-(*)	MTP3-54-(*)	MTP4-72-(*)

*Insert thermocouple calibration code: J, K, T, E, N or U.

** 6 mounting holes per panel.

Shipped unassembled. Minimum order required for non-standard.

Ordering Example: MTP4-24-K, Four-row jack panel with Type K connector.