


# High-Temperature Jack Panels

## For Standard Ceramic Connectors

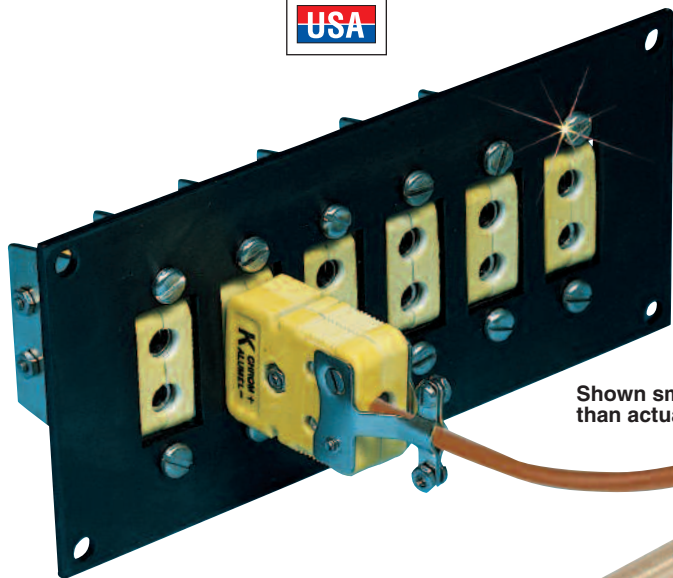

Shown smaller than actual size.


**NXJP Series Starts at \$79**

OMEGA® high-temperature jack panels feature ceramic connectors mounted in a steel plate for service temperatures up to 538°C (1000°F).

- ✓ For Service up to 538°C (1000°F)
- ✓ Ceramic Connectors
- ✓ Steel Panel
- ✓ Compensated Hardware

TT-K-20-SLE wire, \$32 per 7.62 m (25').

CASS-14G-12-NOX, \$40.50; consult sales to order

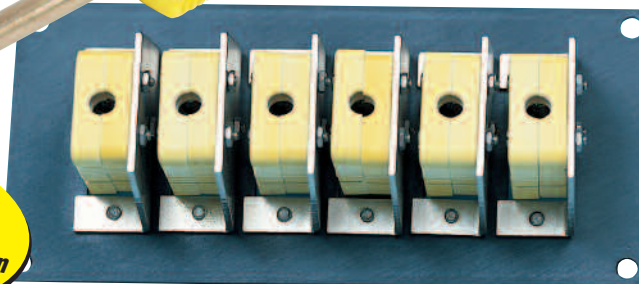

Upper temperature limit is determined by alloy type.

**See Section A for Additional Thermocouple Probes and Connector Extension Assemblies**

Screw Holes: 35 mm H (1.38"), center-to-center

### Price and Quantity Discount Information


Prices shown are for J, K, T, E, R, S, N, G, C, D, and U calibrations. To price more than one panel of any type, use the following price schedule:

- 1 Row.....\$25 per panel, + connectors
- 2 Rows...\$30 per panel, + connectors
- 3 Rows...\$35 per panel, + connectors
- 4 Rows...\$40 per panel, + connectors

Glazed ceramic connectors, type NOX female connectors with XACL panel mounting clip, \$11 each. To order with unglazed connectors, type UOX, consult Sales.

Use connector quantity discount schedule to determine pricing. Panel prices are not discounted.

Discount Schedule	
1-10	.....Net
11-24	.....10%
25-49	.....15%
50-99	.....20%
100 and up	.....Consult Sales

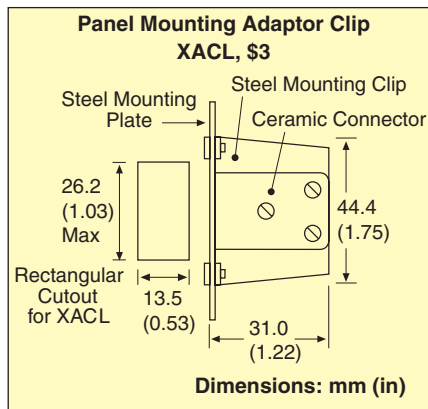

**MOST POPULAR MODELS HIGHLIGHTED!**

To Order (Specify Model Number)					
Circuits Per Row (mm/in)		1 Row 67 mm H (2 5/8")	2 Rows 111 mm H (4 3/8")	3 Rows 156 mm H (6 1/8")	4 Rows 200 mm H (7 7/8")
6 146 mm L (5 3/4")	Model No. Price	NXJP1-06-(*) \$79.00	NXJP2-12-(*) \$127.20	NXJP3-18-(*) \$180.80	NXJP4-24-(*) \$234.40
12 267 mm L (10 1/2")	Model No. Price	NXJP1-12-(*) \$122.00	NXJP2-24-(*) \$224.40	NXJP3-36-(*) \$310.40	NXJP4-48-(*) \$428.80
18 375 mm L (14 3/4")	Model No. Price	NXJP1-18-(*) \$170.80	NXJP2-36-(*) \$305.40	NXJP3-54-(*) \$423.80	NXJP4-72-(*) \$558.40

**Note:** Male connectors can be ordered in place of the female jacks. Consult Sales Department. All OMEGA® NXJP jack panels are shipped unassembled, with all necessary hardware for mounting included. \* Insert thermocouple calibration: J, K, T, E, R, S, N, G, C, D, or U in model number. **Ordering Example:** NXJP1-18-K, single-row color-coded jack panel with Type K connector, \$170.80.



#### UNITED STATES

[www.omega.com](http://www.omega.com)  
1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)  
Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)  
Deckenpfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)  
Manchester, England  
0800-488-488

#### FRANCE

[www.omega.fr](http://www.omega.fr)  
Guyancourt, France  
088-466-342

#### CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)  
Karviná, Czech Republic  
596-311-899

#### BENELUX

[www.omega.nl](http://www.omega.nl)  
Amstelveen, NL  
0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters