


Tubular Thermistor Sensors

For Immersion Temperature Measurements

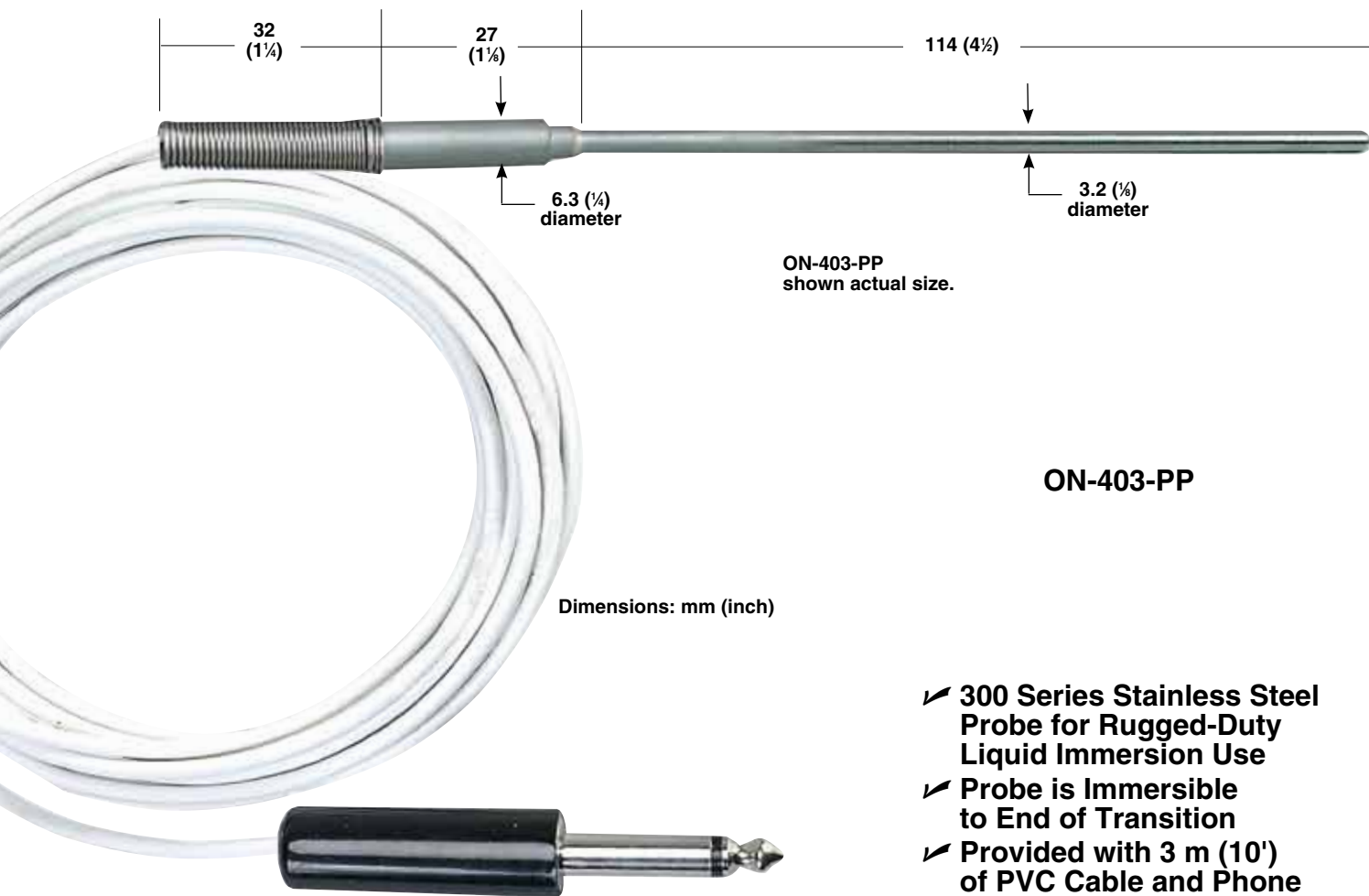

- ✓ 300 Series Stainless Steel Probe for Rugged-Duty Liquid Immersion Use
- ✓ Probe is Immersible to End of Transition
- ✓ Provided with 3 m (10') of PVC Cable and Phone Plug Connector

To Order Visit omega.com/on-403-pp for Pricing and Details

Model Number	Resistance @ 25°C	Interchangeability @ 0 to 70°C	Cable Termination
ON-403-PP	2252 Ω @ 25°C	±0.1°C	Phone plug

Notes: For additional cable length, add required length (in inches) to end of the model number for an additional cost.

Ordering Examples: ON-403-PP, tubular stainless steel immersion thermistor sensor, 2252 Ω at 25°C, interchangeability is ±0.1°C, 3 m (10') of PVC insulated and jacketed cable and phone plug connector.

ON-403-PP-240, tubular stainless steel immersion thermistor sensor, 2252 Ω at 25°C, interchangeability is ±0.1°C, 6 m (20') of PVC insulated and jacketed cable with phone plug.

Accessories

Model Number	Description
450-ATH	Handheld thermometer, thermistor input
HH41	Handheld thermistor thermometer
HH42	Handheld thermistor thermometer with RS232 communications
SSLK-14-18	1/4" tube OD, 1/8" NPT, 316 SS compression fitting