

# Non-Reversible OMEGALABEL® Temperature Labels

## TL-3, 4, and 5 Range Series

- ✓ Adhesive Backs for Easy Mounting for Temperatures Above -40°C/°F
- ✓ Indicator Turns Black When Exposed

**Applications**


- General • Aeronautical • Electrical • HVAC
- All applications where size is not a conditioning factor

### Specifications


**Accuracy:** Up to 99°C (210°F) is ±1°C (1.8°F)  
 From 100°C (212°F) to 154°C (309°F) is ±1.5°C (2.7°F)  
 From 160°C (320°F) to 280°C (536°F) is ±1% and ±1°C (1.8°F)

### 3-Temperature Range Labels

#### TL-3 SERIES 26 x 18 mm (1 x 0.7")

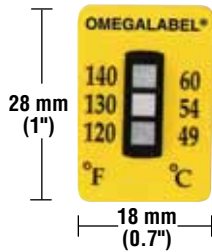

Model No.	Temperature Range
TL-3-105(*)	°F 105 110 115 °C 40 43 46
TL-3-120(*)	°F 120 130 140 °C 49 54 60
TL-3-150(*)	°F 150 160 170 °C 66 71 77
TL-3-180(*)	°F 180 190 200 °C 82 88 93
TL-3-210(*)	°F 210 220 230 °C 99 104 110
TL-3-240(*)	°F 240 250 260 °C 116 121 127
TL-3-270(*)	°F 270 280 290 °C 132 138 143
TL-3-300(*)	°F 300 310 320 °C 149 154 160
TL-3-330(*)	°F 330 340 350 °C 166 171 177
TL-3-360(*)	°F 360 370 380 °C 182 188 193
TL-3-390(*)	°F 390 400 410 °C 199 204 210
TL-3-420(*)	°F 420 435 450 °C 216 224 232
TL-3-465(*)	°F 465 480 490 °C 241 249 254

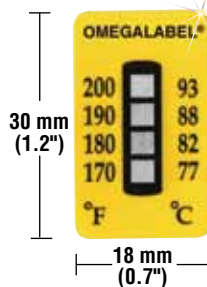

All models shown actual size.


### 4-Temperature Range Labels

#### TL-4 SERIES 30 x 18 mm (1.2 x 0.7")

Model No.	Temperature Range
TL-4-105(*)	°F 105 110 115 120 °C 40 43 46 49
TL-4-130(*)	°F 130 140 150 160 °C 54 60 66 71
TL-4-170(*)	°F 170 180 190 200 °C 77 82 88 93
TL-4-210(*)	°F 210 220 230 240 °C 99 104 110 116
TL-4-250(*)	°F 250 260 270 280 °C 121 127 132 138
TL-4-290(*)	°F 290 300 310 320 °C 143 149 154 160
TL-4-330(*)	°F 330 340 350 360 °C 166 171 177 182
TL-4-370(*)	°F 370 380 390 400 °C 188 193 199 204
TL-4-410(*)	°F 410 420 435 450 °C 210 216 224 232
TL-4-465(*)	°F 465 480 490 500 °C 241 249 254 260

\* Insert "-10" for package of 10 or "-30" for package of 30.  
**Ordering Example:** TL-4-410-30, 4 range temperature labels (410, 420, 435, 450°F), package of 30.

\* Insert "-10" for package of 10 or "-30" for package of 30.  
**Ordering Example:** TL-3-210-30, 3 temperature range labels (210, 220, 230°F), package of 30.

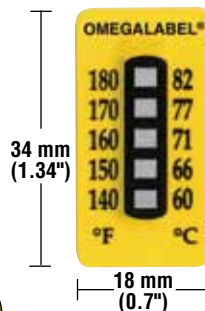

### 5-Temperature Range Labels

#### TL-5 SERIES 34 x 18 mm (1.34 x 0.7")

Model No.	Temperature Range
TL-5-105(*)	°F 105 110 115 120 130 °C 40 43 46 49 54
TL-5-140(*)	°F 140 150 160 170 180 °C 60 66 71 77 82
TL-5-190(*)	°F 190 200 210 220 230 °C 88 93 99 104 110
TL-5-240(*)	°F 240 250 260 270 280 °C 116 121 127 132 138
TL-5-290(*)	°F 290 300 310 320 330 °C 143 149 154 160 166
TL-5-340(*)	°F 340 350 360 370 380 °C 171 177 182 188 193
TL-5-390(*)	°F 390 400 410 420 435 °C 199 204 210 216 224
TL-5-450(*)	°F 450 465 480 490 500 °C 232 241 249 254 260

\* Insert "-10" for package of 10 or "-30" for package of 30.  
**Ordering Example:** TL-5-105-30, 5 range temperature labels (105, 110, 115, 120, 130°F), package of 30.