


Thermocouple Terminals

Barrier Strip Jackets


- ✓ Color-Coded to Calibration Type
- ✓ Complete with Calibration Type Terminal Lugs Installed, pkg of 6 (Order Below)
- ✓ Combination Phillips/Slot Screws
- ✓ Spade Lugs Accept Wire from 24 AWG to 16 AWG

Material: Glass filled nylon


Temperature Rating: 220°C (425°F)

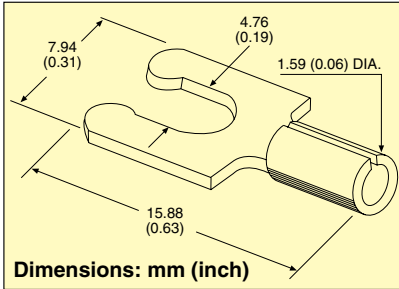

SL(*)-20
spade lugs,
package of 20

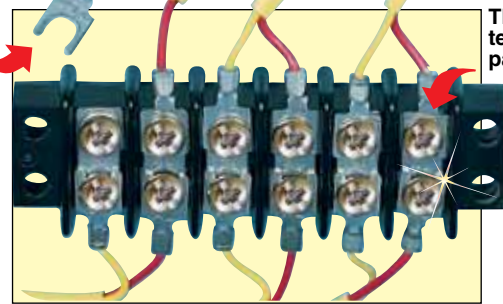

TL(*)-20
terminal lugs,
package of 20

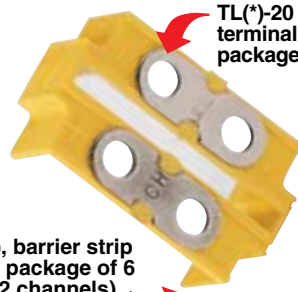

TL(*)-20
terminal lugs,
package of 20

BSJ(**), barrier strip jackets, package of 6 (up to 12 channels), shown actual size.




Crimping Tool

Easy-to-Use Ratchet Action

To attach the thermocouple spade lugs to your thermocouple wire. Operates on a ratchet principle to assure a complete crimp every time.

For Our Complete Line of Thermocouple Terminals Visit Us Online

We make running changes when technical advances allow. Check at time of ordering for additional features.

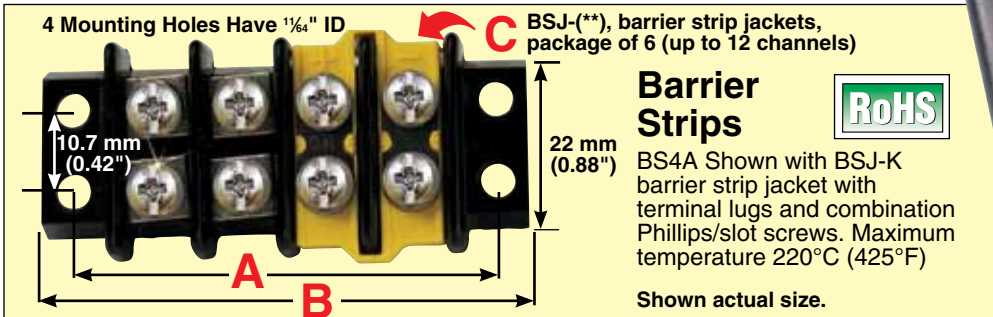

Alloy Types

Order Code	Thermocouple Alloy
CH	CHROMEGA®
AL	ALOMEGA®
IR	Iron
CO	Constantan
CP	Copper (also R/S positive lead)
11	Type R negative compensating lead
405	Type C positive compensating lead
426	Type C negative compensating lead
203	Type D positive compensating lead
225	Type D negative compensating lead
200	Type G positive compensating lead
226	Type G negative compensating lead

Now Available Type N (OMEGALLOY®)

OMEGALLOY®	OMEGA-P®	OMEGA-N®
Spade lug	SLNP-20	SLNN-20
Terminal lug	TLNP-20	TLNN-20

Number of Terminals	Dimensions mm (inch)		Model Number
	A	B	
2	33.34 (1.31)	41.28 (1.63)	BS2A
3	44.45 (1.75)	52.39 (2.06)	BS3A
4	55.55 (2.19)	63.50 (2.50)	BS4A
5	66.80 (2.63)	74.60 (2.94)	BS5A
6	77.79 (3.06)	85.73 (3.38)	BS6A
8	100.08 (3.94)	107.95 (4.25)	BS8A
10	122.24 (4.82)	130.18 (5.13)	BS10A
12	144.47 (5.69)	152.40 (6.00)	BS12A
16	188.92 (7.44)	196.85 (7.75)	BS16A
20	244.48 (9.63)	252.42 (9.94)	BS20A

Note: Terminal lugs and spade lugs sold separately.

Terminal Lugs and Spade Lugs

To Order		
Key	Model No.	Description
A	TL(*)-20	Terminal lugs, package of 20
B	SL(*)-20	Spade lugs, package of 20 (not available for C, D, and G calibrations)
C	BSJ(**)	Barrier strip jacket with terminal lugs (package of 6 for up to 12 channels)

* Specify alloy type from chart above. ** Specify calibration: J, K, T, E, R/S, U or N.

Ordering Example: TLCH-20, terminal lugs, CHROMEGA®, pkg of 20.