

# Universal Connector Write-On Female

Works with All Miniature and Standard Connectors  
Type USTW Glass-Filled Nylon  
Rated from -29 to 220°C (-20 to 425°F)



USTW-K-F

Patented connector fits both standard and miniature connectors.



- ✓ 2 Connectors in 1
- ✓ Universal Female Fits Both Miniature and Standard Connectors
- ✓ Removable/Reversible Write-On Window
- ✓ Accepts Stranded or Solid Wire Up to Size 14 AWG
- ✓ Fully Compatible with OMEGA's as well as All Industry Miniature AND Standard-Size Thermocouple Connectors

USTW-K-F



NMP-K-M

OGP-K-M

GST-K-M

KQIN low-noise probe.

All connectors are shown close to actual size.

OST-K-M


SHX-K-M

USTW-T-F

**PATENTED**  
Covered by U.S. and International patents and pending applications.

NHXX-T-M

## To Order (Visit [omega.com/ust](http://omega.com/ust) for Pricing and Details)

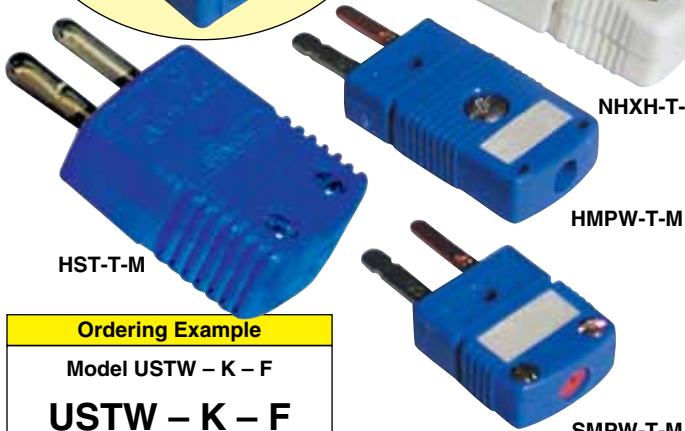

HMPW-T-M

HST-T-M

SMPW-T-M

Alloy Code†	Compensating Alloy Used in Connector		Shell Color	Write-On Window Style
	+	-		
K	CHROMEGA®	ALOMEGA®	Yellow	USTW-K-F
T	Copper	Constantan	Blue	USTW-T-F
J	Iron	Constantan	Black	USTW-J-F
E	CHROMEGA®	Constantan	Purple	USTW-E-F
R/S	Copper	Alloy #11	Green	USTW-R/S-F
U	Copper	Copper	White	USTW-N-F
N	OMEGA-P®	OMEGA-N®	Orange	USTW-N-F

† J, K, T, E, R, S and B are ANSI designations. OMEGA-P® and OMEGA-N® are generically known as nichsil-nisil.

Note: Type U (uncompensated) connectors are used with Type B thermocouples (Pt/6%Rh-Pt/30%Rh).

**Ordering Example**

Model USTW - K - F

**USTW - K - F**

Universal Connector    Window Style    Calibration    Female (only)