


Heavy Duty Hand-Held Thermocouple Probe

Ideal for Grain, Compost and Other Heavy Duty Insertion Applications



HPP Series Starts at **£98**

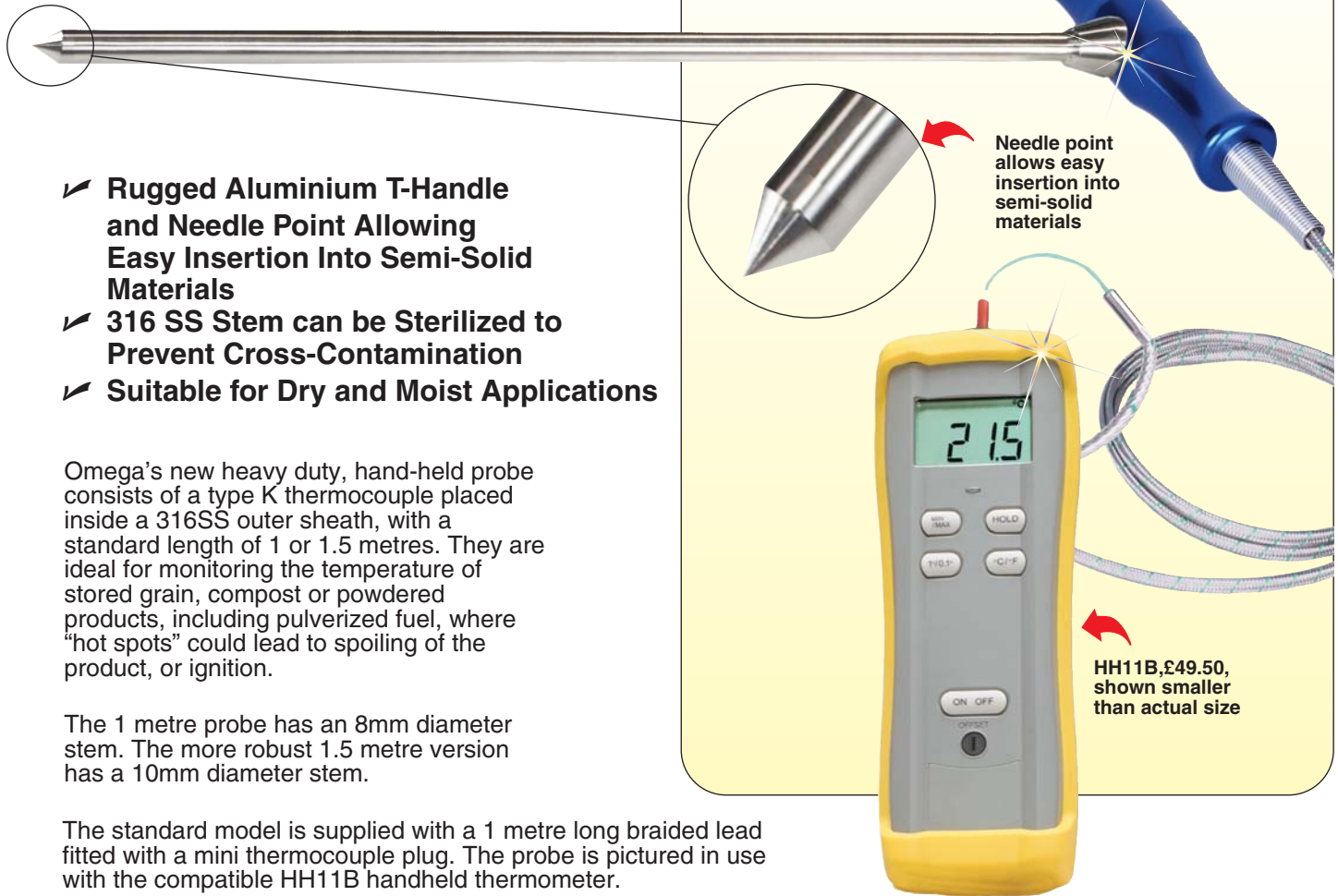

HPP1-1-KI-1000, £98, shown smaller than actual size

Needle point allows easy insertion into semi-solid materials

HH11B, £49.50, shown smaller than actual size

- ✓ Rugged Aluminium T-Handle and Needle Point Allowing Easy Insertion Into Semi-Solid Materials
- ✓ 316 SS Stem can be Sterilized to Prevent Cross-Contamination
- ✓ Suitable for Dry and Moist Applications

Omega's new heavy duty, hand-held probe consists of a type K thermocouple placed inside a 316SS outer sheath, with a standard length of 1 or 1.5 metres. They are ideal for monitoring the temperature of stored grain, compost or powdered products, including pulverized fuel, where "hot spots" could lead to spoiling of the product, or ignition.

The 1 metre probe has an 8mm diameter stem. The more robust 1.5 metre version has a 10mm diameter stem.

The standard model is supplied with a 1 metre long braided lead fitted with a mini thermocouple plug. The probe is pictured in use with the compatible HH11B handheld thermometer.

To Order (Specify Model Number)		
Model No.	Sheath Length	Price
HPP1-1-KI-1000	1 Metre Long Heavy Duty Probe	£98
HPP1-1-KI-1500	1.5 Metre Long Heavy Duty Probe	£125

Other sheath and cable lengths available on request. Contact sales to discuss your specific requirements.

Ordering Example: HPP1-KI-1000, handheld probe, 1 metre long, 8 mm diameter probe with 1 metre long braided cable.

HH11B thermocouple indicator, £98 + £49.50 = **£147.50**



omega.co.uk[®]

Your One-Stop Source for Process Measurement and Control!

Freephone 0800 488 488 | International +44(0) 161 777 6622 | Fax +44(0) 161 777 6622 | Sales@omega.co.uk

www.omega.co.uk



UNITED STATES

www.omega.com

1-800-TC-OMEGA
Stamford, CT.

UNITED KINGDOM

www.omega.co.uk

Manchester, England
0800-488-488
+44-(0)161-777-6611

CANADA

www.omega.ca

Laval(Quebec)
1-800-TC-OMEGA

FRANCE

www.omega.fr

0800-466-342

GERMANY

www.omega.de

Deckenfronn, Germany
0800-8266342

BENELUX

www.omega.nl

0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders, Relative Humidity Measurement Instruments, PT100 Probes, PT100 Elements, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples, Thermowells and Head and Well Assemblies, Transmitters, Thermocouple Wire, RTD Probes

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485, Ethernet and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Pressure Transmitters, Strain Gauges, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters